
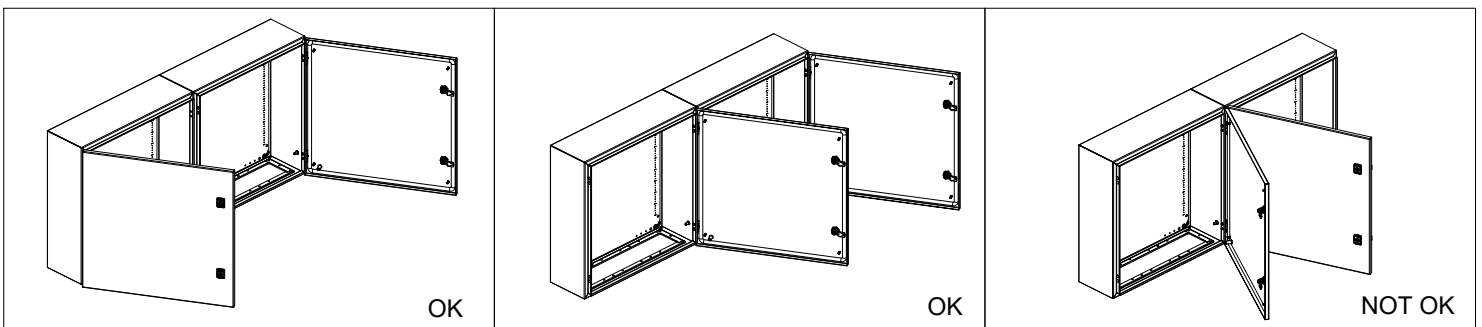
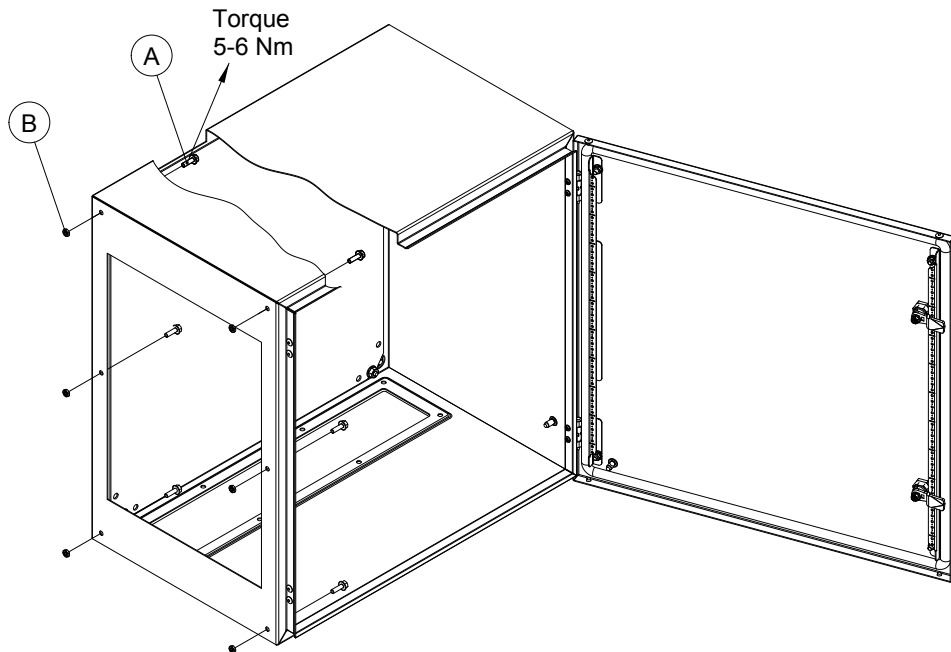
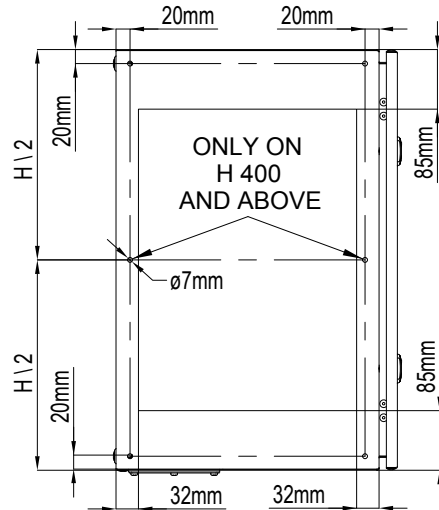



CK01


 



 


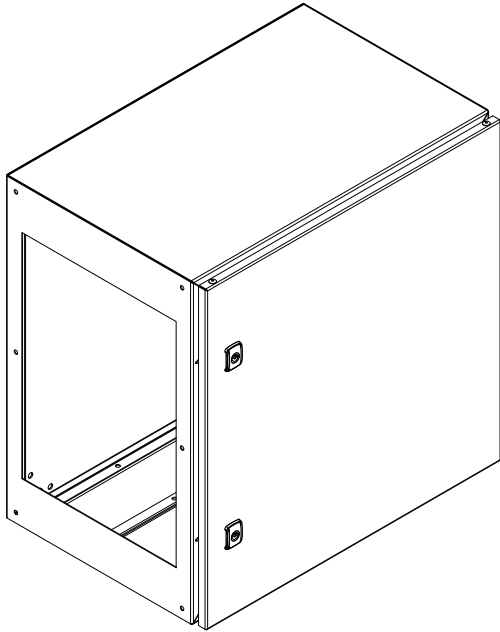

Ref.	Pic.	Qty.
A	M6x20	6
B	M6	6
C	M6	6

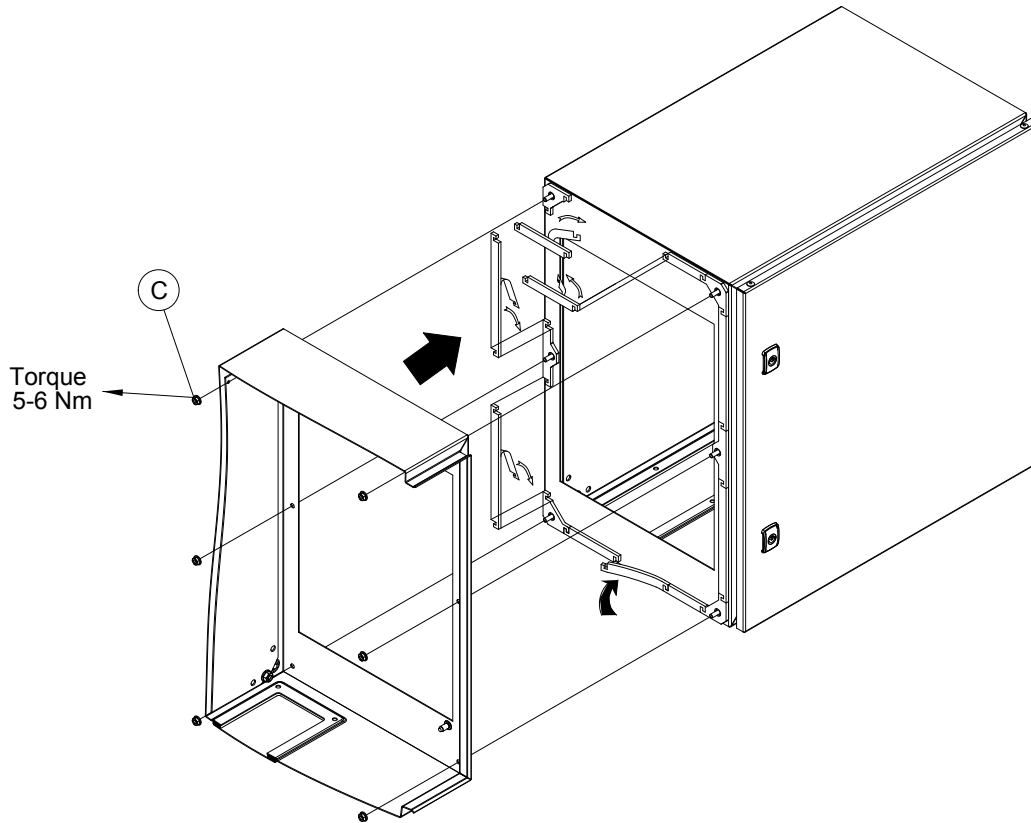

CK01



	 x4	 x2	 30 x4	 50 x8	 75 x2	 85 x2	 100 x8	 200 x6
ENCLOSURE HEIGHT								
300	4x							2x
350	4x			2x				2x
400	4x	2x					4x	
500	4x	2x		4x			4x	
600	4x	2x						4x
700	4x	2x		4x				4x
800	4x	2x					4x	4x
1000	4x	2x					4x	6x
1200	4x	2x		8x			4x	6x
ENCLOSURE DEPTH								
150			2x					
210						2x		
260				2x		2x		
300					2x		2x	
400					2x		4x	