 


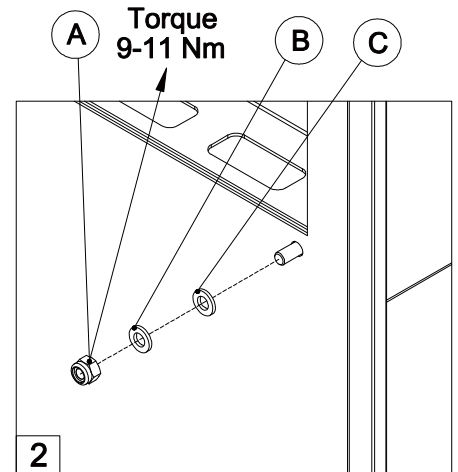
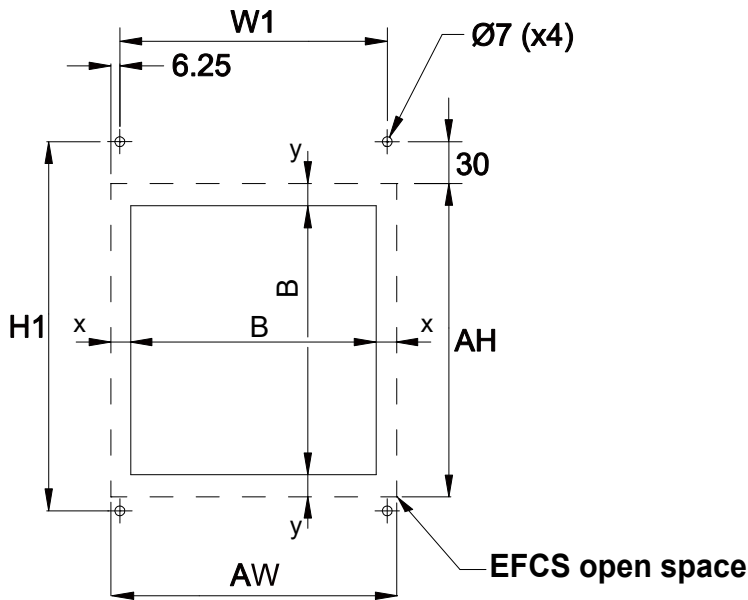


EFCS

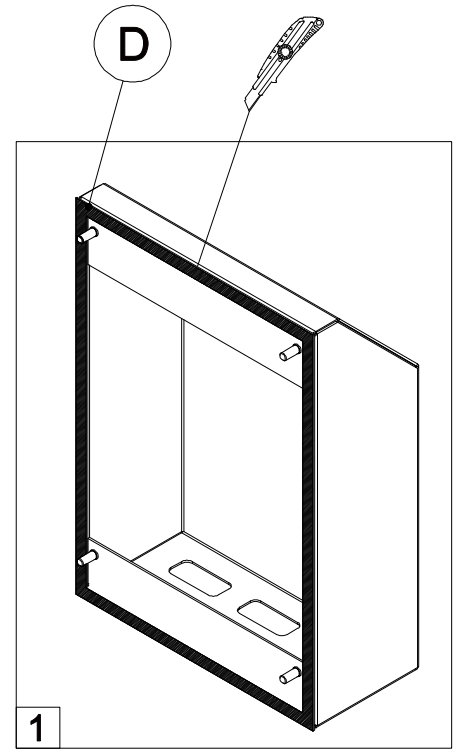

Ref.	Pic.	Qty.
A	M6	4
B	M6	4
C	M6 Nylon	4
D	1,5x10	1

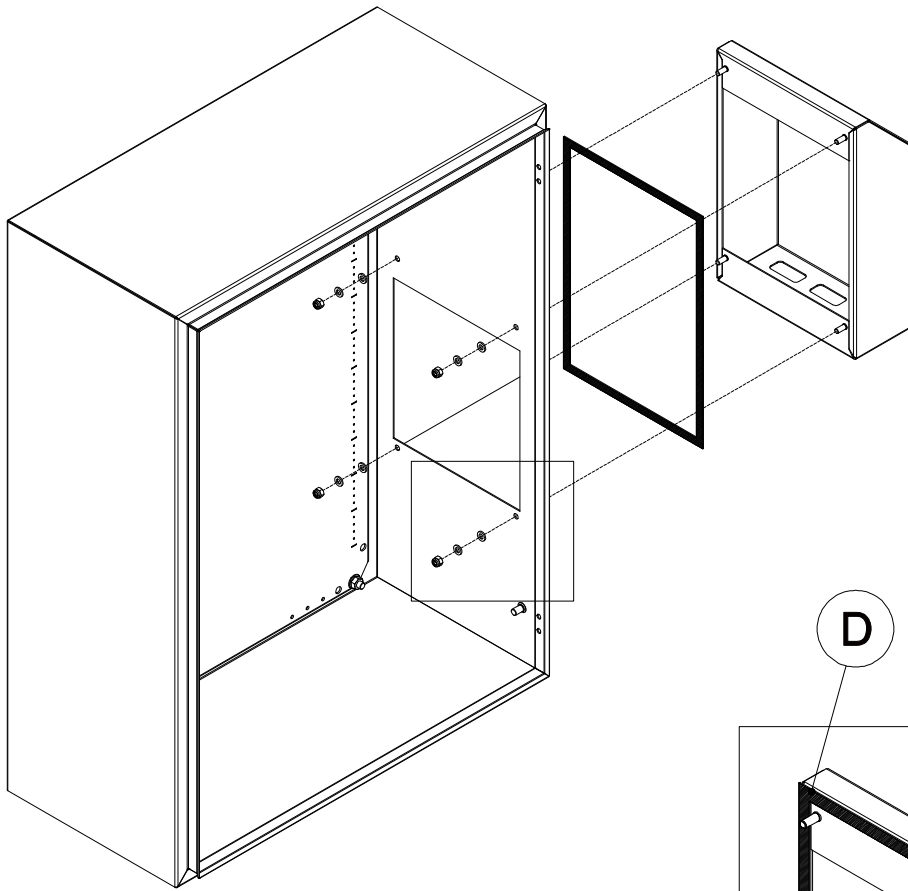

Ref.	Filter type	H	W	H1	W1	AH	AW	B	x	y
EFCS20	EF100	275	175	215	142.5	175	155	92	31.5	31.5
	EF200							125	15	25
EFCS25-30	EF250	375	275	315	242.5	275	255	223	11	26
	EF300									
EFCS50-60	EF500	450	350	390	317.5	350	330	291	19.5	29.5
	EF600									
	EF700									