

nVent ERIFLEX Flexbus System

Rodent and Termite Protection Solution



Introduction

Electrical conductors are installed in a wide variety of environments, with some being more susceptible to pests, rodents, or termites. This is especially true for nVent ERIFLEX FleXbus conductors or cables, which are often laid close to the ground or directly buried in underground conduits or trenches.

Rodents are drawn to insulating materials because of the plasticizers and aromatic odors they contain. Additionally, the color and texture of the cable sheath material can be appealing to them. Termites, on the other hand, live in underground nests deep in the soil. Although their primary diet consists of cellulose from organic waste and plant roots, once these natural sources are depleted, they seek out other manmade sources, such as cables.

When the insulation layer of a cable / FleXbus is chewed through, it can lead to short circuits and potentially cause an electrical fire. Therefore, in areas where there is a risk of pests, rodents, or termites, it is important to consider adding protective barriers or additives to the conductors to prevent damage.



Rodent and Termite Protection Solution for nVent ERIFLEX Flexbus Conductors



A new version of the Flexbus conductors is now available and includes rodent and termite repellent. During the extrusion process, an additive/masterbatch is incorporated into the outer sheath of the Flexbus conductor, ensuring long-lasting effectiveness through the controlled release of active ingredients.

RODENT REPELLENT – HOW IT WORKS

Research has shown that animals are attracted to plastic materials because they look, smell, and taste appealing. Our additive changes this attractiveness in four significant ways:

- When an animal bites into the plastic, they encounter an extremely foul-tasting material
- This unpleasant taste is combined with an extraordinary pungency that causes severe distress to the animal's mucosa, making their mouth, nose, and eyes burn
- Our additive has a distinct odor that animals will now associate with this bad experience, leading to behavior modification and causing animals to avoid these products in the future
- The fear response and unpleasant reaction are also communicated to other animals in the vicinity

TERMITE REPELLENT – HOW IT WORKS

Our Additive for Insects is a highly effective insect repellent masterbatch that, when integrated into a polymer product, provides protection against insect damage. This masterbatch is particularly potent against termites. It acts as a barrier, preventing termites and other agriculturally harmful insects from damaging polymer-based products and the surrounding environment.

Our additive/masterbatch offers several benefits:

- **It is non-toxic, non-hazardous, non-dangerous**, environmentally friendly, and has a low odor
- It complies with **REACH and RoHS** standards, as verified by SGS Testing & Control Services Singapore
- It has been **tested according to the GB/T 34016-2017** Chinese standard for rat and termite proof wires and cables, with tests performed by the China National Center for Quality Supervision and Test of Electric Wire and Cable.
- Its **effectiveness** against insects has been **confirmed** by BAM Germany (Federal Institute for Materials Research & Testing) in accordance with DIN EN 117: Wood preservatives - Determination of toxic values against Reticulitermes species (European termites) (Laboratory method)
- Its **effectiveness** against rodents has been **validated** by Texas A&M University (TAMU) with insulation treated with our Repellent for Rodents

Note: The rodent and termite repellent has not undergone testing according to UL and CSA standards for the North American market.

Rodent and Termite Protection Solution for nVent ERIFLEX Flexbus Conductors



“Where conditions experienced or expected constitute a hazard (AL2), the wiring system shall be selected accordingly or special protective measures shall be adopted”

The IEC 60364: Low-voltage electrical installations – Part 5-52: Selection and erection of electrical equipment – Wiring systems – Chapter 522: Selection and erection of wiring systems in relation to external influences – 522.10: Presence of fauna (AL), specifies:

“Where conditions experienced or expected constitute a hazard (AL2), the wiring system shall be selected accordingly or special protective measures shall be adopted”

The IEC 60721-3-3: Classification of groups of environmental parameters and their severities - Stationary use at weather-protected locations – Chapter 5.4: Biological conditions – Table 3: Classification of biological conditions, **classifies Flexbus conductors with rodent and termite repellent as 3B3 (Presence of rodents and other animals harmful to products, including termites).**

The IEC 60721-3-4: Classification of groups of environmental parameters and their severities - Stationary use at non-weather protected locations – Chapter 5.3 Biological conditions – Table 3: Classification of biological conditions, **classifies Flexbus conductors with rodent and termite repellent as 4B2 (Presence of rodents and other animals harmful to products, including termites).**

HOW TO REQUEST FLEXBUS CONDUCTORS PROTECTED AGAINST RODENT AND TERMITE

Please reach out to your nVent ERIFLEX representative or contact us at ERIFLEX.flexbus@nVent.com for more information or to obtain a quote.

Additionally, you can use our online Flexbus quoting and configurator software. Within this software, select the “Conductor with Rodent and Termite Repellent” version. To request access to this software, please register online: <https://go.nVent.com/FlexbusConfigurator>.

PRODUCT IDENTIFICATION

A Flexbus conductor extruded with the rodent and termite repellent will feature a special marking on the insulation sleeve, and the sleeve color will be dark grey – RAL 7046.

 
nVent
Flexbus Advanced

960mm²
Copper Clad Aluminum
Rodent & Termite Repellent

115°C
1000VAC/1500VDC IEC
Class II / Reinforced
Insulation



LSHFFR
Quality code xxxxx



Part Numbers and Description

Flexbus Conductors with Rodent and Termite Repellent					
Cross Section	Part Number	Global Part Number	Description	Packing Unit pc	Weight kg
220 mm ²	508400	FLEXCORE220L2	Flexbus Conductor 220 mm ² , 2 Meters Long with Rodent and Termite Repellent	1	2.5
	508401	FLEXCORE220L3	Flexbus Conductor 220 mm ² , 3 Meters Long with Rodent and Termite Repellent	1	3.8
	508402	FLEXCORE220L4	Flexbus Conductor 220 mm ² , 4 Meters Long with Rodent and Termite Repellent	1	5.1
	508403	FLEXCORE220L5	Flexbus Conductor 220 mm ² , 5 Meters Long with Rodent and Termite Repellent	1	6.3
	508404	FLEXCORE220L6	Flexbus Conductor 220 mm ² , 6 Meters Long with Rodent and Termite Repellent	1	7.6
	508405	FLEXCORE220L7	Flexbus Conductor 220 mm ² , 7 Meters Long with Rodent and Termite Repellent	1	8.9
	508406	FLEXCORE220L8	Flexbus Conductor 220 mm ² , 8 Meters Long with Rodent and Termite Repellent	1	10.1
	508407	FLEXCORE220L9	Flexbus Conductor 220 mm ² , 9 Meters Long with Rodent and Termite Repellent	1	11.4
	508408	FLEXCORE220L10	Flexbus Conductor 220 mm ² , 10 Meters Long with Rodent and Termite Repellent	1	12.7
	508409	FLEXCORE220L11	Flexbus Conductor 220 mm ² , 11 Meters Long with Rodent and Termite Repellent	1	13.9
	508410	FLEXCORE220L12	Flexbus Conductor 220 mm ² , 12 Meters Long with Rodent and Termite Repellent	1	15.1
	508411	FLEXCORE220L13	Flexbus Conductor 220 mm ² , 13 Meters Long with Rodent and Termite Repellent	1	16.4
	508412	FLEXCORE220L14	Flexbus Conductor 220 mm ² , 14 Meters Long with Rodent and Termite Repellent	1	17.6
	508413	FLEXCORE220L15	Flexbus Conductor 220 mm ² , 15 Meters Long with Rodent and Termite Repellent	1	18.9
	508414	FLEXCORE220L16	Flexbus Conductor 220 mm ² , 16 Meters Long with Rodent and Termite Repellent	1	20.2
	508415	FLEXCORE220L17	Flexbus Conductor 220 mm ² , 17 Meters Long with Rodent and Termite Repellent	1	21.4
	508416	FLEXCORE220L18	Flexbus Conductor 220 mm ² , 18 Meters Long with Rodent and Termite Repellent	1	22.7
	508417	FLEXCORE220L19	Flexbus Conductor 220 mm ² , 19 Meters Long with Rodent and Termite Repellent	1	23.9
	508418	FLEXCORE220L20	Flexbus Conductor 220 mm ² , 20 Meters Long with Rodent and Termite Repellent	1	25.2
	508419	FLEXCORE220L21	Flexbus Conductor 220 mm ² , 21 Meters Long with Rodent and Termite Repellent	1	26.5
	508420	FLEXCORE220L22	Flexbus Conductor 220 mm ² , 22 Meters Long with Rodent and Termite Repellent	1	27.7
	508421	FLEXCORE220L23	Flexbus Conductor 220 mm ² , 23 Meters Long with Rodent and Termite Repellent	1	29
	508422	FLEXCORE220L24	Flexbus Conductor 220 mm ² , 24 Meters Long with Rodent and Termite Repellent	1	30.2
	508423	FLEXCORE220L25	Flexbus Conductor 220 mm ² , 25 Meters Long with Rodent and Termite Repellent	1	31.5

Part Numbers and Description

Flexbus Conductors with Rodent and Termite Repellent					
Cross Section	Part Number	Global Part Number	Description	Packing Unit pc	Weight kg
360 mm ²	508424	FLEXCORE360L2	Flexbus Conductor 360 mm ² , 2 Meters Long with Rodent and Termite Repellent	1	3.7
	508425	FLEXCORE360L3	Flexbus Conductor 360 mm ² , 3 Meters Long with Rodent and Termite Repellent	1	5.5
	508426	FLEXCORE360L4	Flexbus Conductor 360 mm ² , 4 Meters Long with Rodent and Termite Repellent	1	7.3
	508427	FLEXCORE360L5	Flexbus Conductor 360 mm ² , 5 Meters Long with Rodent and Termite Repellent	1	9.2
	508428	FLEXCORE360L6	Flexbus Conductor 360 mm ² , 6 Meters Long with Rodent and Termite Repellent	1	11
	508429	FLEXCORE360L7	Flexbus Conductor 360 mm ² , 7 Meters Long with Rodent and Termite Repellent	1	12.9
	508430	FLEXCORE360L8	Flexbus Conductor 360 mm ² , 8 Meters Long with Rodent and Termite Repellent	1	14.7
	508431	FLEXCORE360L9	Flexbus Conductor 360 mm ² , 9 Meters Long with Rodent and Termite Repellent	1	16.5
	508432	FLEXCORE360L10	Flexbus Conductor 360 mm ² , 10 Meters Long with Rodent and Termite Repellent	1	18.4
	508433	FLEXCORE360L11	Flexbus Conductor 360 mm ² , 11 Meters Long with Rodent and Termite Repellent	1	20.2
	508434	FLEXCORE360L12	Flexbus Conductor 360 mm ² , 12 Meters Long with Rodent and Termite Repellent	1	22.1
	508435	FLEXCORE360L13	Flexbus Conductor 360 mm ² , 13 Meters Long with Rodent and Termite Repellent	1	23.9
	508436	FLEXCORE360L14	Flexbus Conductor 360 mm ² , 14 Meters Long with Rodent and Termite Repellent	1	25.8
	508437	FLEXCORE360L15	Flexbus Conductor 360 mm ² , 15 Meters Long with Rodent and Termite Repellent	1	27.6
	508438	FLEXCORE360L16	Flexbus Conductor 360 mm ² , 16 Meters Long with Rodent and Termite Repellent	1	29.4
	508439	FLEXCORE360L17	Flexbus Conductor 360 mm ² , 17 Meters Long with Rodent and Termite Repellent	1	31.3
	508440	FLEXCORE360L18	Flexbus Conductor 360 mm ² , 18 Meters Long with Rodent and Termite Repellent	1	33.1
	508441	FLEXCORE360L19	Flexbus Conductor 360 mm ² , 19 Meters Long with Rodent and Termite Repellent	1	35
	508442	FLEXCORE360L20	Flexbus Conductor 360 mm ² , 20 Meters Long with Rodent and Termite Repellent	1	36.8
	508443	FLEXCORE360L21	Flexbus Conductor 360 mm ² , 21 Meters Long with Rodent and Termite Repellent	1	38.6
	508444	FLEXCORE360L22	Flexbus Conductor 360 mm ² , 22 Meters Long with Rodent and Termite Repellent	1	40.5
	508445	FLEXCORE360L23	Flexbus Conductor 360 mm ² , 23 Meters Long with Rodent and Termite Repellent	1	42.3
	508446	FLEXCORE360L24	Flexbus Conductor 360 mm ² , 24 Meters Long with Rodent and Termite Repellent	1	44.2
	508447	FLEXCORE360L25	Flexbus Conductor 360 mm ² , 25 Meters Long with Rodent and Termite Repellent	1	46

Part Numbers and Description

Flexbus Conductors with Rodent and Termite Repellent					
Cross Section	Part Number	Global Part Number	Description	Packing Unit pc	Weight kg
545 mm ²	508448	FLEXCORE545L2	Flexbus Conductor 545 mm ² , 2 Meters Long with Rodent and Termite Repellent	1	5.2
	508449	FLEXCORE545L3	Flexbus Conductor 545 mm ² , 3 Meters Long with Rodent and Termite Repellent	1	7.8
	508450	FLEXCORE545L4	Flexbus Conductor 545 mm ² , 4 Meters Long with Rodent and Termite Repellent	1	10.3
	508451	FLEXCORE545L5	Flexbus Conductor 545 mm ² , 5 Meters Long with Rodent and Termite Repellent	1	12.9
	508452	FLEXCORE545L6	Flexbus Conductor 545 mm ² , 6 Meters Long with Rodent and Termite Repellent	1	15.5
	508453	FLEXCORE545L7	Flexbus Conductor 545 mm ² , 7 Meters Long with Rodent and Termite Repellent	1	18.1
	508454	FLEXCORE545L8	Flexbus Conductor 545 mm ² , 8 Meters Long with Rodent and Termite Repellent	1	20.7
	508455	FLEXCORE545L9	Flexbus Conductor 545 mm ² , 9 Meters Long with Rodent and Termite Repellent	1	23.3
	508456	FLEXCORE545L10	Flexbus Conductor 545 mm ² , 10 Meters Long with Rodent and Termite Repellent	1	25.8
	508457	FLEXCORE545L11	Flexbus Conductor 545 mm ² , 11 Meters Long with Rodent and Termite Repellent	1	28.3
	508458	FLEXCORE545L12	Flexbus Conductor 545 mm ² , 12 Meters Long with Rodent and Termite Repellent	1	30.8
	508459	FLEXCORE545L13	Flexbus Conductor 545 mm ² , 13 Meters Long with Rodent and Termite Repellent	1	33.4
	508460	FLEXCORE545L14	Flexbus Conductor 545 mm ² , 14 Meters Long with Rodent and Termite Repellent	1	36
	508461	FLEXCORE545L15	Flexbus Conductor 545 mm ² , 15 Meters Long with Rodent and Termite Repellent	1	38.6
	508462	FLEXCORE545L16	Flexbus Conductor 545 mm ² , 16 Meters Long with Rodent and Termite Repellent	1	41.1
	508463	FLEXCORE545L17	Flexbus Conductor 545 mm ² , 17 Meters Long with Rodent and Termite Repellent	1	43.7
	508464	FLEXCORE545L18	Flexbus Conductor 545 mm ² , 18 Meters Long with Rodent and Termite Repellent	1	46.3
	508465	FLEXCORE545L19	Flexbus Conductor 545 mm ² , 19 Meters Long with Rodent and Termite Repellent	1	48.8
	508466	FLEXCORE545L20	Flexbus Conductor 545 mm ² , 20 Meters Long with Rodent and Termite Repellent	1	51.4
	508467	FLEXCORE545L21	Flexbus Conductor 545 mm ² , 21 Meters Long with Rodent and Termite Repellent	1	54
	508468	FLEXCORE545L22	Flexbus Conductor 545 mm ² , 22 Meters Long with Rodent and Termite Repellent	1	56.5
	508469	FLEXCORE545L23	Flexbus Conductor 545 mm ² , 23 Meters Long with Rodent and Termite Repellent	1	59.1
	508470	FLEXCORE545L24	Flexbus Conductor 545 mm ² , 24 Meters Long with Rodent and Termite Repellent	1	61.7
	508471	FLEXCORE545L25	Flexbus Conductor 545 mm ² , 25 Meters Long with Rodent and Termite Repellent	1	64.3

Part Numbers and Description

Flexbus Conductors with Rodent and Termite Repellent					
Cross Section	Part Number	Global Part Number	Description	Packing Unit pc	Weight kg
640 mm ²	508472	FLEXCORE640L2	Flexbus Conductor 640 mm ² , 2 Meters Long with Rodent and Termite Repellent	1	5.9
	508473	FLEXCORE640L3	Flexbus Conductor 640 mm ² , 3 Meters Long with Rodent and Termite Repellent	1	8.8
	508474	FLEXCORE640L4	Flexbus Conductor 640 mm ² , 4 Meters Long with Rodent and Termite Repellent	1	11.8
	508475	FLEXCORE640L5	Flexbus Conductor 640 mm ² , 5 Meters Long with Rodent and Termite Repellent	1	14.7
	508476	FLEXCORE640L6	Flexbus Conductor 640 mm ² , 6 Meters Long with Rodent and Termite Repellent	1	17.7
	508477	FLEXCORE640L7	Flexbus Conductor 640 mm ² , 7 Meters Long with Rodent and Termite Repellent	1	20.6
	508478	FLEXCORE640L8	Flexbus Conductor 640 mm ² , 8 Meters Long with Rodent and Termite Repellent	1	23.6
	508479	FLEXCORE640L9	Flexbus Conductor 640 mm ² , 9 Meters Long with Rodent and Termite Repellent	1	26.5
	508480	FLEXCORE640L10	Flexbus Conductor 640 mm ² , 10 Meters Long with Rodent and Termite Repellent	1	29.5
	508481	FLEXCORE640L11	Flexbus Conductor 640 mm ² , 11 Meters Long with Rodent and Termite Repellent	1	32.3
	508482	FLEXCORE640L12	Flexbus Conductor 640 mm ² , 12 Meters Long with Rodent and Termite Repellent	1	35.3
	508483	FLEXCORE640L13	Flexbus Conductor 640 mm ² , 13 Meters Long with Rodent and Termite Repellent	1	38.2
	508484	FLEXCORE640L14	Flexbus Conductor 640 mm ² , 14 Meters Long with Rodent and Termite Repellent	1	41.2
	508485	FLEXCORE640L15	Flexbus Conductor 640 mm ² , 15 Meters Long with Rodent and Termite Repellent	1	44.1
	508486	FLEXCORE640L16	Flexbus Conductor 640 mm ² , 16 Meters Long with Rodent and Termite Repellent	1	47
	508487	FLEXCORE640L17	Flexbus Conductor 640 mm ² , 17 Meters Long with Rodent and Termite Repellent	1	50
	508488	FLEXCORE640L18	Flexbus Conductor 640 mm ² , 18 Meters Long with Rodent and Termite Repellent	1	52.9
	508489	FLEXCORE640L19	Flexbus Conductor 640 mm ² , 19 Meters Long with Rodent and Termite Repellent	1	55.9
	508490	FLEXCORE640L20	Flexbus Conductor 640 mm ² , 20 Meters Long with Rodent and Termite Repellent	1	58.8
	508491	FLEXCORE640L21	Flexbus Conductor 640 mm ² , 21 Meters Long with Rodent and Termite Repellent	1	61.7
	508492	FLEXCORE640L22	Flexbus Conductor 640 mm ² , 22 Meters Long with Rodent and Termite Repellent	1	64.7
	508493	FLEXCORE640L23	Flexbus Conductor 640 mm ² , 23 Meters Long with Rodent and Termite Repellent	1	67.6
	508494	FLEXCORE640L24	Flexbus Conductor 640 mm ² , 24 Meters Long with Rodent and Termite Repellent	1	70.6
	508495	FLEXCORE640L25	Flexbus Conductor 640 mm ² , 25 Meters Long with Rodent and Termite Repellent	1	73.5

Part Numbers and Description

Flexbus Conductors with Rodent and Termite Repellent					
Cross Section	Part Number	Global Part Number	Description	Packing Unit pc	Weight kg
800 mm ²	508496	FLEXCORE800L2	Flexbus Conductor 800 mm ² , 2 Meters Long with Rodent and Termite Repellent	1	7.44
	508497	FLEXCORE800L3	Flexbus Conductor 800 mm ² , 3 Meters Long with Rodent and Termite Repellent	1	11.16
	508498	FLEXCORE800L4	Flexbus Conductor 800 mm ² , 4 Meters Long with Rodent and Termite Repellent	1	14.88
	508499	FLEXCORE800L5	Flexbus Conductor 800 mm ² , 5 Meters Long with Rodent and Termite Repellent	1	18.6
	508500	FLEXCORE800L6	Flexbus Conductor 800 mm ² , 6 Meters Long with Rodent and Termite Repellent	1	22.32
	508501	FLEXCORE800L7	Flexbus Conductor 800 mm ² , 7 Meters Long with Rodent and Termite Repellent	1	26.04
	508502	FLEXCORE800L8	Flexbus Conductor 800 mm ² , 8 Meters Long with Rodent and Termite Repellent	1	29.76
	508503	FLEXCORE800L9	Flexbus Conductor 800 mm ² , 9 Meters Long with Rodent and Termite Repellent	1	33.48
	508504	FLEXCORE800L10	Flexbus Conductor 800 mm ² , 10 Meters Long with Rodent and Termite Repellent	1	37.2
	508505	FLEXCORE800L11	Flexbus Conductor 800 mm ² , 11 Meters Long with Rodent and Termite Repellent	1	40.92
	508506	FLEXCORE800L12	Flexbus Conductor 800 mm ² , 12 Meters Long with Rodent and Termite Repellent	1	44.64
	508507	FLEXCORE800L13	Flexbus Conductor 800 mm ² , 13 Meters Long with Rodent and Termite Repellent	1	48.36
	508508	FLEXCORE800L14	Flexbus Conductor 800 mm ² , 14 Meters Long with Rodent and Termite Repellent	1	52.08
	508509	FLEXCORE800L15	Flexbus Conductor 800 mm ² , 15 Meters Long with Rodent and Termite Repellent	1	55.8
	508510	FLEXCORE800L16	Flexbus Conductor 800 mm ² , 16 Meters Long with Rodent and Termite Repellent	1	59.52
	508511	FLEXCORE800L17	Flexbus Conductor 800 mm ² , 17 Meters Long with Rodent and Termite Repellent	1	63.24
	508512	FLEXCORE800L18	Flexbus Conductor 800 mm ² , 18 Meters Long with Rodent and Termite Repellent	1	66.96
	508513	FLEXCORE800L19	Flexbus Conductor 800 mm ² , 19 Meters Long with Rodent and Termite Repellent	1	70.68
	508514	FLEXCORE800L20	Flexbus Conductor 800 mm ² , 20 Meters Long with Rodent and Termite Repellent	1	74.4
	508515	FLEXCORE800L21	Flexbus Conductor 800 mm ² , 21 Meters Long with Rodent and Termite Repellent	1	78.12
508516	FLEXCORE800L22	Flexbus Conductor 800 mm ² , 22 Meters Long with Rodent and Termite Repellent	1	81.84	
508517	FLEXCORE800L23	Flexbus Conductor 800 mm ² , 23 Meters Long with Rodent and Termite Repellent	1	85.56	
508518	FLEXCORE800L24	Flexbus Conductor 800 mm ² , 24 Meters Long with Rodent and Termite Repellent	1	89.28	
508519	FLEXCORE800L25	Flexbus Conductor 800 mm ² , 25 Meters Long with Rodent and Termite Repellent	1	93	

Part Numbers and Description



Flexbus Conductors with Rodent and Termite Repellent					
Cross Section	Part Number	Global Part Number	Description	Packing Unit pc	Weight kg
960 mm ²	508520	FLEXCORE960L2	Flexbus Conductor 960 mm ² , 2 Meters Long with Rodent and Termite Repellent	1	8.9
	508521	FLEXCORE960L3	Flexbus Conductor 960 mm ² , 3 Meters Long with Rodent and Termite Repellent	1	13.3
	508522	FLEXCORE960L4	Flexbus Conductor 960 mm ² , 4 Meters Long with Rodent and Termite Repellent	1	17.8
	508523	FLEXCORE960L5	Flexbus Conductor 960 mm ² , 5 Meters Long with Rodent and Termite Repellent	1	22.2
	508524	FLEXCORE960L6	Flexbus Conductor 960 mm ² , 6 Meters Long with Rodent and Termite Repellent	1	26.7
	508525	FLEXCORE960L7	Flexbus Conductor 960 mm ² , 7 Meters Long with Rodent and Termite Repellent	1	31.1
	508526	FLEXCORE960L8	Flexbus Conductor 960 mm ² , 8 Meters Long with Rodent and Termite Repellent	1	35.6
	508527	FLEXCORE960L9	Flexbus Conductor 960 mm ² , 9 Meters Long with Rodent and Termite Repellent	1	40
	508528	FLEXCORE960L10	Flexbus Conductor 960 mm ² , 10 Meters Long with Rodent and Termite Repellent	1	44.5
	508529	FLEXCORE960L11	Flexbus Conductor 960 mm ² , 11 Meters Long with Rodent and Termite Repellent	1	48.8
	508530	FLEXCORE960L12	Flexbus Conductor 960 mm ² , 12 Meters Long with Rodent and Termite Repellent	1	53.3
	508531	FLEXCORE960L13	Flexbus Conductor 960 mm ² , 13 Meters Long with Rodent and Termite Repellent	1	57.7
	508532	FLEXCORE960L14	Flexbus Conductor 960 mm ² , 14 Meters Long with Rodent and Termite Repellent	1	62.2
	508533	FLEXCORE960L15	Flexbus Conductor 960 mm ² , 15 Meters Long with Rodent and Termite Repellent	1	66.6
	508534	FLEXCORE960L16	Flexbus Conductor 960 mm ² , 16 Meters Long with Rodent and Termite Repellent	1	71
	508535	FLEXCORE960L17	Flexbus Conductor 960 mm ² , 17 Meters Long with Rodent and Termite Repellent	1	75.5
	508536	FLEXCORE960L18	Flexbus Conductor 960 mm ² , 18 Meters Long with Rodent and Termite Repellent	1	79.9
	508537	FLEXCORE960L19	Flexbus Conductor 960 mm ² , 19 Meters Long with Rodent and Termite Repellent	1	84.4
	508538	FLEXCORE960L20	Flexbus Conductor 960 mm ² , 20 Meters Long with Rodent and Termite Repellent	1	88.8
	508539	FLEXCORE960L21	Flexbus Conductor 960 mm ² , 21 Meters Long with Rodent and Termite Repellent	1	93.2
	508540	FLEXCORE960L22	Flexbus Conductor 960 mm ² , 22 Meters Long with Rodent and Termite Repellent	1	97.7
	508541	FLEXCORE960L23	Flexbus Conductor 960 mm ² , 23 Meters Long with Rodent and Termite Repellent	1	102.1
	508542	FLEXCORE960L24	Flexbus Conductor 960 mm ² , 24 Meters Long with Rodent and Termite Repellent	1	106.6
	508543	FLEXCORE960L25	Flexbus Conductor 960 mm ² , 25 Meters Long with Rodent and Termite Repellent	1	111

Part Numbers and Description

Flexbus Conductors with Rodent and Termite Repellent					
Cross Section	Part Number	Global Part Number	Description	Packing Unit pc	Weight kg
1280 mm ²	508544	FLEXCORE1280L2	Flexbus Conductor 1280 mm ² , 2 Meters Long with Rodent and Termite Repellent	1	11.4
	508545	FLEXCORE1280L3	Flexbus Conductor 1280 mm ² , 3 Meters Long with Rodent and Termite Repellent	1	17
	508546	FLEXCORE1280L4	Flexbus Conductor 1280 mm ² , 4 Meters Long with Rodent and Termite Repellent	1	22.7
	508547	FLEXCORE1280L5	Flexbus Conductor 1280 mm ² , 5 Meters Long with Rodent and Termite Repellent	1	28.4
	508548	FLEXCORE1280L6	Flexbus Conductor 1280 mm ² , 6 Meters Long with Rodent and Termite Repellent	1	34.1
	508549	FLEXCORE1280L7	Flexbus Conductor 1280 mm ² , 7 Meters Long with Rodent and Termite Repellent	1	39.7
	508550	FLEXCORE1280L8	Flexbus Conductor 1280 mm ² , 8 Meters Long with Rodent and Termite Repellent	1	45.4
	508551	FLEXCORE1280L9	Flexbus Conductor 1280 mm ² , 9 Meters Long with Rodent and Termite Repellent	1	51.1
	508552	FLEXCORE1280L10	Flexbus Conductor 1280 mm ² , 10 Meters Long with Rodent and Termite Repellent	1	56.8
	508553	FLEXCORE1280L11	Flexbus Conductor 1280 mm ² , 11 Meters Long with Rodent and Termite Repellent	1	62.2
	508554	FLEXCORE1280L12	Flexbus Conductor 1280 mm ² , 12 Meters Long with Rodent and Termite Repellent	1	67.8
	508555	FLEXCORE1280L13	Flexbus Conductor 1280 mm ² , 13 Meters Long with Rodent and Termite Repellent	1	73.5
	508556	FLEXCORE1280L14	Flexbus Conductor 1280 mm ² , 14 Meters Long with Rodent and Termite Repellent	1	79.1
	508557	FLEXCORE1280L15	Flexbus Conductor 1280 mm ² , 15 Meters Long with Rodent and Termite Repellent	1	84.8
	1810 mm ²	508558	FLEXCORE1810L2	Flexbus Conductor 1810 mm ² , 2 Meters Long with Rodent and Termite Repellent	1
508559		FLEXCORE1810L3	Flexbus Conductor 1810 mm ² , 3 Meters Long with Rodent and Termite Repellent	1	23.2
508560		FLEXCORE1810L4	Flexbus Conductor 1810 mm ² , 4 Meters Long with Rodent and Termite Repellent	1	31
508561		FLEXCORE1810L5	Flexbus Conductor 1810 mm ² , 5 Meters Long with Rodent and Termite Repellent	1	38.7
508562		FLEXCORE1810L6	Flexbus Conductor 1810 mm ² , 6 Meters Long with Rodent and Termite Repellent	1	46.4
508563		FLEXCORE1810L7	Flexbus Conductor 1810 mm ² , 7 Meters Long with Rodent and Termite Repellent	1	54.2
508564		FLEXCORE1810L8	Flexbus Conductor 1810 mm ² , 8 Meters Long with Rodent and Termite Repellent	1	61.9
508565		FLEXCORE1810L9	Flexbus Conductor 1810 mm ² , 9 Meters Long with Rodent and Termite Repellent	1	69.7
508566		FLEXCORE1810L10	Flexbus Conductor 1810 mm ² , 10 Meters Long with Rodent and Termite Repellent	1	77.4
508567		FLEXCORE1810L11	Flexbus Conductor 1810 mm ² , 11 Meters Long with Rodent and Termite Repellent	1	85

Part Numbers and Description

Flexbus Conductors with Rodent and Termite Repellent					
Cross Section	Part Number	Global Part Number	Description	Packing Unit pc	Weight kg
1810 mm ²	508568	FLEXCORE1810L12	Flexbus Conductor 1810 mm ² , 12 Meters Long with Rodent and Termite Repellent	1	92.8
	508569	FLEXCORE1810L13	Flexbus Conductor 1810 mm ² , 13 Meters Long with Rodent and Termite Repellent	1	100.5
	508570	FLEXCORE1810L14	Flexbus Conductor 1810 mm ² , 14 Meters Long with Rodent and Termite Repellent	1	108.2
	508571	FLEXCORE1810L15	Flexbus Conductor 1810 mm ² , 15 Meters Long with Rodent and Termite Repellent	1	116

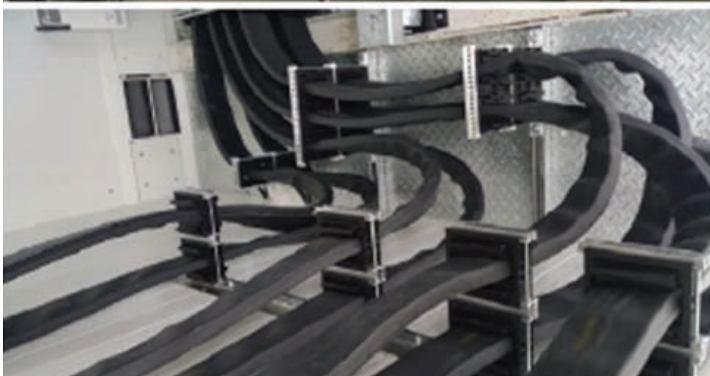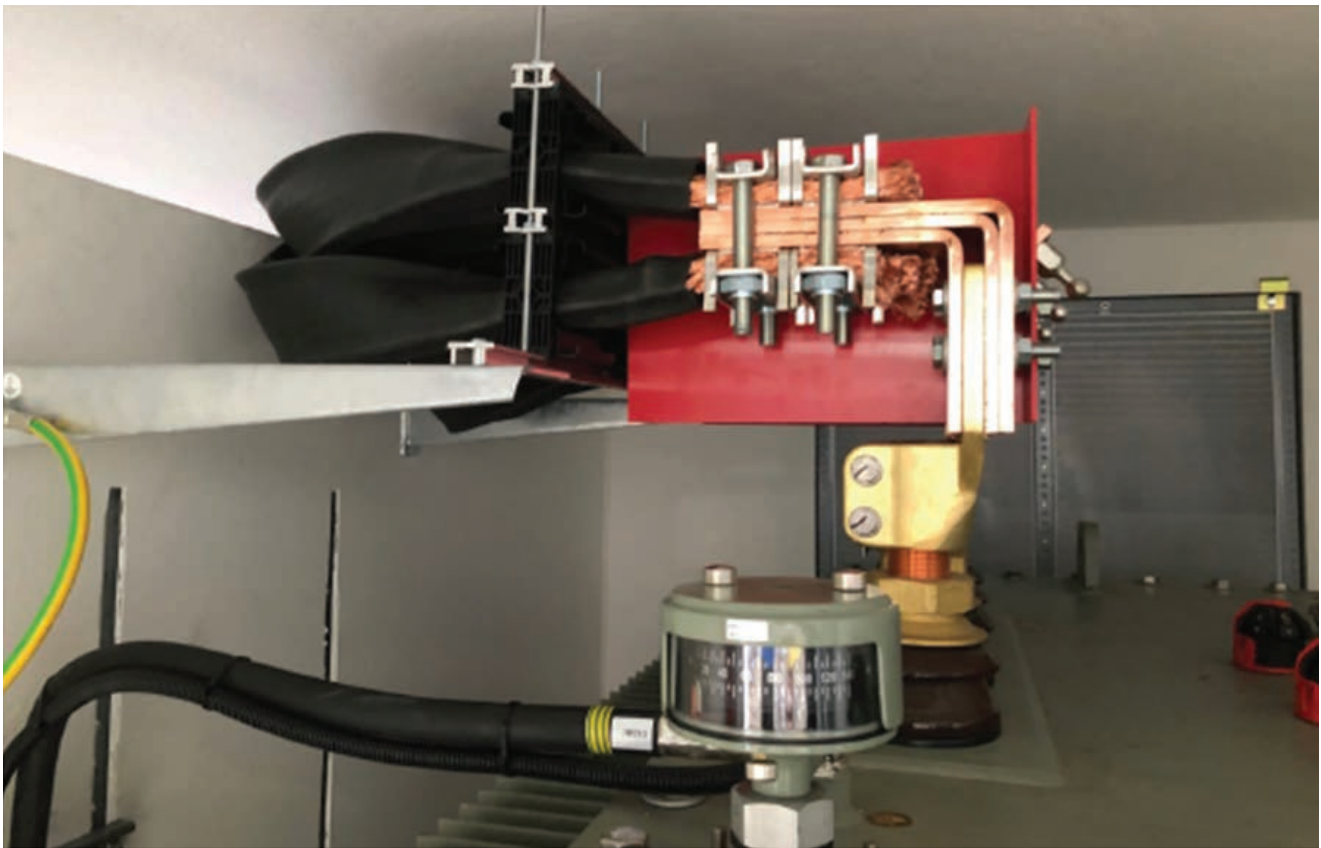

Cross Reference

Standard FleXbus Conductors VS Rodent and Termite Repellent Version

Standard FleXbus Conductors		FleXbus Conductors with Rodent and Termite Repellent	
Part Number	Description	Part Number	Description
508000	FleXbus Conductor 220 mm ² , 2 Meters Long	508400	FleXbus Conductor 220 mm ² , 2 Meters Long with Rodent and Termite Repellent
508001	FleXbus Conductor 220 mm ² , 3 Meters Long	508401	FleXbus Conductor 220 mm ² , 3 Meters Long with Rodent and Termite Repellent
508002	FleXbus Conductor 220 mm ² , 4 Meters Long	508402	FleXbus Conductor 220 mm ² , 4 Meters Long with Rodent and Termite Repellent
508003	FleXbus Conductor 220 mm ² , 5 Meters Long	508403	FleXbus Conductor 220 mm ² , 5 Meters Long with Rodent and Termite Repellent
508004	FleXbus Conductor 220 mm ² , 6 Meters Long	508404	FleXbus Conductor 220 mm ² , 6 Meters Long with Rodent and Termite Repellent
508005	FleXbus Conductor 220 mm ² , 7 Meters Long	508405	FleXbus Conductor 220 mm ² , 7 Meters Long with Rodent and Termite Repellent
508006	FleXbus Conductor 220 mm ² , 8 Meters Long	508406	FleXbus Conductor 220 mm ² , 8 Meters Long with Rodent and Termite Repellent
508007	FleXbus Conductor 220 mm ² , 9 Meters Long	508407	FleXbus Conductor 220 mm ² , 9 Meters Long with Rodent and Termite Repellent
508008	FleXbus Conductor 220 mm ² , 10 Meters Long	508408	FleXbus Conductor 220 mm ² , 10 Meters Long with Rodent and Termite Repellent
508210	FleXbus Conductor 220 mm ² , 11 Meters Long	508409	FleXbus Conductor 220 mm ² , 11 Meters Long with Rodent and Termite Repellent
508211	FleXbus Conductor 220 mm ² , 12 Meters Long	508410	FleXbus Conductor 220 mm ² , 12 Meters Long with Rodent and Termite Repellent
508212	FleXbus Conductor 220 mm ² , 13 Meters Long	508411	FleXbus Conductor 220 mm ² , 13 Meters Long with Rodent and Termite Repellent
508213	FleXbus Conductor 220 mm ² , 14 Meters Long	508412	FleXbus Conductor 220 mm ² , 14 Meters Long with Rodent and Termite Repellent
508214	FleXbus Conductor 220 mm ² , 15 Meters Long	508413	FleXbus Conductor 220 mm ² , 15 Meters Long with Rodent and Termite Repellent
508215	FleXbus Conductor 220 mm ² , 16 Meters Long	508414	FleXbus Conductor 220 mm ² , 16 Meters Long with Rodent and Termite Repellent
508216	FleXbus Conductor 220 mm ² , 17 Meters Long	508415	FleXbus Conductor 220 mm ² , 17 Meters Long with Rodent and Termite Repellent
508217	FleXbus Conductor 220 mm ² , 18 Meters Long	508416	FleXbus Conductor 220 mm ² , 18 Meters Long with Rodent and Termite Repellent
508218	FleXbus Conductor 220 mm ² , 19 Meters Long	508417	FleXbus Conductor 220 mm ² , 19 Meters Long with Rodent and Termite Repellent
508219	FleXbus Conductor 220 mm ² , 20 Meters Long	508418	FleXbus Conductor 220 mm ² , 20 Meters Long with Rodent and Termite Repellent
508220	FleXbus Conductor 220 mm ² , 21 Meters Long	508419	FleXbus Conductor 220 mm ² , 21 Meters Long with Rodent and Termite Repellent
508221	FleXbus Conductor 220 mm ² , 22 Meters Long	508420	FleXbus Conductor 220 mm ² , 22 Meters Long with Rodent and Termite Repellent
508222	FleXbus Conductor 220 mm ² , 23 Meters Long	508421	FleXbus Conductor 220 mm ² , 23 Meters Long with Rodent and Termite Repellent
508223	FleXbus Conductor 220 mm ² , 24 Meters Long	508422	FleXbus Conductor 220 mm ² , 24 Meters Long with Rodent and Termite Repellent
508224	FleXbus Conductor 220 mm ² , 25 Meters Long	508423	FleXbus Conductor 220 mm ² , 25 Meters Long with Rodent and Termite Repellent

Cross Reference

Standard FleXbus Conductors VS Rodent and Termite Repellent Version

Standard FleXbus Conductors		FleXbus Conductors with Rodent and Termite Repellent	
Part Number	Description	Part Number	Description
508010	FleXbus Conductor 360 mm ² , 2 Meters Long	508424	FleXbus Conductor 360 mm ² , 2 Meters Long with Rodent and Termite Repellent
508011	FleXbus Conductor 360 mm ² , 3 Meters Long	508425	FleXbus Conductor 360 mm ² , 3 Meters Long with Rodent and Termite Repellent
508012	FleXbus Conductor 360 mm ² , 4 Meters Long	508426	FleXbus Conductor 360 mm ² , 4 Meters Long with Rodent and Termite Repellent
508013	FleXbus Conductor 360 mm ² , 5 Meters Long	508427	FleXbus Conductor 360 mm ² , 5 Meters Long with Rodent and Termite Repellent
508014	FleXbus Conductor 360 mm ² , 6 Meters Long	508428	FleXbus Conductor 360 mm ² , 6 Meters Long with Rodent and Termite Repellent
508015	FleXbus Conductor 360 mm ² , 7 Meters Long	508429	FleXbus Conductor 360 mm ² , 7 Meters Long with Rodent and Termite Repellent
508016	FleXbus Conductor 360 mm ² , 8 Meters Long	508430	FleXbus Conductor 360 mm ² , 8 Meters Long with Rodent and Termite Repellent
508017	FleXbus Conductor 360 mm ² , 9 Meters Long	508431	FleXbus Conductor 360 mm ² , 9 Meters Long with Rodent and Termite Repellent
508018	FleXbus Conductor 360 mm ² , 10 Meters Long	508432	FleXbus Conductor 360 mm ² , 10 Meters Long with Rodent and Termite Repellent
508230	FleXbus Conductor 360 mm ² , 11 Meters Long	508433	FleXbus Conductor 360 mm ² , 11 Meters Long with Rodent and Termite Repellent
508231	FleXbus Conductor 360 mm ² , 12 Meters Long	508434	FleXbus Conductor 360 mm ² , 12 Meters Long with Rodent and Termite Repellent
508232	FleXbus Conductor 360 mm ² , 13 Meters Long	508435	FleXbus Conductor 360 mm ² , 13 Meters Long with Rodent and Termite Repellent
508233	FleXbus Conductor 360 mm ² , 14 Meters Long	508436	FleXbus Conductor 360 mm ² , 14 Meters Long with Rodent and Termite Repellent
508234	FleXbus Conductor 360 mm ² , 15 Meters Long	508437	FleXbus Conductor 360 mm ² , 15 Meters Long with Rodent and Termite Repellent
508235	FleXbus Conductor 360 mm ² , 16 Meters Long	508438	FleXbus Conductor 360 mm ² , 16 Meters Long with Rodent and Termite Repellent
508236	FleXbus Conductor 360 mm ² , 17 Meters Long	508439	FleXbus Conductor 360 mm ² , 17 Meters Long with Rodent and Termite Repellent
508237	FleXbus Conductor 360 mm ² , 18 Meters Long	508440	FleXbus Conductor 360 mm ² , 18 Meters Long with Rodent and Termite Repellent
508238	FleXbus Conductor 360 mm ² , 19 Meters Long	508441	FleXbus Conductor 360 mm ² , 19 Meters Long with Rodent and Termite Repellent
508239	FleXbus Conductor 360 mm ² , 20 Meters Long	508442	FleXbus Conductor 360 mm ² , 20 Meters Long with Rodent and Termite Repellent
508240	FleXbus Conductor 360 mm ² , 21 Meters Long	508443	FleXbus Conductor 360 mm ² , 21 Meters Long with Rodent and Termite Repellent
508241	FleXbus Conductor 360 mm ² , 22 Meters Long	508444	FleXbus Conductor 360 mm ² , 22 Meters Long with Rodent and Termite Repellent
508242	FleXbus Conductor 360 mm ² , 23 Meters Long	508445	FleXbus Conductor 360 mm ² , 23 Meters Long with Rodent and Termite Repellent
508243	FleXbus Conductor 360 mm ² , 24 Meters Long	508446	FleXbus Conductor 360 mm ² , 24 Meters Long with Rodent and Termite Repellent
508244	FleXbus Conductor 360 mm ² , 25 Meters Long	508447	FleXbus Conductor 360 mm ² , 25 Meters Long with Rodent and Termite Repellent

Cross Reference

Standard FleXbus Conductors VS Rodent and Termite Repellent Version

Standard FleXbus Conductors		FleXbus Conductors with Rodent and Termite Repellent	
Part Number	Description	Part Number	Description
508020	FleXbus Conductor 545 mm ² , 2 Meters Long	508448	FleXbus Conductor 545 mm ² , 2 Meters Long with Rodent and Termite Repellent
508021	FleXbus Conductor 545 mm ² , 3 Meters Long	508449	FleXbus Conductor 545 mm ² , 3 Meters Long with Rodent and Termite Repellent
508022	FleXbus Conductor 545 mm ² , 4 Meters Long	508450	FleXbus Conductor 545 mm ² , 4 Meters Long with Rodent and Termite Repellent
508023	FleXbus Conductor 545 mm ² , 5 Meters Long	508451	FleXbus Conductor 545 mm ² , 5 Meters Long with Rodent and Termite Repellent
508024	FleXbus Conductor 545 mm ² , 6 Meters Long	508452	FleXbus Conductor 545 mm ² , 6 Meters Long with Rodent and Termite Repellent
508025	FleXbus Conductor 545 mm ² , 7 Meters Long	508453	FleXbus Conductor 545 mm ² , 7 Meters Long with Rodent and Termite Repellent
508026	FleXbus Conductor 545 mm ² , 8 Meters Long	508454	FleXbus Conductor 545 mm ² , 8 Meters Long with Rodent and Termite Repellent
508027	FleXbus Conductor 545 mm ² , 9 Meters Long	508455	FleXbus Conductor 545 mm ² , 9 Meters Long with Rodent and Termite Repellent
508028	FleXbus Conductor 545 mm ² , 10 Meters Long	508456	FleXbus Conductor 545 mm ² , 10 Meters Long with Rodent and Termite Repellent
508250	FleXbus Conductor 545 mm ² , 11 Meters Long	508457	FleXbus Conductor 545 mm ² , 11 Meters Long with Rodent and Termite Repellent
508251	FleXbus Conductor 545 mm ² , 12 Meters Long	508458	FleXbus Conductor 545 mm ² , 12 Meters Long with Rodent and Termite Repellent
508252	FleXbus Conductor 545 mm ² , 13 Meters Long	508459	FleXbus Conductor 545 mm ² , 13 Meters Long with Rodent and Termite Repellent
508253	FleXbus Conductor 545 mm ² , 14 Meters Long	508460	FleXbus Conductor 545 mm ² , 14 Meters Long with Rodent and Termite Repellent
508254	FleXbus Conductor 545 mm ² , 15 Meters Long	508461	FleXbus Conductor 545 mm ² , 15 Meters Long with Rodent and Termite Repellent
508255	FleXbus Conductor 545 mm ² , 16 Meters Long	508462	FleXbus Conductor 545 mm ² , 16 Meters Long with Rodent and Termite Repellent
508256	FleXbus Conductor 545 mm ² , 17 Meters Long	508463	FleXbus Conductor 545 mm ² , 17 Meters Long with Rodent and Termite Repellent
508257	FleXbus Conductor 545 mm ² , 18 Meters Long	508464	FleXbus Conductor 545 mm ² , 18 Meters Long with Rodent and Termite Repellent
508258	FleXbus Conductor 545 mm ² , 19 Meters Long	508465	FleXbus Conductor 545 mm ² , 19 Meters Long with Rodent and Termite Repellent
508259	FleXbus Conductor 545 mm ² , 20 Meters Long	508466	FleXbus Conductor 545 mm ² , 20 Meters Long with Rodent and Termite Repellent
508260	FleXbus Conductor 545 mm ² , 21 Meters Long	508467	FleXbus Conductor 545 mm ² , 21 Meters Long with Rodent and Termite Repellent
508261	FleXbus Conductor 545 mm ² , 22 Meters Long	508468	FleXbus Conductor 545 mm ² , 22 Meters Long with Rodent and Termite Repellent
508262	FleXbus Conductor 545 mm ² , 23 Meters Long	508469	FleXbus Conductor 545 mm ² , 23 Meters Long with Rodent and Termite Repellent
508263	FleXbus Conductor 545 mm ² , 24 Meters Long	508470	FleXbus Conductor 545 mm ² , 24 Meters Long with Rodent and Termite Repellent
508264	FleXbus Conductor 545 mm ² , 25 Meters Long	508471	FleXbus Conductor 545 mm ² , 25 Meters Long with Rodent and Termite Repellent

Cross Reference

Standard FleXbus Conductors VS Rodent and Termite Repellent Version

Standard FleXbus Conductors		FleXbus Conductors with Rodent and Termite Repellent	
Part Number	Description	Part Number	Description
508030	FleXbus Conductor 640 mm ² , 2 Meters Long	508472	FleXbus Conductor 640 mm ² , 2 Meters Long with Rodent and Termite Repellent
508031	FleXbus Conductor 640 mm ² , 3 Meters Long	508473	FleXbus Conductor 640 mm ² , 3 Meters Long with Rodent and Termite Repellent
508032	FleXbus Conductor 640 mm ² , 4 Meters Long	508474	FleXbus Conductor 640 mm ² , 4 Meters Long with Rodent and Termite Repellent
508033	FleXbus Conductor 640 mm ² , 5 Meters Long	508475	FleXbus Conductor 640 mm ² , 5 Meters Long with Rodent and Termite Repellent
508034	FleXbus Conductor 640 mm ² , 6 Meters Long	508476	FleXbus Conductor 640 mm ² , 6 Meters Long with Rodent and Termite Repellent
508035	FleXbus Conductor 640 mm ² , 7 Meters Long	508477	FleXbus Conductor 640 mm ² , 7 Meters Long with Rodent and Termite Repellent
508036	FleXbus Conductor 640 mm ² , 8 Meters Long	508478	FleXbus Conductor 640 mm ² , 8 Meters Long with Rodent and Termite Repellent
508037	FleXbus Conductor 640 mm ² , 9 Meters Long	508479	FleXbus Conductor 640 mm ² , 9 Meters Long with Rodent and Termite Repellent
508038	FleXbus Conductor 640 mm ² , 10 Meters Long	508480	FleXbus Conductor 640 mm ² , 10 Meters Long with Rodent and Termite Repellent
508270	FleXbus Conductor 640 mm ² , 11 Meters Long	508481	FleXbus Conductor 640 mm ² , 11 Meters Long with Rodent and Termite Repellent
508271	FleXbus Conductor 640 mm ² , 12 Meters Long	508482	FleXbus Conductor 640 mm ² , 12 Meters Long with Rodent and Termite Repellent
508272	FleXbus Conductor 640 mm ² , 13 Meters Long	508483	FleXbus Conductor 640 mm ² , 13 Meters Long with Rodent and Termite Repellent
508273	FleXbus Conductor 640 mm ² , 14 Meters Long	508484	FleXbus Conductor 640 mm ² , 14 Meters Long with Rodent and Termite Repellent
508274	FleXbus Conductor 640 mm ² , 15 Meters Long	508485	FleXbus Conductor 640 mm ² , 15 Meters Long with Rodent and Termite Repellent
508275	FleXbus Conductor 640 mm ² , 16 Meters Long	508486	FleXbus Conductor 640 mm ² , 16 Meters Long with Rodent and Termite Repellent
508276	FleXbus Conductor 640 mm ² , 17 Meters Long	508487	FleXbus Conductor 640 mm ² , 17 Meters Long with Rodent and Termite Repellent
508277	FleXbus Conductor 640 mm ² , 18 Meters Long	508488	FleXbus Conductor 640 mm ² , 18 Meters Long with Rodent and Termite Repellent
508278	FleXbus Conductor 640 mm ² , 19 Meters Long	508489	FleXbus Conductor 640 mm ² , 19 Meters Long with Rodent and Termite Repellent
508279	FleXbus Conductor 640 mm ² , 20 Meters Long	508490	FleXbus Conductor 640 mm ² , 20 Meters Long with Rodent and Termite Repellent
508280	FleXbus Conductor 640 mm ² , 21 Meters Long	508491	FleXbus Conductor 640 mm ² , 21 Meters Long with Rodent and Termite Repellent
508281	FleXbus Conductor 640 mm ² , 22 Meters Long	508492	FleXbus Conductor 640 mm ² , 22 Meters Long with Rodent and Termite Repellent
508282	FleXbus Conductor 640 mm ² , 23 Meters Long	508493	FleXbus Conductor 640 mm ² , 23 Meters Long with Rodent and Termite Repellent
508283	FleXbus Conductor 640 mm ² , 24 Meters Long	508494	FleXbus Conductor 640 mm ² , 24 Meters Long with Rodent and Termite Repellent
508284	FleXbus Conductor 640 mm ² , 25 Meters Long	508495	FleXbus Conductor 640 mm ² , 25 Meters Long with Rodent and Termite Repellent

Cross Reference

Standard FleXbus Conductors VS Rodent and Termite Repellent Version

Standard FleXbus Conductors		FleXbus Conductors with Rodent and Termite Repellent	
Part Number	Description	Part Number	Description
508330	FleXbus Conductor 800 mm ² , 2 Meters Long	508496	FleXbus Conductor 800 mm ² , 2 Meters Long with Rodent and Termite Repellent
508331	FleXbus Conductor 800 mm ² , 3 Meters Long	508497	FleXbus Conductor 800 mm ² , 3 Meters Long with Rodent and Termite Repellent
508332	FleXbus Conductor 800 mm ² , 4 Meters Long	508498	FleXbus Conductor 800 mm ² , 4 Meters Long with Rodent and Termite Repellent
508333	FleXbus Conductor 800 mm ² , 5 Meters Long	508499	FleXbus Conductor 800 mm ² , 5 Meters Long with Rodent and Termite Repellent
508334	FleXbus Conductor 800 mm ² , 6 Meters Long	508500	FleXbus Conductor 800 mm ² , 6 Meters Long with Rodent and Termite Repellent
508335	FleXbus Conductor 800 mm ² , 7 Meters Long	508501	FleXbus Conductor 800 mm ² , 7 Meters Long with Rodent and Termite Repellent
508336	FleXbus Conductor 800 mm ² , 8 Meters Long	508502	FleXbus Conductor 800 mm ² , 8 Meters Long with Rodent and Termite Repellent
508337	FleXbus Conductor 800 mm ² , 9 Meters Long	508503	FleXbus Conductor 800 mm ² , 9 Meters Long with Rodent and Termite Repellent
508338	FleXbus Conductor 800 mm ² , 10 Meters Long	508504	FleXbus Conductor 800 mm ² , 10 Meters Long with Rodent and Termite Repellent
508339	FleXbus Conductor 800 mm ² , 11 Meters Long	508505	FleXbus Conductor 800 mm ² , 11 Meters Long with Rodent and Termite Repellent
508340	FleXbus Conductor 800 mm ² , 12 Meters Long	508506	FleXbus Conductor 800 mm ² , 12 Meters Long with Rodent and Termite Repellent
508341	FleXbus Conductor 800 mm ² , 13 Meters Long	508507	FleXbus Conductor 800 mm ² , 13 Meters Long with Rodent and Termite Repellent
508342	FleXbus Conductor 800 mm ² , 14 Meters Long	508508	FleXbus Conductor 800 mm ² , 14 Meters Long with Rodent and Termite Repellent
508343	FleXbus Conductor 800 mm ² , 15 Meters Long	508509	FleXbus Conductor 800 mm ² , 15 Meters Long with Rodent and Termite Repellent
508344	FleXbus Conductor 800 mm ² , 16 Meters Long	508510	FleXbus Conductor 800 mm ² , 16 Meters Long with Rodent and Termite Repellent
508345	FleXbus Conductor 800 mm ² , 17 Meters Long	508511	FleXbus Conductor 800 mm ² , 17 Meters Long with Rodent and Termite Repellent
508346	FleXbus Conductor 800 mm ² , 18 Meters Long	508512	FleXbus Conductor 800 mm ² , 18 Meters Long with Rodent and Termite Repellent
508347	FleXbus Conductor 800 mm ² , 19 Meters Long	508513	FleXbus Conductor 800 mm ² , 19 Meters Long with Rodent and Termite Repellent
508348	FleXbus Conductor 800 mm ² , 20 Meters Long	508514	FleXbus Conductor 800 mm ² , 20 Meters Long with Rodent and Termite Repellent
508349	FleXbus Conductor 800 mm ² , 21 Meters Long	508515	FleXbus Conductor 800 mm ² , 21 Meters Long with Rodent and Termite Repellent
508350	FleXbus Conductor 800 mm ² , 22 Meters Long	508516	FleXbus Conductor 800 mm ² , 22 Meters Long with Rodent and Termite Repellent
508351	FleXbus Conductor 800 mm ² , 23 Meters Long	508517	FleXbus Conductor 800 mm ² , 23 Meters Long with Rodent and Termite Repellent
508352	FleXbus Conductor 800 mm ² , 24 Meters Long	508518	FleXbus Conductor 800 mm ² , 24 Meters Long with Rodent and Termite Repellent
508353	FleXbus Conductor 800 mm ² , 25 Meters Long	508519	FleXbus Conductor 800 mm ² , 25 Meters Long with Rodent and Termite Repellent

Cross Reference

Standard FleXbus Conductors VS Rodent and Termite Repellent Version

Standard FleXbus Conductors		FleXbus Conductors with Rodent and Termite Repellent	
Part Number	Description	Part Number	Description
508040	FleXbus Conductor 960 mm ² , 2 Meters Long	508520	FleXbus Conductor 960 mm ² , 2 Meters Long with Rodent and Termite Repellent
508041	FleXbus Conductor 960 mm ² , 3 Meters Long	508521	FleXbus Conductor 960 mm ² , 3 Meters Long with Rodent and Termite Repellent
508042	FleXbus Conductor 960 mm ² , 4 Meters Long	508522	FleXbus Conductor 960 mm ² , 4 Meters Long with Rodent and Termite Repellent
508043	FleXbus Conductor 960 mm ² , 5 Meters Long	508523	FleXbus Conductor 960 mm ² , 5 Meters Long with Rodent and Termite Repellent
508044	FleXbus Conductor 960 mm ² , 6 Meters Long	508524	FleXbus Conductor 960 mm ² , 6 Meters Long with Rodent and Termite Repellent
508045	FleXbus Conductor 960 mm ² , 7 Meters Long	508525	FleXbus Conductor 960 mm ² , 7 Meters Long with Rodent and Termite Repellent
508046	FleXbus Conductor 960 mm ² , 8 Meters Long	508526	FleXbus Conductor 960 mm ² , 8 Meters Long with Rodent and Termite Repellent
508047	FleXbus Conductor 960 mm ² , 9 Meters Long	508527	FleXbus Conductor 960 mm ² , 9 Meters Long with Rodent and Termite Repellent
508048	FleXbus Conductor 960 mm ² , 10 Meters Long	508528	FleXbus Conductor 960 mm ² , 10 Meters Long with Rodent and Termite Repellent
508290	FleXbus Conductor 960 mm ² , 11 Meters Long	508529	FleXbus Conductor 960 mm ² , 11 Meters Long with Rodent and Termite Repellent
508291	FleXbus Conductor 960 mm ² , 12 Meters Long	508530	FleXbus Conductor 960 mm ² , 12 Meters Long with Rodent and Termite Repellent
508292	FleXbus Conductor 960 mm ² , 13 Meters Long	508531	FleXbus Conductor 960 mm ² , 13 Meters Long with Rodent and Termite Repellent
508293	FleXbus Conductor 960 mm ² , 14 Meters Long	508532	FleXbus Conductor 960 mm ² , 14 Meters Long with Rodent and Termite Repellent
508294	FleXbus Conductor 960 mm ² , 15 Meters Long	508533	FleXbus Conductor 960 mm ² , 15 Meters Long with Rodent and Termite Repellent
508295	FleXbus Conductor 960 mm ² , 16 Meters Long	508534	FleXbus Conductor 960 mm ² , 16 Meters Long with Rodent and Termite Repellent
508296	FleXbus Conductor 960 mm ² , 17 Meters Long	508535	FleXbus Conductor 960 mm ² , 17 Meters Long with Rodent and Termite Repellent
508297	FleXbus Conductor 960 mm ² , 18 Meters Long	508536	FleXbus Conductor 960 mm ² , 18 Meters Long with Rodent and Termite Repellent
508298	FleXbus Conductor 960 mm ² , 19 Meters Long	508537	FleXbus Conductor 960 mm ² , 19 Meters Long with Rodent and Termite Repellent
508299	FleXbus Conductor 960 mm ² , 20 Meters Long	508538	FleXbus Conductor 960 mm ² , 20 Meters Long with Rodent and Termite Repellent
508300	FleXbus Conductor 960 mm ² , 21 Meters Long	508539	FleXbus Conductor 960 mm ² , 21 Meters Long with Rodent and Termite Repellent
508301	FleXbus Conductor 960 mm ² , 22 Meters Long	508540	FleXbus Conductor 960 mm ² , 22 Meters Long with Rodent and Termite Repellent
508302	FleXbus Conductor 960 mm ² , 23 Meters Long	508541	FleXbus Conductor 960 mm ² , 23 Meters Long with Rodent and Termite Repellent
508303	FleXbus Conductor 960 mm ² , 24 Meters Long	508542	FleXbus Conductor 960 mm ² , 24 Meters Long with Rodent and Termite Repellent
508304	FleXbus Conductor 960 mm ² , 25 Meters Long	508543	FleXbus Conductor 960 mm ² , 25 Meters Long with Rodent and Termite Repellent

Cross Reference

Standard FleXbus Conductors VS Rodent and Termite Repellent Version


Standard FleXbus Conductors		FleXbus Conductors with Rodent and Termite Repellent	
Part Number	Description	Part Number	Description
508050	FleXbus Conductor 1280 mm ² , 2 Meters Long	508544	FleXbus Conductor 1280 mm ² , 2 Meters Long with Rodent and Termite Repellent
508051	FleXbus Conductor 1280 mm ² , 3 Meters Long	508545	FleXbus Conductor 1280 mm ² , 3 Meters Long with Rodent and Termite Repellent
508052	FleXbus Conductor 1280 mm ² , 4 Meters Long	508546	FleXbus Conductor 1280 mm ² , 4 Meters Long with Rodent and Termite Repellent
508053	FleXbus Conductor 1280 mm ² , 5 Meters Long	508547	FleXbus Conductor 1280 mm ² , 5 Meters Long with Rodent and Termite Repellent
508054	FleXbus Conductor 1280 mm ² , 6 Meters Long	508548	FleXbus Conductor 1280 mm ² , 6 Meters Long with Rodent and Termite Repellent
508055	FleXbus Conductor 1280 mm ² , 7 Meters Long	508549	FleXbus Conductor 1280 mm ² , 7 Meters Long with Rodent and Termite Repellent
508056	FleXbus Conductor 1280 mm ² , 8 Meters Long	508550	FleXbus Conductor 1280 mm ² , 8 Meters Long with Rodent and Termite Repellent
508057	FleXbus Conductor 1280 mm ² , 9 Meters Long	508551	FleXbus Conductor 1280 mm ² , 9 Meters Long with Rodent and Termite Repellent
508058	FleXbus Conductor 1280 mm ² , 10 Meters Long	508552	FleXbus Conductor 1280 mm ² , 10 Meters Long with Rodent and Termite Repellent
508310	FleXbus Conductor 1280 mm ² , 11 Meters Long	508553	FleXbus Conductor 1280 mm ² , 11 Meters Long with Rodent and Termite Repellent
508311	FleXbus Conductor 1280 mm ² , 12 Meters Long	508554	FleXbus Conductor 1280 mm ² , 12 Meters Long with Rodent and Termite Repellent
508312	FleXbus Conductor 1280 mm ² , 13 Meters Long	508555	FleXbus Conductor 1280 mm ² , 13 Meters Long with Rodent and Termite Repellent
508313	FleXbus Conductor 1280 mm ² , 14 Meters Long	508556	FleXbus Conductor 1280 mm ² , 14 Meters Long with Rodent and Termite Repellent
508314	FleXbus Conductor 1280 mm ² , 15 Meters Long	508557	FleXbus Conductor 1280 mm ² , 15 Meters Long with Rodent and Termite Repellent
508060	FleXbus Conductor 1810 mm ² , 2 Meters Long	508558	FleXbus Conductor 1810 mm ² , 2 Meters Long with Rodent and Termite Repellent
508061	FleXbus Conductor 1810 mm ² , 3 Meters Long	508559	FleXbus Conductor 1810 mm ² , 3 Meters Long with Rodent and Termite Repellent
508062	FleXbus Conductor 1810 mm ² , 4 Meters Long	508560	FleXbus Conductor 1810 mm ² , 4 Meters Long with Rodent and Termite Repellent
508063	FleXbus Conductor 1810 mm ² , 5 Meters Long	508561	FleXbus Conductor 1810 mm ² , 5 Meters Long with Rodent and Termite Repellent
508064	FleXbus Conductor 1810 mm ² , 6 Meters Long	508562	FleXbus Conductor 1810 mm ² , 6 Meters Long with Rodent and Termite Repellent
508065	FleXbus Conductor 1810 mm ² , 7 Meters Long	508563	FleXbus Conductor 1810 mm ² , 7 Meters Long with Rodent and Termite Repellent
508066	FleXbus Conductor 1810 mm ² , 8 Meters Long	508564	FleXbus Conductor 1810 mm ² , 8 Meters Long with Rodent and Termite Repellent
508067	FleXbus Conductor 1810 mm ² , 9 Meters Long	508565	FleXbus Conductor 1810 mm ² , 9 Meters Long with Rodent and Termite Repellent
508068	FleXbus Conductor 1810 mm ² , 10 Meters Long	508566	FleXbus Conductor 1810 mm ² , 10 Meters Long with Rodent and Termite Repellent
508320	FleXbus Conductor 1810 mm ² , 11 Meters Long	508567	FleXbus Conductor 1810 mm ² , 11 Meters Long with Rodent and Termite Repellent

Cross Reference

Standard FleXbus Conductors VS Rodent and Termite Repellent Version

Standard FleXbus Conductors		FleXbus Conductors with Rodent and Termite Repellent	
Part Number	Description	Part Number	Description
508321	FleXbus Conductor 1810 mm ² , 12 Meters Long	508568	FleXbus Conductor 1810 mm ² , 12 Meters Long with Rodent and Termite Repellent
508322	FleXbus Conductor 1810 mm ² , 13 Meters Long	508569	FleXbus Conductor 1810 mm ² , 13 Meters Long with Rodent and Termite Repellent
508323	FleXbus Conductor 1810 mm ² , 14 Meters Long	508570	FleXbus Conductor 1810 mm ² , 14 Meters Long with Rodent and Termite Repellent
508324	FleXbus Conductor 1810 mm ² , 15 Meter sLong	508571	FleXbus Conductor 1810 mm ² , 15 Meters Long with Rodent and Termite Repellent



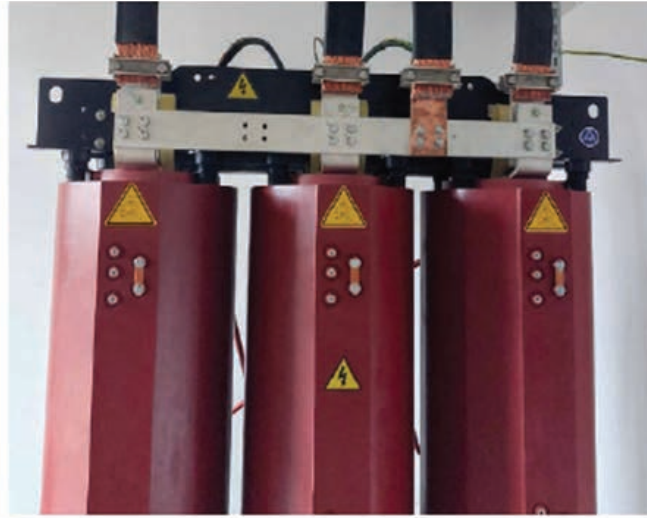

More Technical Information

 
All other technical data is consistent across the entire Flexbus conductor range.

Please download our comprehensive nVent ERIFLEX Flexbus Catalogue and Technical Guide:

- [English](#)
- [French](#)

- [German](#)
- [Italian](#)

- [Spanish](#)
- [Dutch](#)





nVent.com



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO RAYCHEM SCHROFF