

nVent CADDY CAT32HP J-Hook

Features Guide




ROBUST CONSTRUCTION

- Class leading load capacity
- UL2239 – 60 lbs
- Design feature for simple field configurations, UL listed



CABLE SUPPORT & PROTECTION

- Generous bend radius
- Meets latest TIA-568 requirements
- Future proof installations for ultra-high speed and PoE

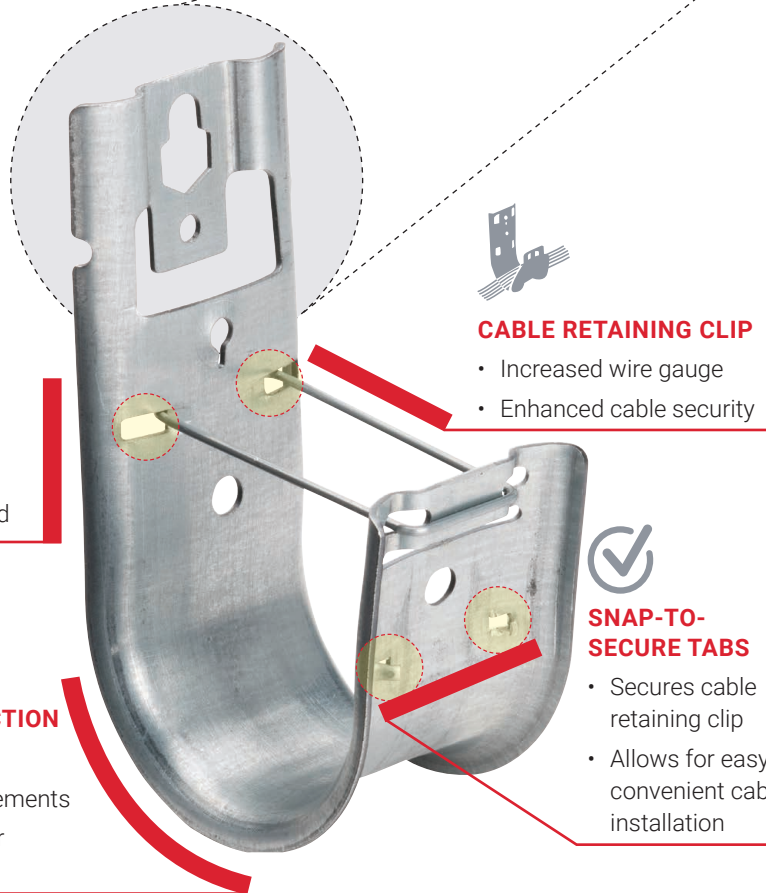

CABLE RETAINING CLIP

- Increased wire gauge
- Enhanced cable security




SNAP-TO-SECURE TABS

- Secures cable retaining clip
- Allows for easy, convenient cable installation

VERSA-MOUNT TECHNOLOGY

The nVent CADDY J-Hook Versa-Mount Technology is an innovative attachment design that provides multiple structural and installation methods for wall, ceiling, and threaded rod mounting applications.

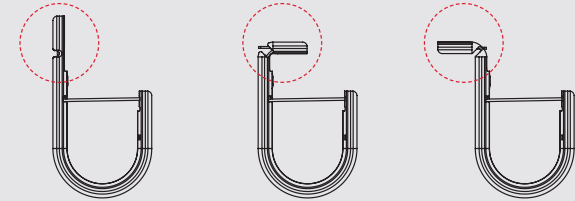

Wall mount:

- Flat flush mount allows for no gap between wall upon install
- Hex feature allows for pre-installed fastener
- Allows for multiple types of hardware, including shot fire



Threaded rod mount:

- 1/4" & 3/8"
- Quickly and easily bend hook for field install
- Use SN25 or SN38 for quick, simple securement to threaded rod



Ceiling/deck mount:

- Use commercially available shot fire (pins not included)
- Pin geometry minimizes prying effect during cable installation
- Quickly and easily bend hook for field install



CONNECT AND PROTECT

[nVent.com/CADDY](https://www.nVent.com/CADDY)

©2022 nVent. All nVent marks and logos are owned or licensed by nVent Services GmbH or its affiliates. All other trademarks are the property of their respective owners. nVent reserves the right to change specifications without notice.

CADDY-FLY-H88595-CAT32HPJHook-USEN-2210

