



nVent CADDY Flexible Conduit Connector

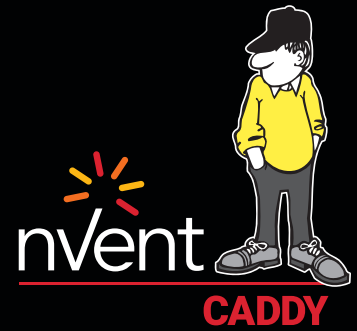

CONNECT AND PROTECT

The nVent CADDY Flexible Conduit Connectors are a tool-free line of connectors built to accommodate a wide range of flexible conduit (14/2 and 10/2). Designed to form an easy, secure, snap-in connection, the connectors also provide the option for a quick, damage-free removal by simply depressing the side tab. Conduit can be removed without harm by simply rotating the connector. In addition, the unique three-prong design assists in keeping the cable secure to reduce the risk of accidental disconnection or pullout.

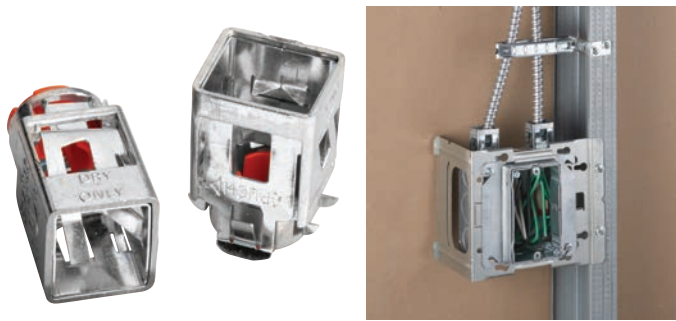


FEATURES

- Innovative snap-in style design makes installing fitting to ½" box knockout fast and easy
- Fitting can be easily removed by pressing tabs to release from box
- Conduit smoothly pushes into connector
- Features ability to remove cables damage-free by simply twisting the fitting off cables
- No tools required for installation
- Polycarbonate insulated throat
- Designed for AC, MCI-A, HCF steel and aluminum cable, flexible metal conduit steel and aluminum, MCI Cable, and continuous corrugated aluminum

Material: Steel; Spring Steel



Part Number	Knockout Sizes	Diameter Ø	Length L	Width W	Height H
EZF1410	½"	0.37"	1.54"	1"	0.86"

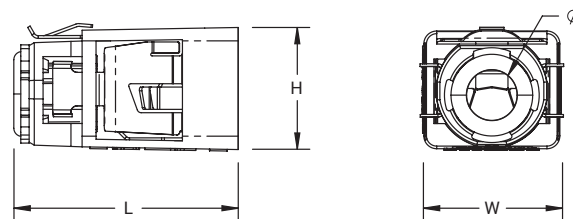

Our powerful portfolio of brands:

CADDY ERICO HOFFMAN RAYCHEM SCHROFF TRACER

©2023 nVent. All nVent marks and logos are owned or licensed by nVent Services GmbH or its affiliates. All other trademarks are the property of their respective owners. nVent reserves the right to change specifications without notice.

CADDY-DS-H88612-EZF1410-USEN-2307

nVent.com/CADDY