


Telescoping Plumbing Bracket



CONNECT AND PROTECT

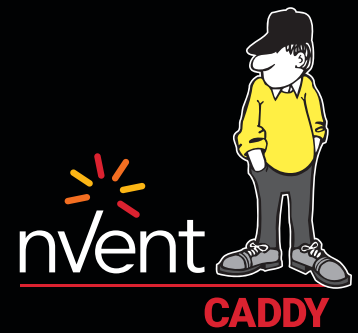

FEATURES

- Notched and marked for easy identification and bending
- Adjustable for non-standard stud spacing
- Interlocking tab prevents accidental disassembly
- Can be mounted at multiple depths to face or inside of stud
- Additional pilot holes in bracket allow for easy attachment utilizing multiple standard solutions
- Increased rigidity for heavier-duty plumbing applications
- Requires only a screw gun to install

Material: Steel
Finish: Pregalvanized

Part Number	Stud Spacing	Standard Packaging Quantity
TPB1624	15 3/4" – 25"	50 pc

Bend Lines	
Center of Stud	1 13/16"
In Stud Cavity	2 1/2"
Back of Stud	3 1/4"



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN RAYCHEM SCHROFF TRACER

©2022 nVent. All nVent marks and logos are owned or licensed by nVent Services GmbH or its affiliates. All other trademarks are the property of their respective owners. nVent reserves the right to change specifications without notice.

CADDY-DS-H88797-TPB1624-USEN-2212

[nVent.com/CADDY](https://www.nVent.com/CADDY)