



# Improved nVent CADDY B18 Combination Box/Conduit Hanger

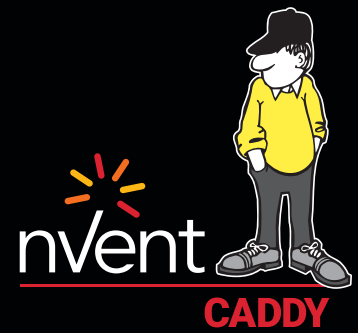

CONNECT AND PROTECT

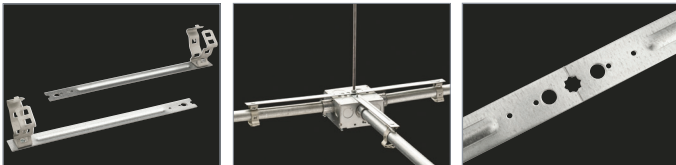

The Improved nVent CADDY B18 Combination Box/Conduit Hanger presents an efficient and secure solution for the installation of electrical boxes and conduit in overhead applications by streamlining the process with a single-threaded rod drop.

The system is designed to provide greater efficiency in the field with our class-leading range of nVent CADDY Conduit Clamps.

## FEATURES


- Scoreline breakaway feature can be easily modified by hand while maintaining UL listing
- Eliminates need for offset bending conduit
- Labor and time savings due to built-in first means of support
- NEC® & CEC compliant

Material: Steel, Spring Steel  
Finish: Pregalvanized; nVent CADDY Armour



Part Number	Flexible Conduit Size	MC/AC Cable Size	EMT Conduit Size	Hole Size HS	Hole Type	Screw Included	Screw Length	Screw Diameter Sc	Width W	Length L
812MB18S			1/2", 3/4"			Yes	9/16"	1/4"	2.1"	18"
812MB18A			1/2", 3/4"	1/4"	Plain	No			2.1"	18"
16MB18A			3/4", 1"	1/4"	Plain	No			2.1"	18"
6MB18A	3/8"	14-2 to 12-3		1/4"	Plain	No			2.1"	18"

NEC® 300.11 requires dedicated drop wire/rod. For single and multiple runs of conduit.

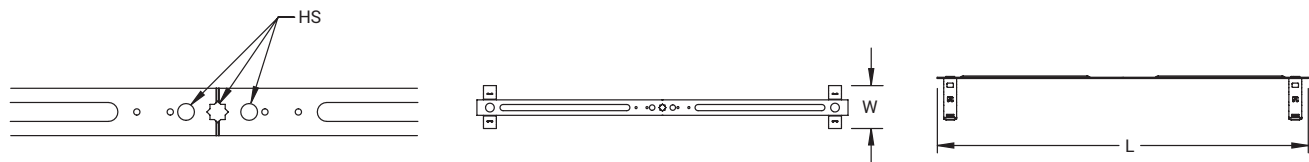

Our powerful portfolio of brands:

CADDY ERICO HOFFMAN RAYCHEM SCHROFF TRACER