


# nVent ERICO Fence/Pipe/Pedestal Clamp

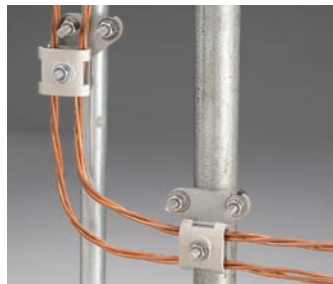

CONNECT AND PROTECT

The nVent ERICO line of dual conductor clamps offers a full range of grounding products for fence, pipe and pedestal applications ranging from 0.5" – 1.25" diameters. The clamps feature a swing-in U-bolt design to save installers time on the job and are made of a tin-plated, copper composition which ensures a reliable, high-quality connection for every application. Each clamp carries the same wide conductor range of #6 – #2 AWG to allow for versatility during installation and reduce the need for additional on-site inventory. The entire nVent ERICO line of fence, pipe and pedestal clamps has been rigorously tested to ensure connection strength and current carrying capabilities.



## FEATURES

- Composed of electro, tin-plated copper with stainless steel hardware
- Cross-directional feature designed for vertical or horizontal grids
- Swing-in design allows for easy installation with no loose hardware
- Suitable for direct burial in concrete or earth
- Appropriate for use with one or two conductors

Material: Tinned Copper, Stainless Steel 304 (EN 1.4301)  
Direct Burial: Yes



Part Number	Conductor Size	Number of Conductors	Pipe Size, Nominal	Thread Size	Outer Diameter	Length	Width	Height	Unit Weight
EFC050075	#6 Solid/Stranded – #2 Stranded	2	0.5 – 0.75"	5/16" UNC	0.375" – 1"	2.652"	2.58"	3.85"	0.621 lb
EFC100125	#6 Solid/Stranded – #2 Stranded	2	1 – 1.25"	5/16" UNC	0.9" – 1.7"	2.651"	2.9"	3.85"	0.665 lb



Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN ILSCO RAYCHEM SCHROFF**