


Improved nVent CADDY Cat HP Mod Clip to Hammer-On Flange

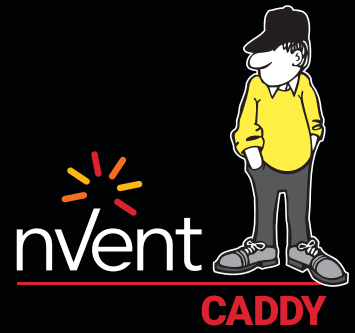


CONNECT AND PROTECT




Improved nVent CADDY Cat HP Mod Clip to Flange features two locking tabs that offer a secure hold—boosting both stability and flexibility on-site when installing nVent CADDY Cat HP J-Hooks. By eliminating the need for screws, rivets or special tools, both installation time and cost are reduced. Our innovative nVent CADDY J-Hook Versa-Mount Technology is compatible with the nVent CADDY Cat HP Mod Clip to Flange, allowing for multiple structural and installation methods for wall, ceiling and threaded rod mounting applications due to its unique attachment design.

- Link J-Hooks to multiple color options, aiding in pathway identification and organization

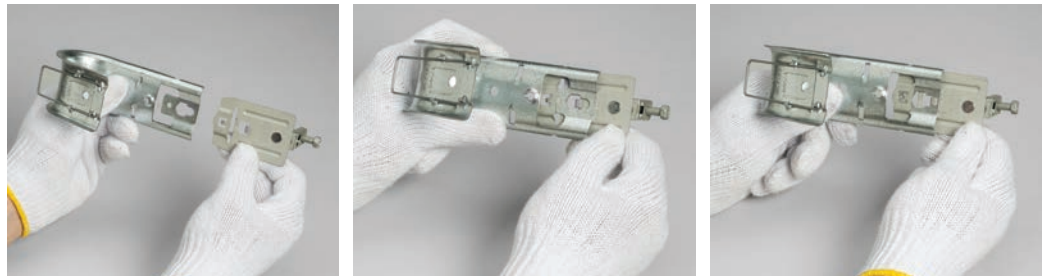

IMPROVED NVENT CADDY CAT HP J-HOOK MOD CLIP WITH HAMMER-ON FLANGE CLIP

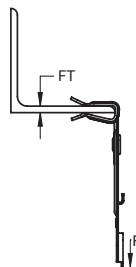

Features


- Requires only a hammer to install
- Works with nVent CADDY J-Hook Versa-Mount Technology

Material: Spring Steel
Finish: nVent CADDY Armour



Part Number	Flange Thickness FT	Static Load F
CATHPM24SM	0.125" - 0.25"	200 lb
CATHPM58SM	0.3" - 0.5"	200 lb
CATHPM912SM	0.5" - 0.75"	200 lb

IMPROVED nVENT CADDY CAT HP J-HOOK MOD CLIP WITH HAMMER-ON FLANGE CLIP, SWIVEL

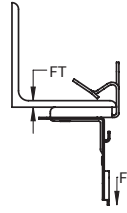

Features

- Requires only a hammer to install
- Two tabs lock onto nVent CADDY Cat HP components to provide rigidity and stability
- Works with nVent CADDY J-Hook Versa-Mount Technology

Material: Spring Steel
Finish: nVent CADDY Armour



Part Number	Flange Thickness FT	Static Load F
CATHPM24	0.125" - 0.25"	75 lb
CATHPM58	0.3" - 0.5"	75 lb
CATHPM912	0.5" - 0.75"	75 lb



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN RAYCHEM SCHROFF TRACER