


# Improved nVent CADDY Cat HP Mod Clip Brackets

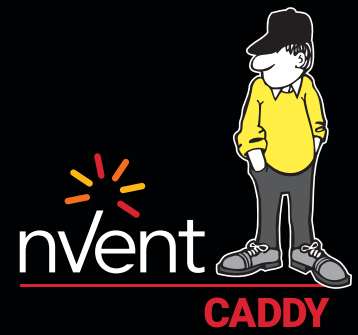


## CONNECT AND PROTECT





Improved nVent CADDY Cat HP Mod Clip Brackets simplify cable management and offer both stability and flexibility during installation. Our bracket design allows users to modify the clip by using just a nut and bolt to add an attachment of choice. By eliminating the need for screws, rivets or special tools, both installation time and cost are reduced. Our innovative nVent CADDY J-Hook Versa-Mount Technology is compatible with the nVent CADDY Cat HP Mod Clip Brackets, allowing for multiple structural and installation methods for wall, ceiling and threaded rod mounting applications due to its unique attachment design.

- Link J-Hooks to multiple color options, aiding in pathway identification and organization

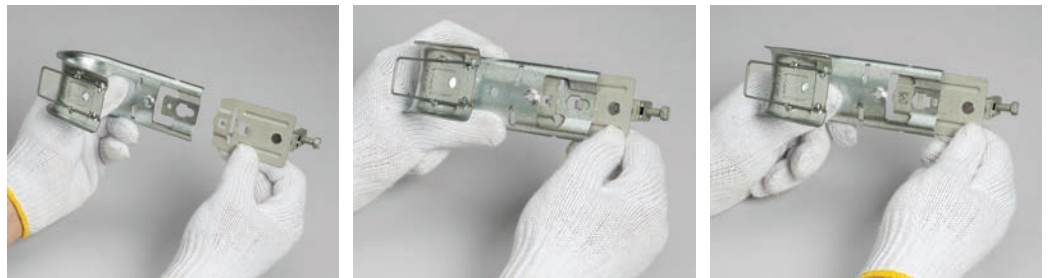

### IMPROVED NVENT CADDY CAT HP J-HOOK MOD CLIP WITH SHOT-FIRE BRACKET

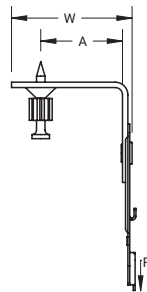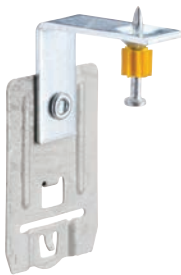

#### Features


- Complete with nVent CADDY Cat HP J-Hook with Shot-Fire Bracket and pre-assembled drive pin from DEWALT®
- Quickly and easily attaches to concrete, steel or composite metal decking
- Integrated pin installs easily using powder-actuated or single-shot gas-actuated tools
- ICC-ES ESR-2024 evaluation report available for drive pin from DEWALT® ready-to-go out of the box
- Works with nVent CADDY J-Hook Versa-Mount Technology

Material: Steel, Spring Steel  
Finish: Electrogalvanized, nVent CADDY Armour



Part Number	Offset A	Static Load F	Width W
CATHPMABSF	1.563"	60 lb	1.85"

## IMPROVED NVENT CADDY CAT HP J-HOOK MOD CLIP WITH ANGLE BRACKET

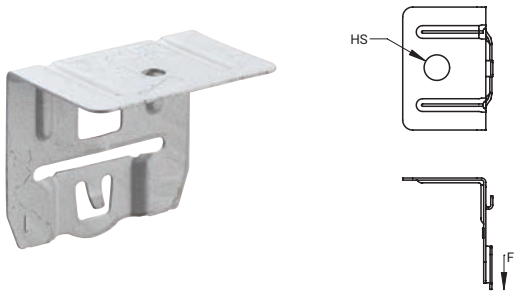

### Features


- Complete with nVent CADDY CAT HP J-Hook with Shot-Fire Bracket
- Quickly and easily attaches to concrete, steel or composite metal decking
- Integrated pin installs easily using powder-actuated or single-shot gas-actuated tools
- Works with nVent CADDY J-Hook Versa-Mount Technology

Material: Spring Steel  
Finish: nVent CADDY Armour



Part Number	Hole Size HS	Static Load F
CATHPMA8	0.25"	200 lb
CATHPMA4	0.25"	200 lb
CATHPMAN	0.25"	160 lb
CATHPMA6	0.25"	200 lb

## IMPROVED NVENT CADDY CAT HP J-HOOK MOD CLIP WITH STRAIGHT BRACKET

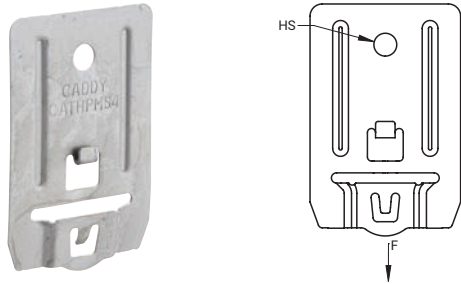

### Features

- Can be attached to various nVent CADDY fasteners or screwed directly to a wall
- Ideal for attaching to concrete, steel or wood surfaces
- No screws, rivets or special tools required for assembly
- Two tabs lock onto nVent CADDY Cat HP components to provide rigidity and stability
- Works with nVent CADDY J-Hook Versa-Mount Technology

Material: Spring Steel  
Finish: nVent CADDY Armour



Part Number	Hole Size HS	Static Load F
CATHPMS4	0.25"	200 lb



Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN RAYCHEM SCHROFF TRACER**