




Improved nVent CADDY Cat HP Mod Clip Beam Clamp

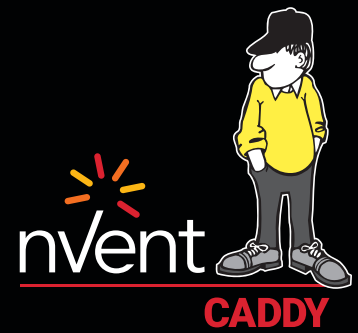


CONNECT AND PROTECT

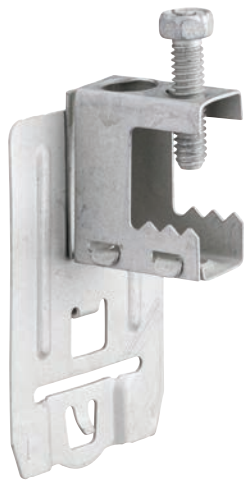

Improved nVent CADDY Cat HP Mod Clip Beam Clamp features two locking tabs that offer a secure hold—boosting both stability and flexibility on-site when installing nVent CADDY Cat HP J-Hooks. By eliminating the need for screws, rivets or special tools, both installation time and cost are reduced. Our innovative nVent CADDY J-Hook Versa-Mount Technology is compatible with the nVent CADDY Cat HP Mod Clip Beam Clamp, allowing for multiple structural and installation methods for wall, ceiling and threaded rod mounting applications due to its unique attachment design.

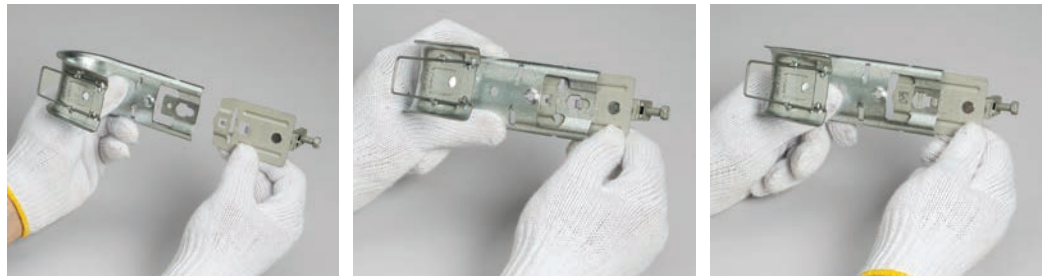

IMPROVED NVENT CADDY CAT HP J-HOOK MOD CLIP WITH BC BEAM CLAMP

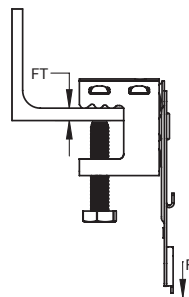

Features


- Easy beam flange installation
- Works with J-Hook Versa-Mount technology from nVent CADDY
- Link J-Hooks to multiple color options, aiding in pathway identification and organization

Material: Steel, Spring Steel
Finish: Electrogalvanized, nVent CADDY Armour



Part Number	Flange Thickness FT	Static Load F
CATHPMBC	0.125" – 0.5"	100 lb

IMPROVED NVENT CADDY CAT HP J-HOOK MOD CLIP WITH BC BEAM CLAMP, SWIVEL

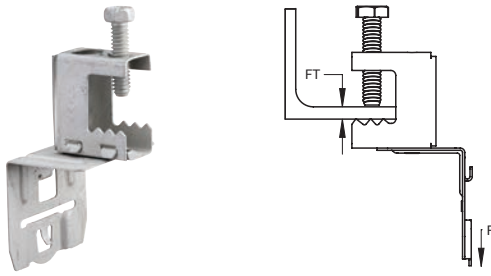

Features


- Rotates 360 degrees to support various directional runs of cable
- Works with J-Hook Versa-Mount technology from nVent CADDY
- Link J-Hook to multiple color options, aiding in pathway identification and organization

Material: Steel, Spring Steel
Finish: Electrogalvanized, nVent CADDY Armour



Part Number	Flange Thickness FT	Static Load F
CATHPMBCB	0.125" – 0.5"	60 lb

IMPROVED NVENT CADDY CAT HP J-HOOK MOD CLIP WITH BC200 BEAM CLAMP

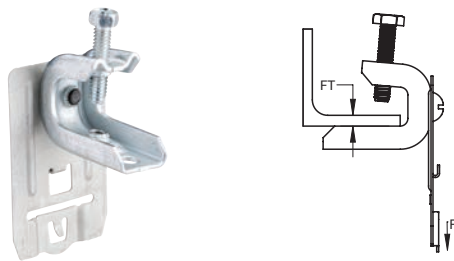

Features


- Easy beam flange installation
- Tool-free assembly
- Works with J-Hook Versa-Mount technology from nVent CADDY
- Link J-Hook to multiple color options, aiding in pathway identification and organization

Material: Steel, Spring Steel
Finish: Electrogalvanized, nVent CADDY Armour



Part Number	Flange Thickness FT	Static Load F
CATHPMBC200	0.125" – 0.625"	100 lb

IMPROVED NVENT CADDY CAT HP J-HOOK MOD CLIP WITH BC200 BEAM CLAMP, SWIVEL

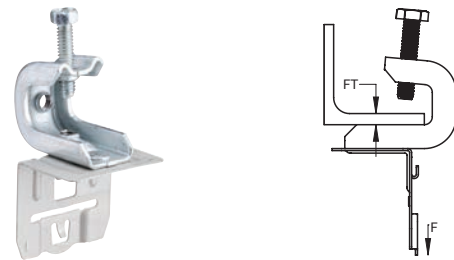

Features

- Rotates 360 degrees to support various directional runs of cable
- Works with J-Hook Versa-Mount technology from nVent CADDY
- Link J-Hooks to multiple color options, aiding in pathway identification and organization

Material: Steel, Spring Steel
Finish: Electrogalvanized, nVent CADDY Armour



Part Number	Flange Thickness FT	Static Load F
CATHPMBC200B	0.125" – 0.625"	100 lb



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN RAYCHEM SCHROFF TRACER