


LADDER RACK CURVED SECTIONS

cULus Classified



Provide a vertical change in direction. They are made of 1-1/2 in. x 3/8 in. (38 mm x 8 mm) tubular steel with a painted or plated finish. Cross members are welded on the inside (inside bends) or outside (outside bends) of the section. Connect to straight section with butt-splice kits. Designed for category 5e, 6, 6A and fiber optic cable.

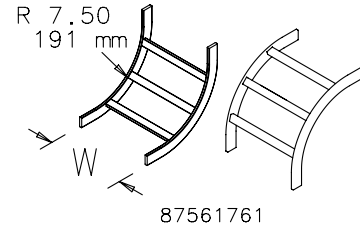

BULLETIN: DCR

| Catalog Number | Finish | Vertical Bend Type | W (in.) | W (mm) |
|----------------|--------|--------------------|---------|--------|
| LIB6G | Gray | Inside | 6.00 | 152 |
| LIB6BLK | Black | Inside | 6.00 | 152 |
| LIB6GZ | Plated | Inside | 6.00 | 152 |
| LIB6W | White | Inside | 6.00 | 152 |
| LIB12G | Gray | Inside | 12.00 | 305 |
| LIB12BLK | Black | Inside | 12.00 | 305 |
| LIB12GZ | Plated | Inside | 12.00 | 305 |
| LIB12W | White | Inside | 12.00 | 305 |
| LIB15BLK | Black | Inside | 15.00 | 381 |
| LIB15W | White | Inside | 15.00 | 381 |
| LIB18G | Gray | Inside | 18.00 | 457 |
| LIB18BLK | Black | Inside | 18.00 | 457 |
| LIB18W | White | Inside | 18.00 | 457 |
| LIB18GZ | Plated | Inside | 18.00 | 457 |
| LIB24BLK | Black | Inside | 24.00 | 610 |
| LIB24W | White | Inside | 24.00 | 610 |
| LOB6G | Gray | Outside | 6.00 | 152 |
| LOB6BLK | Black | Outside | 6.00 | 152 |
| LOB6GZ | Plated | Outside | 6.00 | 152 |
| LOB6W | White | Outside | 6.00 | 152 |
| LOB12G | Gray | Outside | 12.00 | 305 |
| LOB12BLK | Black | Outside | 12.00 | 305 |
| LOB12GZ | Plated | Outside | 12.00 | 305 |
| LOB12W | White | Outside | 12.00 | 305 |
| LOB15BLK | Black | Outside | 15.00 | 381 |
| LOB15W | White | Outside | 15.00 | 381 |
| LOB18G | Gray | Outside | 18.00 | 457 |
| LOB18BLK | Black | Outside | 18.00 | 457 |
| LOB18GZ | Plated | Outside | 18.00 | 457 |
| LOB18W | White | Outside | 18.00 | 457 |
| LOB24BLK | Black | Outside | 24.00 | 610 |
| LOB24W | White | Outside | 24.00 | 610 |