
 
 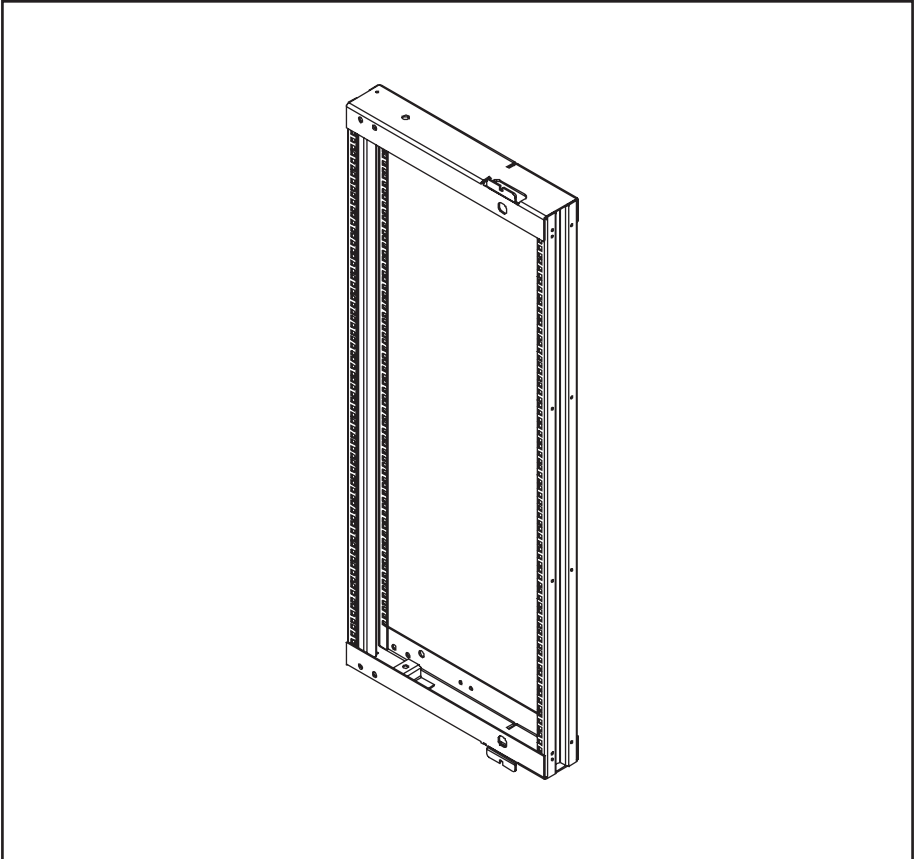







 


 

 



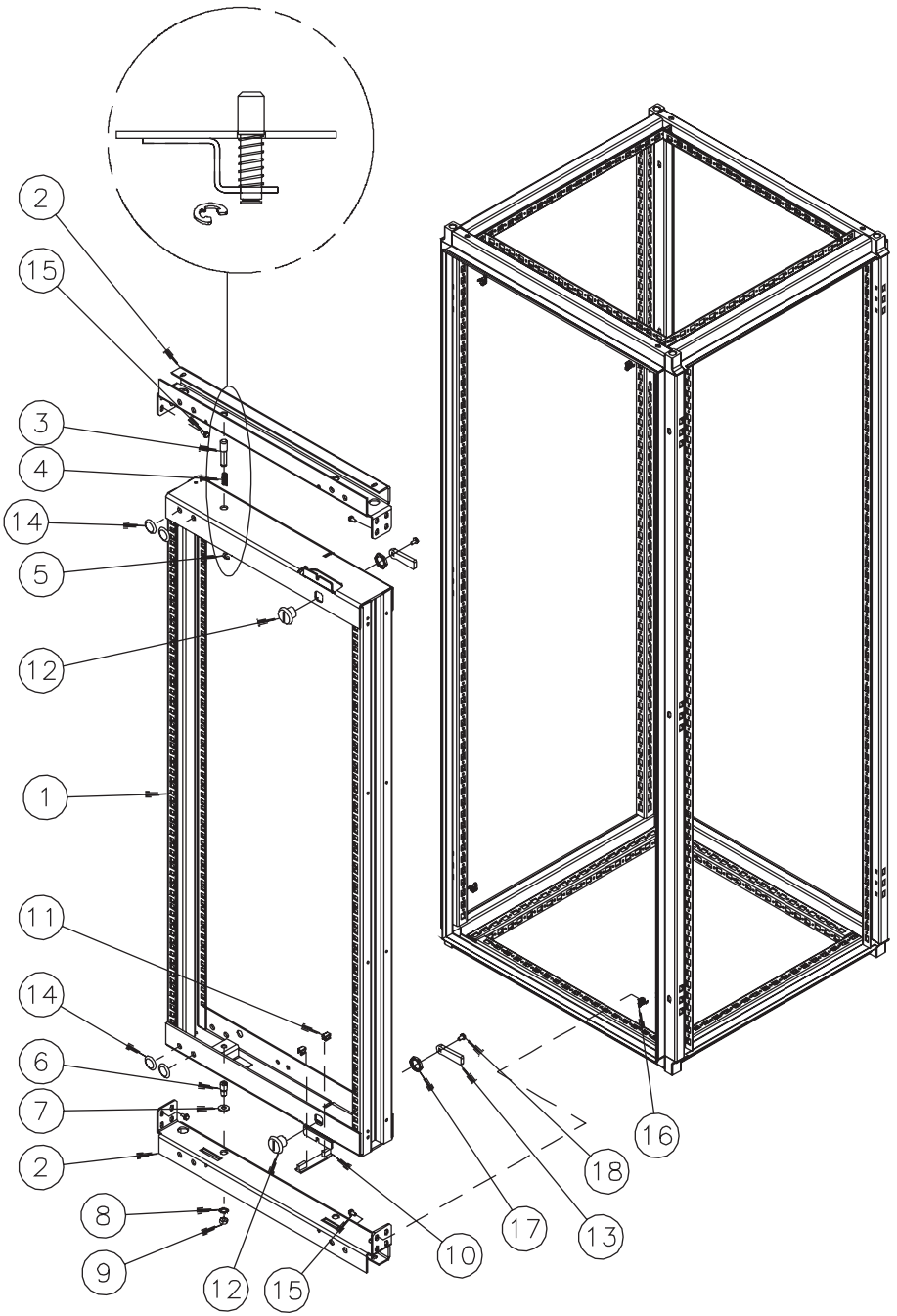




PROLINE®





1  (1x)	2  (2x)	3  (1x)	4  (1x)
5  (1x)	6 M10  (1x)	7 M10  (1x)	8 M10  (1x)
9 M10  (1x)	10  (1x)	11  (2x)	12 M22  (2x)
13  (2x)	14  (4x)	15 M6  (8x)	16 M6  (8x)
17 M22  (2x)	18 M6  (2x)		




⚠ WARNING	
	<p>.20 5 mm Max.</p>

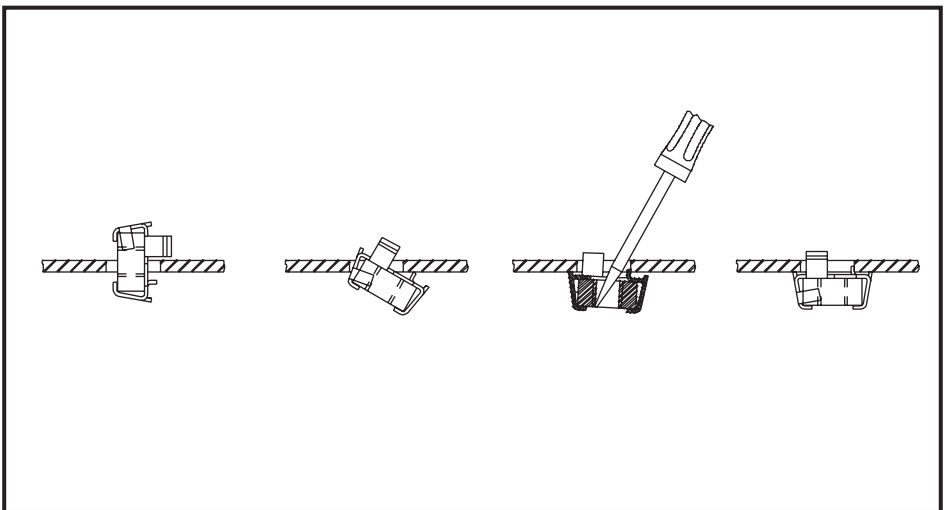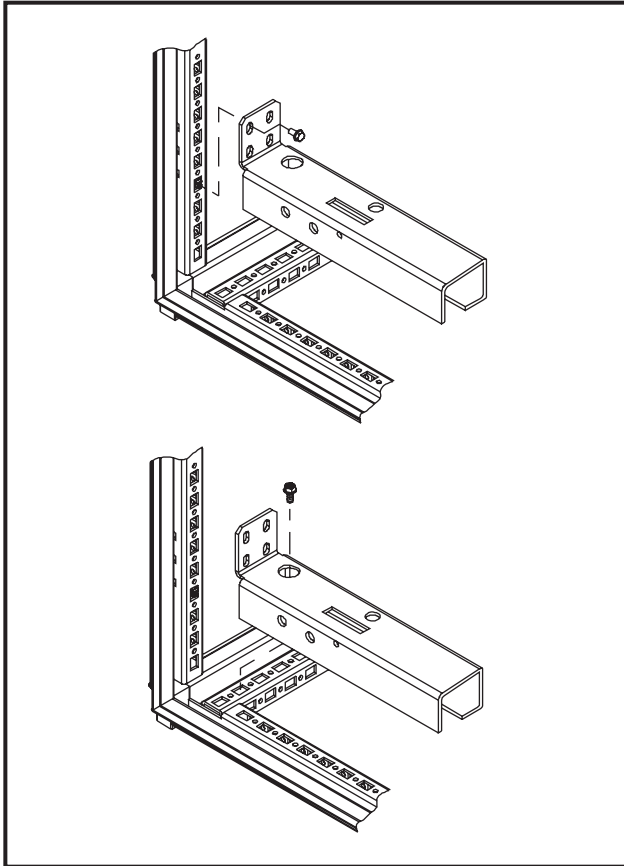


800mm

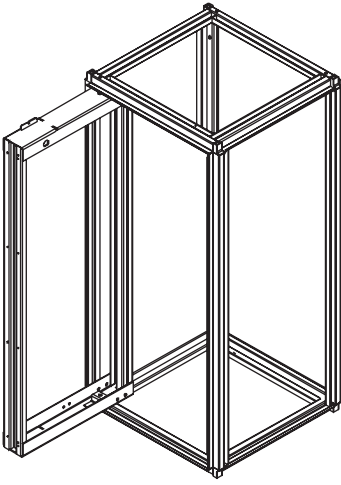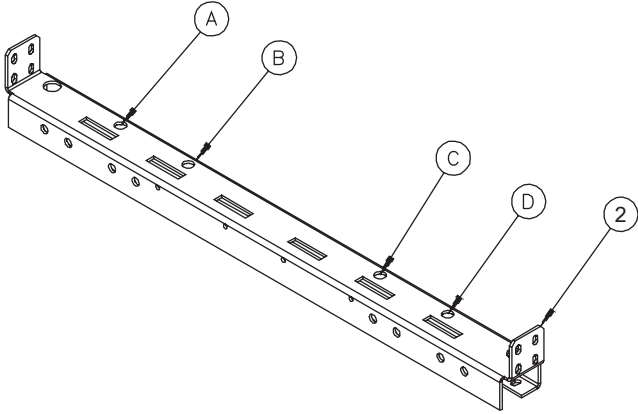


A

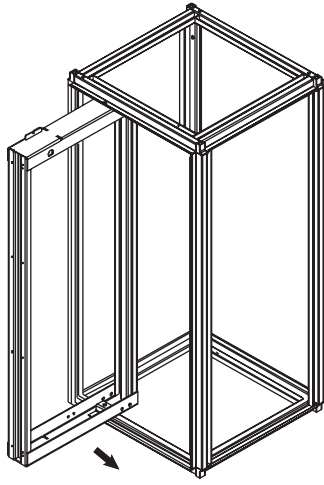

B

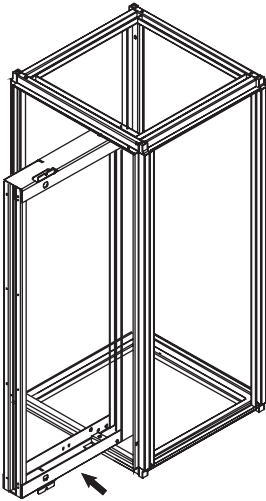

C

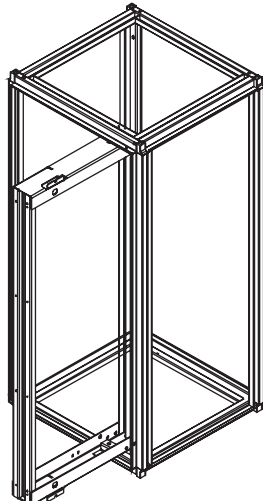

D



HOFFMAN