
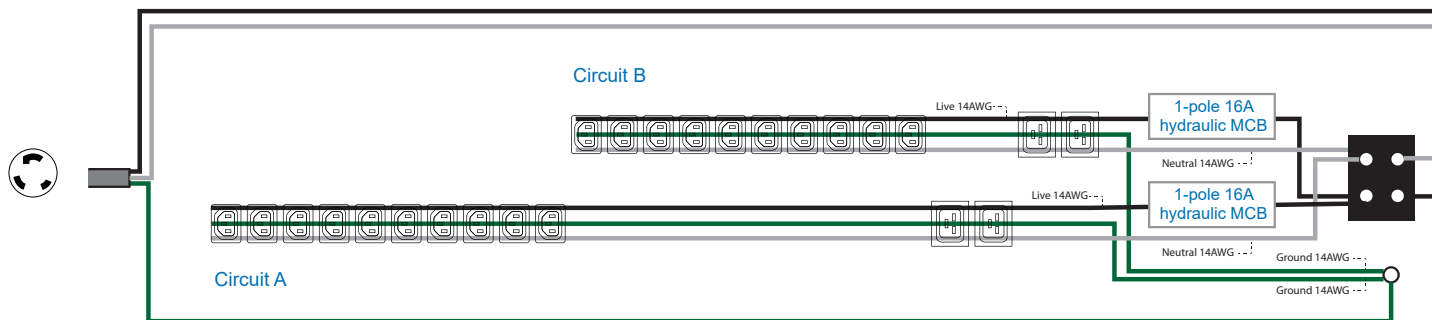


Basic Strip

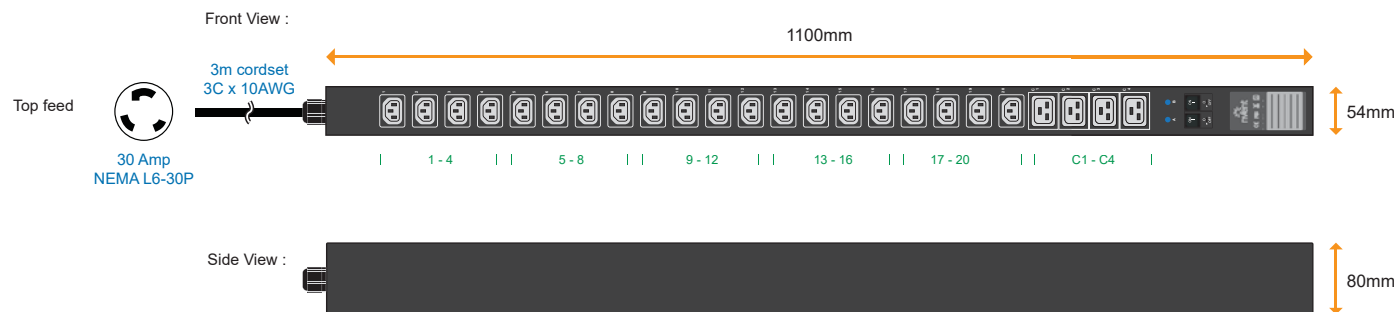

Single phase basic PDU

Input Rating : 30A, 208V
 Outlet : 10A Rated C13 x 20
 16A Rated C19 x 4
 Inlet : 30A NEMA L6-30P plug
 Cordset : 3 meter 10AWG cordset
 Protection : 16A single pole hydraulic MCB x 2
 Circuit Details : < **Circuit A** > Output 12A max. C13 #1-10 + C19 #C1-C2
 < **Circuit B** > Output 12A max. C13 #11-20 + C19 #C3-C4

Operating Temperature : -5 to 60 °C
 Storage Temperature : -25 to 65 °C
 Operating Altitude : 0 to 2,000 m
 Storage Altitude : 0 to 15,000 m
 Humidity : 8 to 95% RH, non-condensing

EMC Compliance : FCC Part 15 Subpart B
 Safety Compliance : UL 60950-1:2007/R:2014-10
 CAN/CSA-C22.2 No. 60950-1:2007/A2:2014-10
 UL 62368-1:2014
 CAN/CSA-C22.2 No. 62368-1:2014
 UL 60730-1 Ed.5 (2016)
 Environment Compliance : RoHS2 & REACH

Chassis Material : Steel
 Chassis Color : Black

Product Dimension : 2.1 (W) x 3.1 (D) x 43.3 (H) inch
 Net Weight : 10.75 lbs

Packing Dimension (for 2 PDUs) : 4.3 (W) x 10.6 (D) x 54.8 (H) inch
 PDU Gross Weight (for 2 PDUs) : 27.7 lbs