


Basic Strip

unit : mm


Front view :

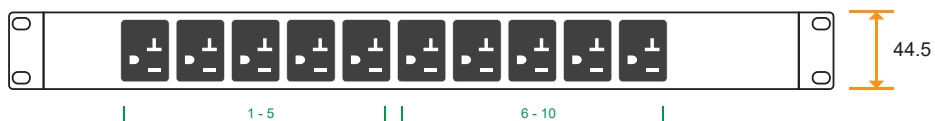


Rear view :



Top View :

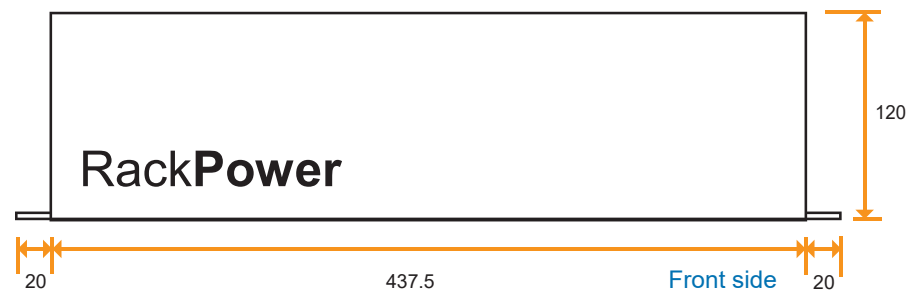

Circuit A

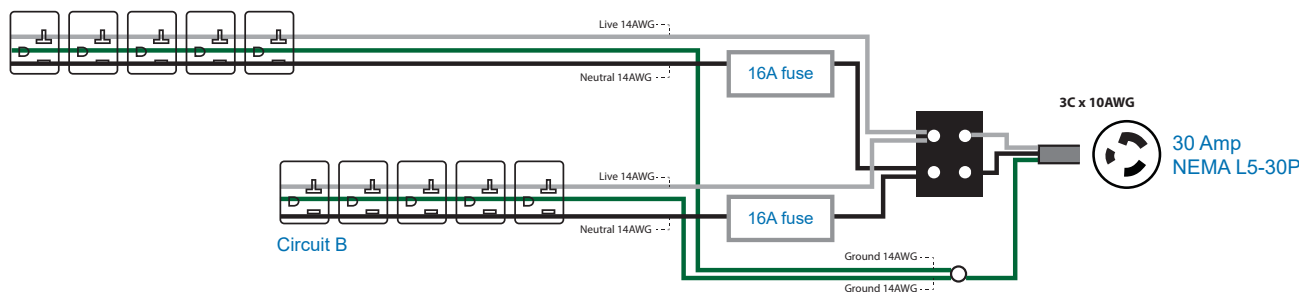

Single phase basic PDU

Input Rating : 30A, 110V
 Outlet : 20A rated US NEMA 5-20R x 10
 Inlet : 30A NEMA L5-30P plug
 Cordset : 3 meter UL 10AWG cordset
 Protection : 16A resettable fuse x 2
 Circuit Details : < **Circuit A** > Output 12A max. U.S # 1 - 5
 < **Circuit B** > Output 12A max. U.S # 6 - 10

Operating Temperature : -5 to 60 °C
 Storage Temperature : -25 to 65 °C
 Operating Altitude : 0 to 2,000 m
 Storage Altitude : 0 to 15,000 m
 Humidity : 8 to 95% RH, non-condensing

EMC Compliance : FCC Part 15 Subpart B certified
 Safety Compliance : cTUVus Mark to UL 60950-1:2007/R:2014-10
 CAN/CSA-C22.2 No. 60950-1:2007/A2:2014-10
 UL 62368-1:2014
 CAN/CSA-C22.2 No. 62368-1:2014
 UL 60730-1 Ed.5 (2016)
 Environment Compliance : RoHS2 & REACH

Chassis Material : Steel
 Chassis Color : Black
 Product Dimension : 17.2 (W) x 4.7 (D) x 1.8 (H) inch
 Net Weight : 7.0 lbs
 Packing Dimension : 20.7 (W) x 9.1 (D) x 3.1 (H) inch
 PDU Gross Weight : 8.4 lbs