

Basic Strip

unit : mm


Front view :



Rear view :



Top View :

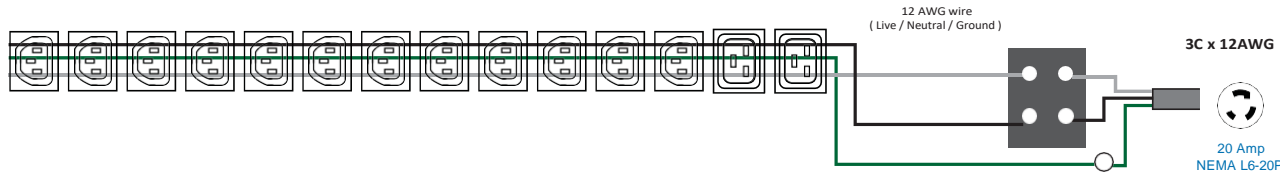

Single phase basic PDU

Input Rating : 20A, 208V
 Outlet : 10A Rated C13 x 12
 16A Rated C19 x 2
 Inlet : 20A NEMA L6-20P plug
 Cordset : 3 meter UL SJT 12 AWG cordset
 Protection : NIL
 Circuit Details : Output 16A max. C13 #1-12 + C19 #C1-C2

EMC Compliance : FCC Part 15 Subpart B certified
 Safety Compliance : cTUVus Mark to UL60950-1:2007/R:2014-10
 CAN/CSA-C22.2 No. 60950-1:2007/A2:2014-10
 UL 62368-1:2014
 CAN/CSA-C22.2 No. 62368-1:2014
 UL 60730-1 Ed.5 (2016)
 Environment Compliance : RoHS2 & REACH

Operating Temperature : -5 to 60 °C
 Storage Temperature : -25 to 65 °C
 Operating Altitude : 0 to 2,000 m
 Storage Altitude : 0 to 15,000 m
 Humidity : 8 to 95% RH, non-condensing

Chassis Material : Steel
 Chassis Color : Black

Product Dimension : 17.2 (W) x 4.7 (D) x 1.8 (H) inch
 Net Weight : 5.6 lbs

Packing dimension : 21.3 (W) x 21.3 (D) x 5.9 (H) inch
 PDU gross weight : 6.1 lbs