

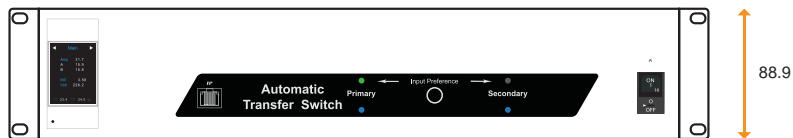
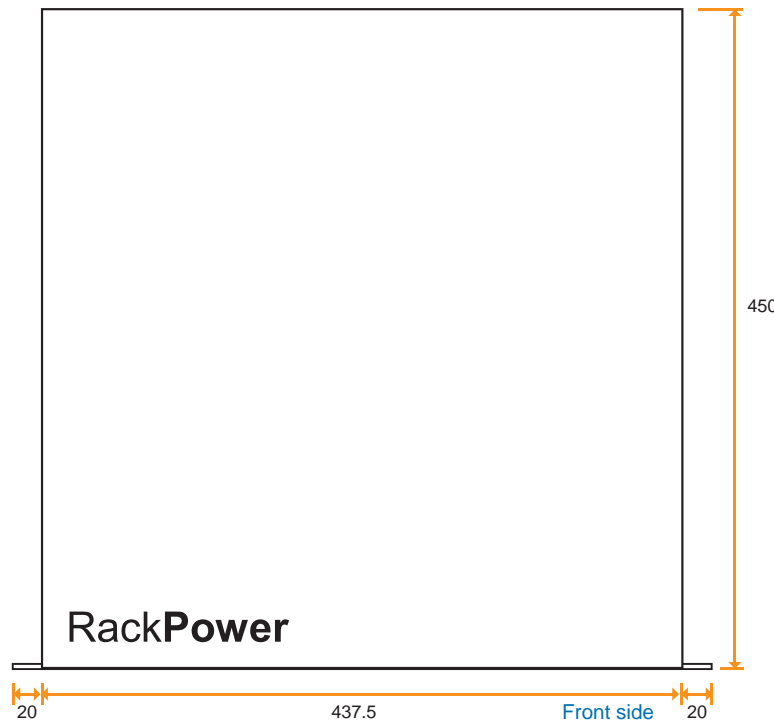


Top View

Front view

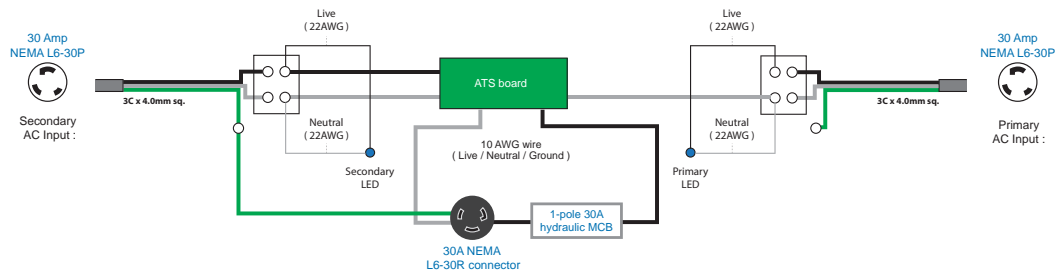

Rear view

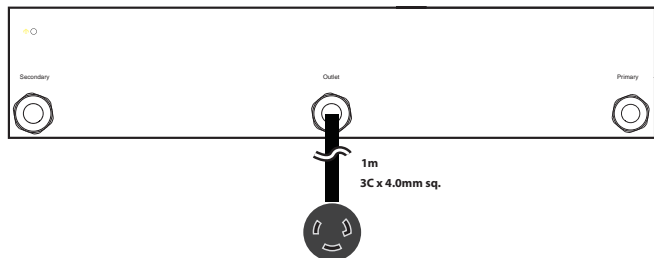

unit : mm

Automatic transfer switch

Input Rating : 30A, 208V
 Outlet : 30A NEMA L6-30R connector x 1
 with 1 meter 4.0mm sq. H05V V-F cordset
 Inlet : 30A NEMA L6-30P plug x 2
 Cordset : 3 meter 4.0mm sq. H05V V-F cordset x 2
 Protection : 30A single pole hydraulic MCB x 1
 Circuit Details : Output 30A max. 30A NEMA L6-30R connector.

ATS Specification :

Nominal input voltage : 208V
 Acceptable input voltage : $\pm 10\%$ nominal
 Input frequency : 50 / 60Hz
 Transfer time : 10 - 14ms typical
 Electrical endurance : 1×10^5 operations
 Power consumption : Approx. 20W

Meter Features

Local Display : 2.0" color LCD with touchscreen
 Measurement : Voltage (V), Current (A), energy (kWh) & power factor
 Accuracy : $\pm 1\%$ Billing-grade
 IP Access : via built-in IP dongle for network access
 SNMP : V2 / V3 version, via built-in IP dongle

Operating Temperature : -5 to 60 °C
 Storage Temperature : -25 to 65 °C
 Operating Altitude : 0 to 2,000 m
 Storage Altitude : 0 to 15,000 m
 Humidity : 8 to 95% RH, non-condensing
 Material : Steel
 Color : Black

EMC Compliance : FCC Part 15 Subpart B
 Safety Compliance : TUVus to UL 60950-1:2007/R:2014-10
 CAN/CSA-C22.2
 No. 60950-1:2007/A2:2014-10
 UL 62368-1:2014
 CAN/CSA-C22.2 No. 62368-1:2014
 UL 60730-1 Ed.5 (2016)
 Environment Compliance : RoHS2 & REACH
 Product Dimension : 17.2 (W) x 17.7 (D) x 3.5 (H) inch
 Net Weight : 12.76 lbs