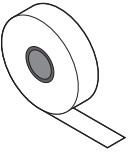

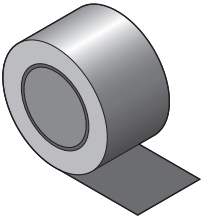
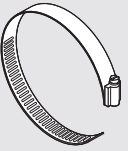



Accessories

CONNECT AND PROTECT

ATTACHMENT PRODUCTS

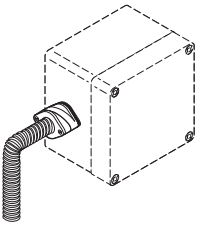
Catalog number	Part number	Description
GT-66 	C77220-000	66 ft (20 m) roll of glass tape for attaching heating cable to pipe. Not for stainless steel pipes or for installation temperatures below 40°F (5°C).
GS-54 	C77221-000	54 ft (16.5 m) roll of glass tape for attaching heating cable to pipe. For stainless steel pipes or for any installation below 40°F (5°C).
AT-180 	158139-000	180 ft (55 m) roll of aluminum tape for attaching heating cables and thermostat sensors to pipes and tanks. Minimum installation temperature: 32°F (0°C). Dimensions: 2.5 in wide, 5 mils thick.
Pipe straps 	PS-01 C77211-000 PS-03 C77212-000 PS-10 C77213-000 PS-20 C77216-000	For conduit ≤ 1 in For connection kits on pipes with dimensions ≤ 2 in For connection kits on pipes with dimensions 2 in – 10 in For connection kits on pipes with dimensions 10 in – 19.5 in Used to secure connection kits and brackets to pipes. Order by pipe diameter, as shown above.

LABELS

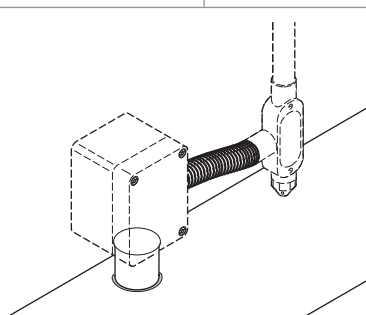
Catalog number	Part number	Description
ETL 	C77203-000	"Electric Traced" label for identifying traced pipes and tanks.



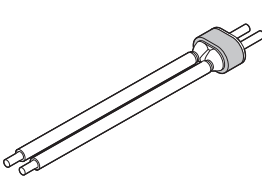
GLAND ENTRY KIT

Catalog number	Part number	Description	Kit Contents	
			Qty	Description
C75-100-A	000539-000	<p>A NEMA 4X-rated gland kit used to transition heating cables into a junction box when making connections off of a pipe or tank. It may be used for power, splice, or tee connections. For use with nVent RAYCHEM brand BTV, QTVR, XTVR, HTV, VPL, and LBTV2-CT⁽¹⁾ heating cables. The kit does not include the junction box, flexible tubing, or tape that are required to make a complete connection.</p> <p>(1) For LBTV2-CT only, order HCS-100-A heat-shrink core sealer (P/N 257649) and PMK-GK-10 grommet (P/N 222724)</p>	1	Red grommet
			1	Gland with threaded inserts
			1	Gland with screws
			1	Gland gasket
			1	Locknut
			1	Green / yellow tube
			1	CS-100 core sealer
			1	Terminal block

 
SINGLE-ENTRY TRANSITION KIT

Catalog number	Part number	Description	Kit Contents	
			Qty	Description
JS-100-A	166639-000	<p>Junction box stand for use with nVent RAYCHEM brand BTV, QTVR, XTVR, HTV and VPL heating cables. A separate customer-supplied NEMA 4X junction box is required.</p>	1	Stand assembly
			1	Lubricant
			1	Adapter for small pipes
			1	Cable tie
			1	Green / yellow tube
			1	CS-100 cold-applied core sealer
			1	JS-100 transition
			1	1-inch locknut


 
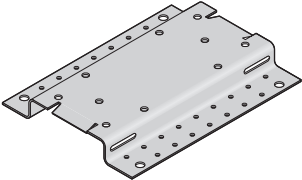
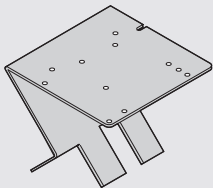
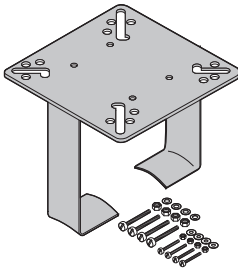
COLD-APPLIED CORE SEALER

Catalog number	Part number	Description
CS-100-A	232949-000	<p>Replacement cold-applied core sealer for nVent RAYCHEM brand BTV, QTVR, XTVR, HTV and VPL heating cables</p>
		

CONDUIT DRAIN

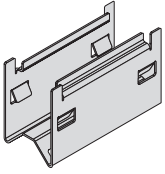
Catalog number	Part number	Description
JB-DRAIN-PLUG-3/4IN	278621-000	<p>nVent recommends the use of this 3/4-in conduit drain with each JBS-100 and JBM-100, and other enclosures with associated conduits, to prevent condensate from collecting in the box.</p>
		

BRACKETS, ADAPTERS

Catalog number	Part number	Description
JBS-SPA 	E90515-000	Adapter for mounting E-100, JBS-100, and JS-100 to small pipe (≤ 1 inch nominal diameter).
JBM-SPA 	D55673-000	Adapter for mounting JBM-100 and T-100 to small pipe (≤ 1 inch nominal diameter).
SB-100-T 	279613-000	Adapter for mounting E-100, E-100-L, and JBS-100 connection kits on a tank surface.
UMB 	263757-000	Universal mounting bracket for mounting thermostats and other equipment on a pipe.
JB-SB-25 	471139-000	Stainless-steel mounting bracket for RAYSTAT-EX-03-A thermostat.

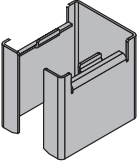
HELICAL FLEXIBLE PLASTIC TUBING

Catalog number	Part number	Description
HCTE-1000 	3679754004	Helical flexible plastic tubing for C75-100-A and HAK-C-100 connection kits.

Junction box standoffFor insulation thickness ≥ 120 mm & ≤ 180 mm*

Catalog number	JBM-100-STANDOFF
Part Number	P000003624
Weight	0.599 lb / 272 g

* Consider extra pipe strap length 6-9" (150-225 mm) for attachment

Junction box standoffFor insulation thickness ≥ 120 mm & ≤ 180 mm*

Catalog number	JBS-100-STANDOFF
Part Number	P000003408
Weight	0.297 lb / 135 g

* Consider extra pipe strap length 6-9" (150-225 mm) for attachment

North America

Tel +1.800.545.6258
 Fax +1.800.527.5703
 thermal.info@nVent.com

Europe, Middle East, Africa

Tel +32.16.213.511
 Fax +32.16.213.604
 thermal.info@nVent.com

Asia Pacific

Tel +86.21.2412.1688
 Fax +86.21.5426.3167
 cn.thermal.info@nVent.com

Latin America

Tel +1.713.868.4800
 Fax +1.713.868.2333
 thermal.info@nVent.com



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN RAYCHEM SCHROFF TRACER