

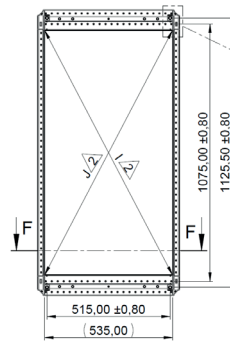


# Varistar CP Stand-Alone Server Rack

10630-019

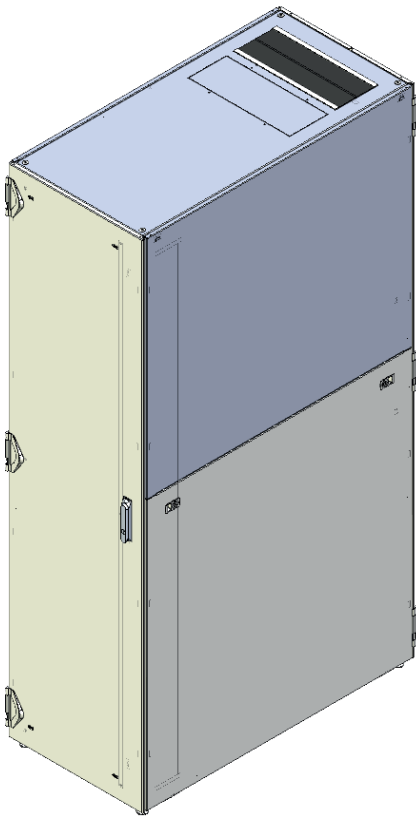

Position adjustable feet

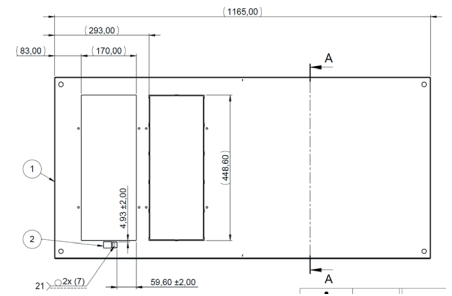

Cable entry top cover

## TECHNICAL DATA

Depth: 1,200 mm  
Height: 2,200 mm/47U  
Width: 600 mm  
Version: Stand-alone

## Delivery comprises:

| Item | Quantity | Description  |
|------|----------|--|
| 1    | 1        | Welded basic frame (CP) sheet metal profile with all-round meandering in 25 mm grid increments for M6 taptite screws and/or M5 cage nuts has a static load-carrying capacity of max. 1,600 kg and 1,000 kg dynamic, RAL 7021 |
| 2    | 1        | Top cover, RAL 7021 in steel plate 1.5 mm with cut-out for cable entry   |
| 3    | 1        | Brush strip set fitted in cut-out zone rear  |
| 4    | 1        | Front door, perforated, steel, with 180° hinges, 3-point locking and lever handle, 1333 locking cylinder, color RAL 7021   |
| 5    | 1        | Rear double door, steel, with 180° hinges and perforation, 3-point locking and lever handle 1333 locking cylinder, color RAL 7021  |
| 6    | 2        | Side panels with quick-release fastener, divided, 1 mm steel   |
| 7    | 4        | 19" panel/slide mounts, steel, mounted in 740 mm intervals, with U marking, color RAL 7021, panel/slide mounts can be recessed in 25 mm steps  |
| 8    | 2        | Gasket material for sealing front side   |
| 9    | 4        | Adjustable foot  |
| 10   | 1        | Panel bottom to seal the gap front side under the cabinet for containment integration  |
| 11   | 1        | Earthing kit, assembled  |