

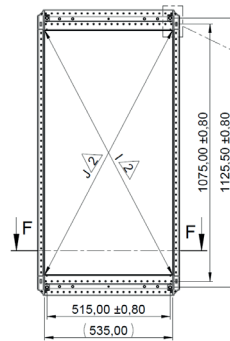


Varistar CP Side-By-Side Server Rack

10630-025

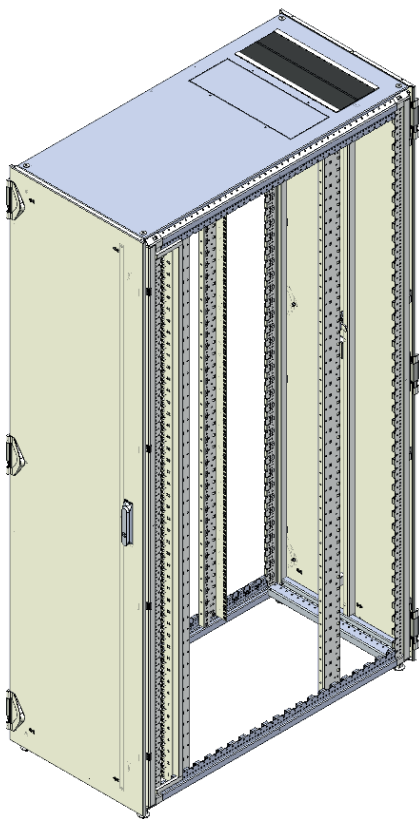

Position adjustable feet

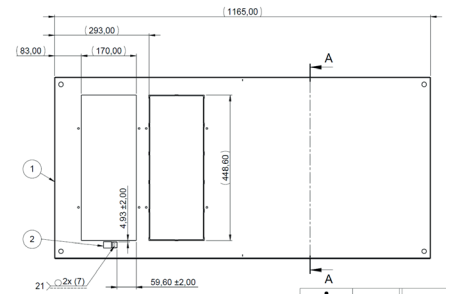

Cable entry top cover

TECHNICAL DATA

Depth: 1,200 mm
Height: 2,200 mm/47U
Width: 600 mm
Version: Side-by-side

Delivery comprises:

Item	Quantity	Description
1	1	Welded basic frame (CP) sheet metal profile with all-round meandering in 25 mm grid increments for M6 taptite screws and/or M5 cage nuts has a static load-carrying capacity of max. 1,600 kg and 1,000 kg dynamic, RAL 7021
2	1	Top cover, RAL 7021 in steel plate 1.5 mm with cut-out for cable entry
3	1	Brush strip set fitted in cut-out zone rear
4	1	Front door, perforated, steel, with 180° hinges, 3-point locking and lever handle, 1333 locking cylinder, color RAL 7021
5	1	Rear double door, steel, with 180° hinges and perforation, 3-point locking and lever handle 1333 locking cylinder, color RAL 7021
6	4	19" panel/slide mounts, steel, mounted in 740 mm intervals, with U marking, color RAL 7021, panel/slide mounts can be recessed in 25 mm steps
7	2	Gasket material for sealing front side
8	4	Adjustable foot
9	1	Panel bottom to seal the gap front side under the cabinet for containment integration
10	1	Earthing kit, assembled