





RAYCHEM




U-RD-ACC-CE CE-T2RED/ETL

PCN: 323608-000 - E 89 490 05 - RSK 240 80 53
El.nr 10 350 35 - NRF 240 76 01 / 240 75 65
SSTL 04 309 90 - LVI 18 47 016

R-ETL, T2RED

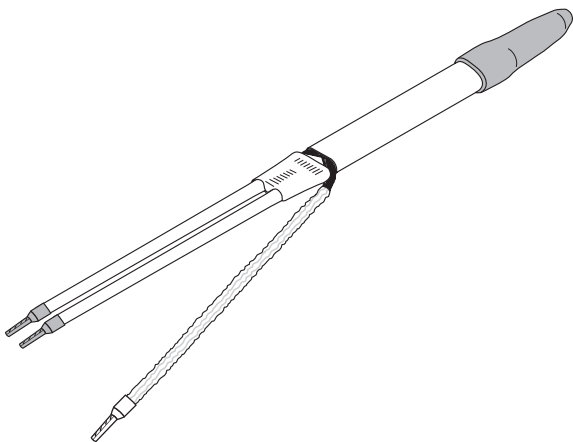

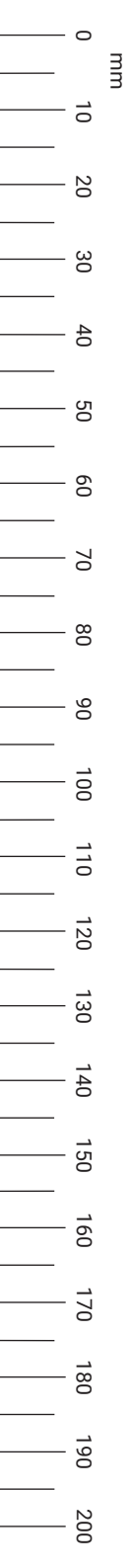

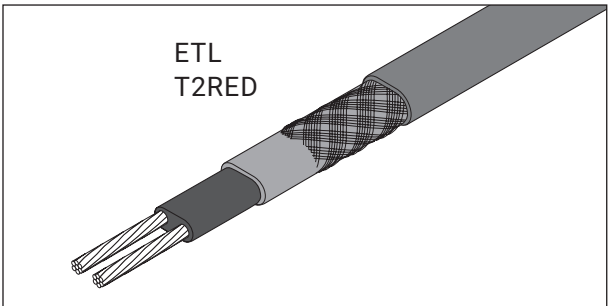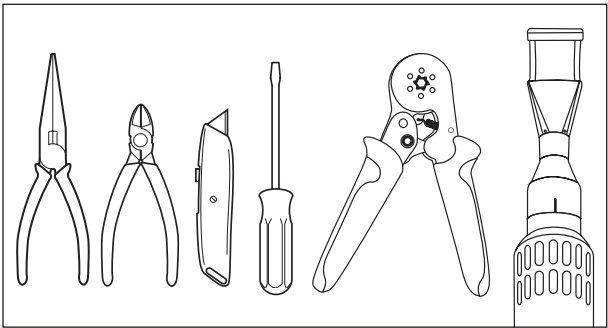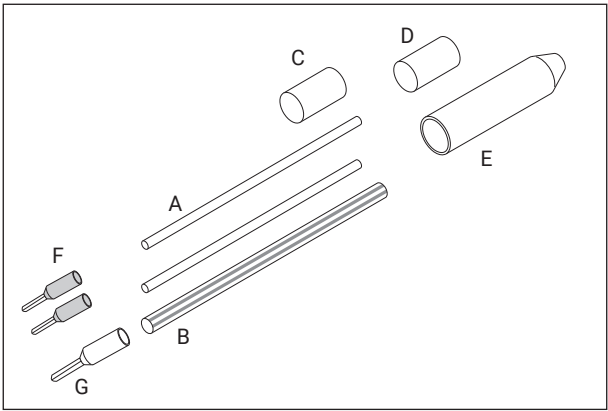

R-ETL:

Min. installation temp. -10°C

**R-ETL-A, R-ETL-A-CR:**

 
$L_{\text{max}} = 100 \text{ m, C10A / 230 VAC}$

R-ETL-B, R-ETL-B-CR:

$L_{\text{max}} = 100 \text{ m, C16A / 230 VAC}$

R-ETL-A, R-ETL-B:

Max. water pressure 16 bar

**R-ETL-A:**

$L_{\text{max}} = 60 \text{ m, C10A / 230 VAC}$

R-ETL-B:

$L_{\text{max}} = 60 \text{ m, C16A / 230 VAC}$

T2RED:

C10A/230 VAC

L_{max} @ start-up temp:


100m @ $+20^{\circ}\text{C}$

85m @ $+15^{\circ}\text{C}$





75m @ $+10^{\circ}\text{C}$




60m @ $+5^{\circ}\text{C}$

Min. installation temp. $+5^{\circ}\text{C}$

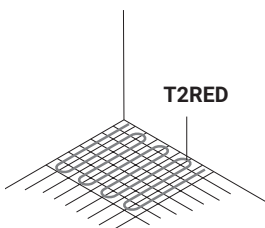


Min. 5°C

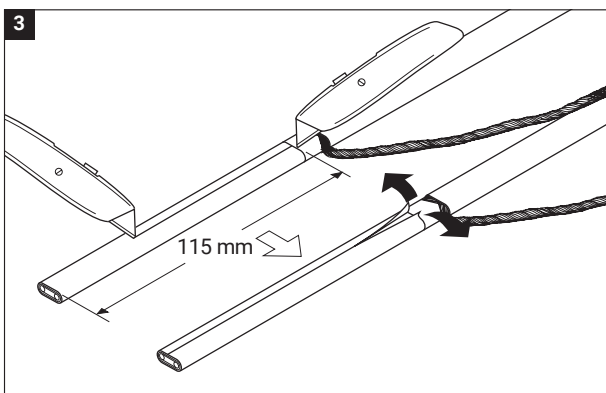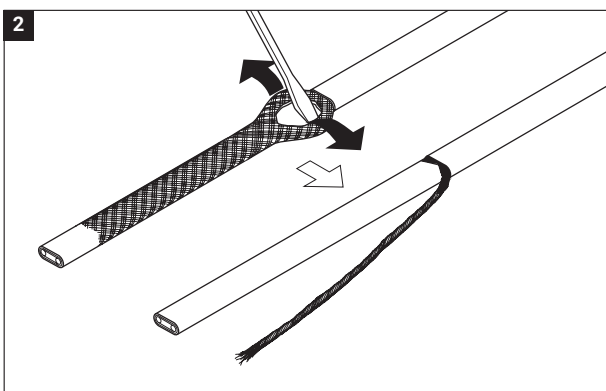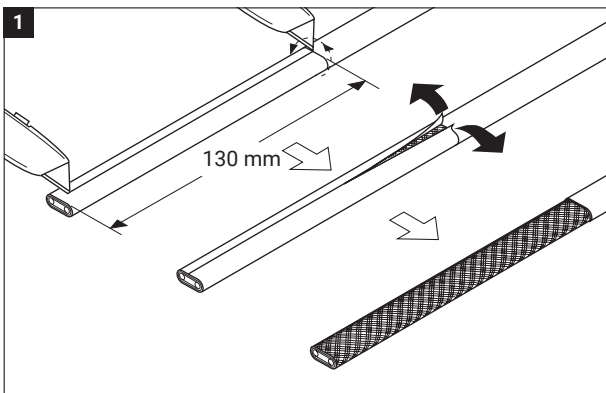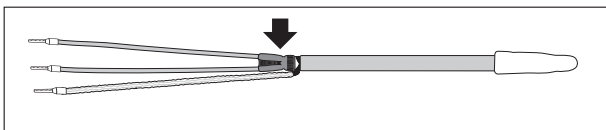



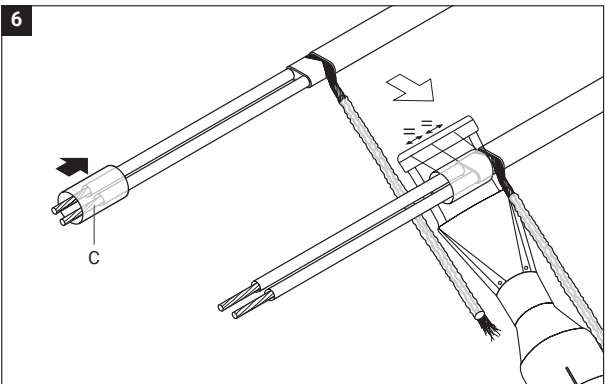
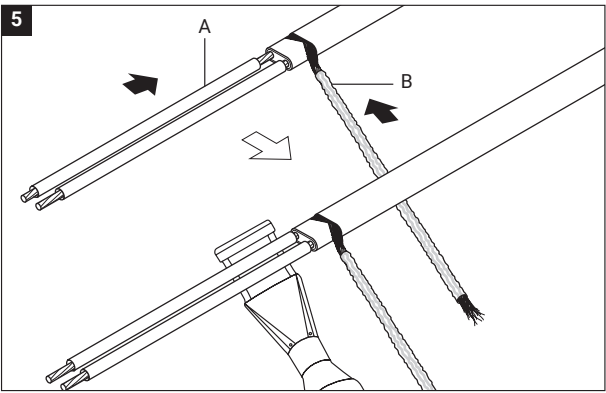
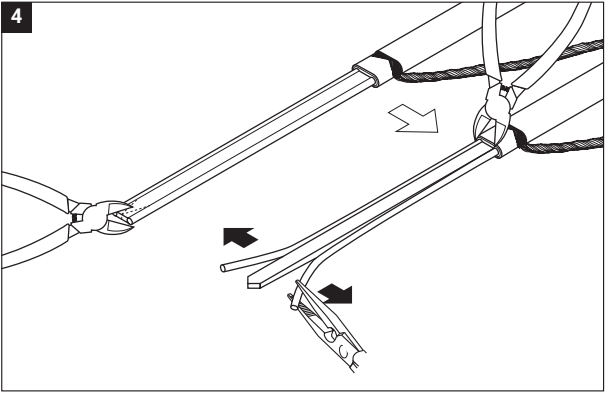


7

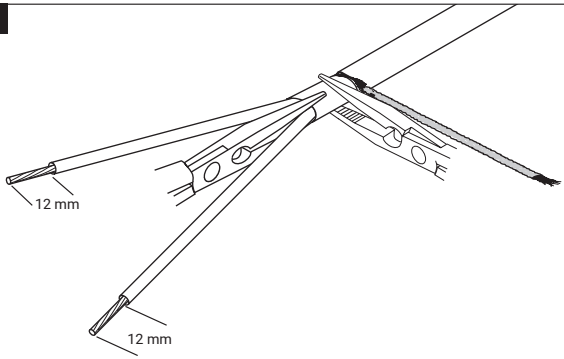


8

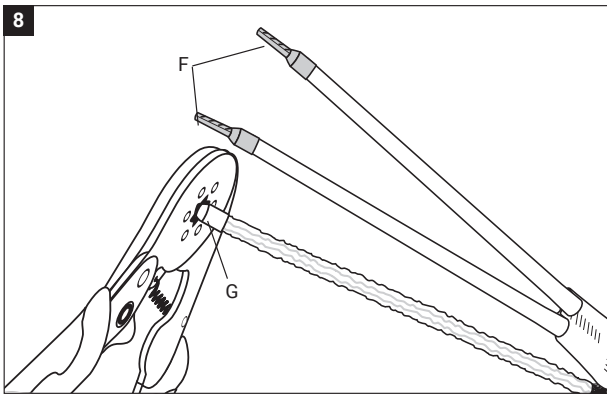


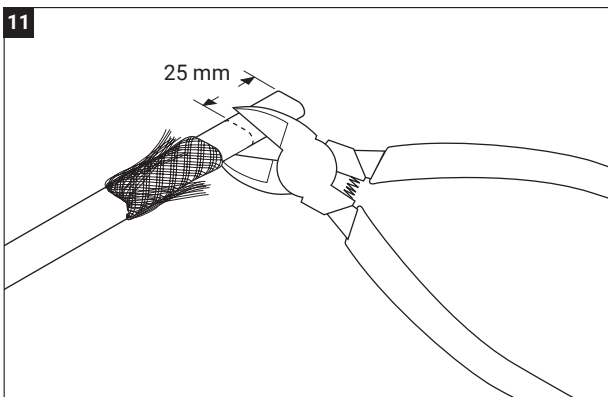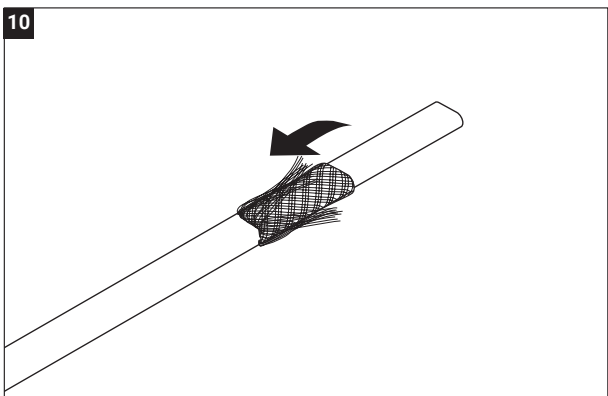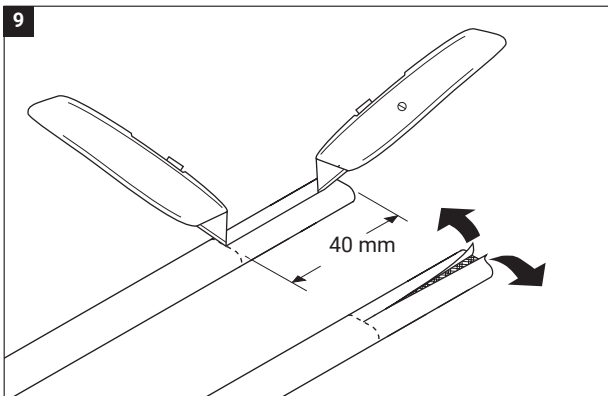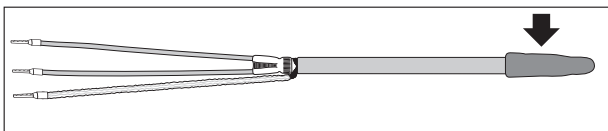


12

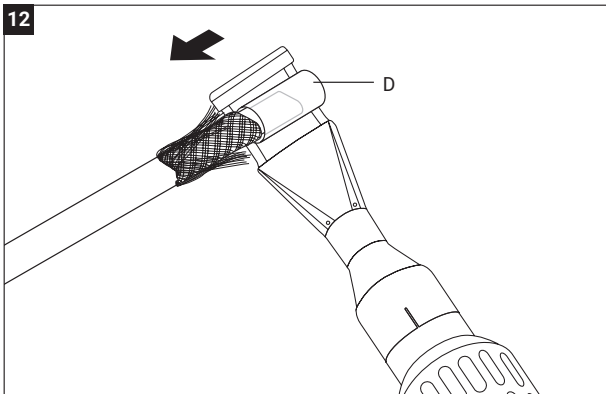


13

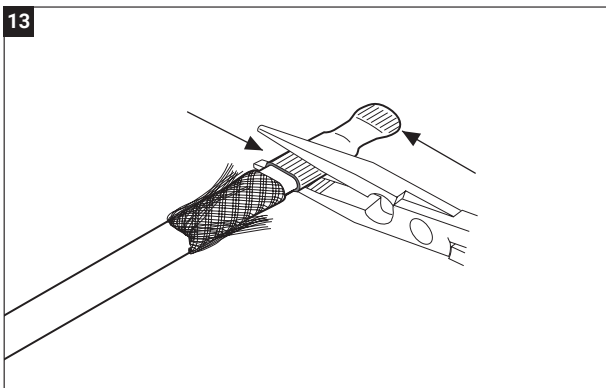


14

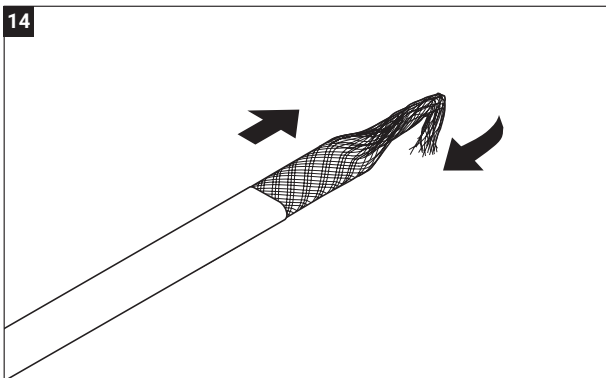


15

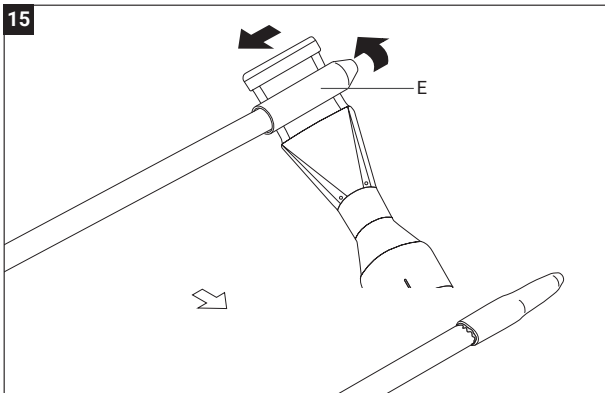

16

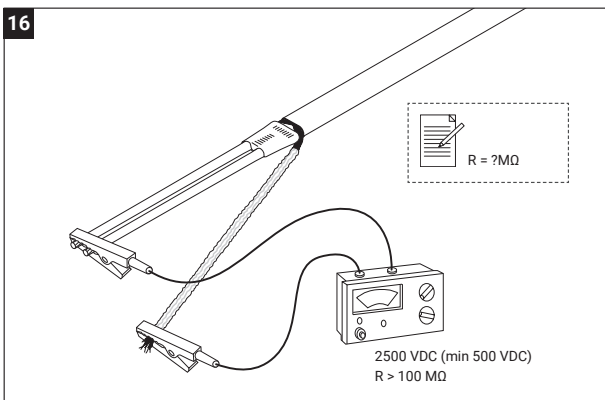

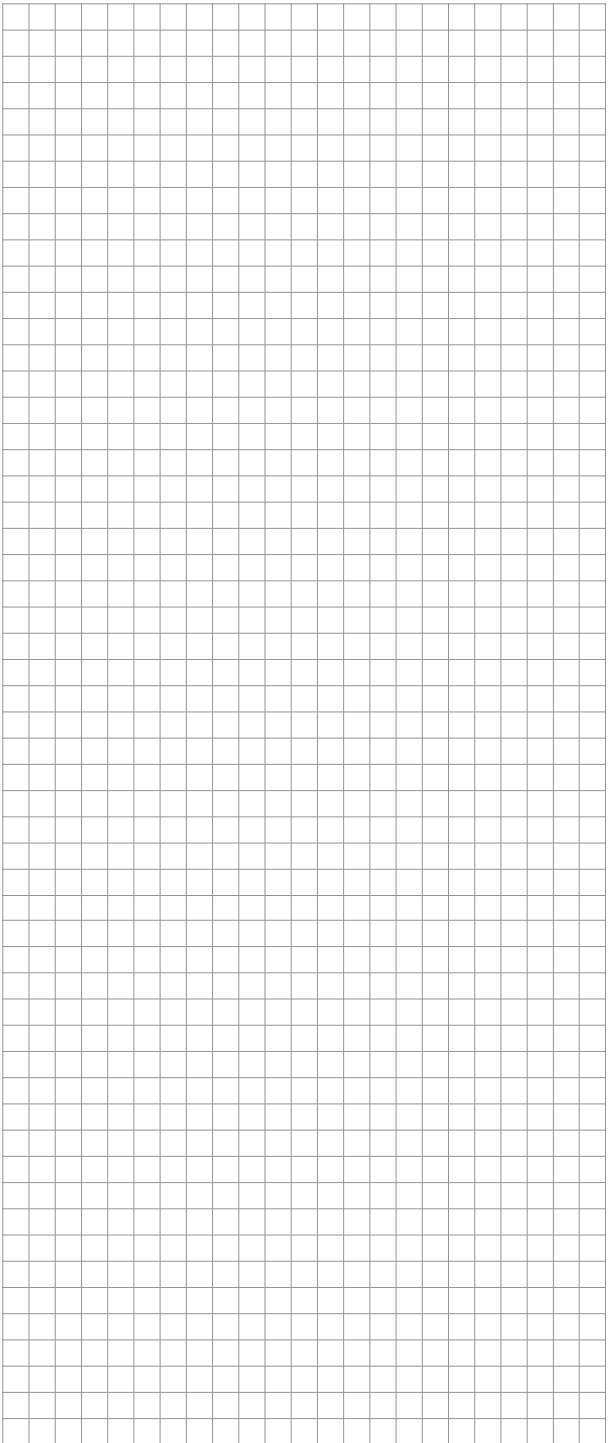

BELGIË / BELGIQUE

Tel. +32 16 21 35 02
Fax +32 16 21 36 04
salesbelux@nVent.com

BULGARIA

Tel. +359 5686 6886
Fax +359 5686 6886
salesee@nVent.com

ČESKÁ REPUBLIKA

Tel. +420 606 069 618
czechinfo@nVent.com

DENMARK

Tel. +45 70 11 04 00
salesdk@nVent.com

DEUTSCHLAND

Tel. 0800 1818205
Fax 0800 1818204
salesde@nVent.com

ESPAÑA

Tel. +34 911 59 30 60
Fax +34 900 98 32 64
ntm-sales-es@nVent.com

FRANCE

Tél. 0800 906045
Fax 0800 906003
salesfr@nVent.com

HRVATSKA

Tel. +385 1 605 01 88
Fax +385 1 605 01 88
salesee@nVent.com

ITALIA

Tel. +39 02 577 61 51
Fax +39 02 577 61 55 28
salesit@nVent.com

LIETUVA/LATVIJA/EESTI

Tel. +370 5 2136633
Fax +370 5 2330084
info.baltic@nVent.com

MAGYARORSZÁG

Tel. +36 1 253 7617
Fax +36 1 253 7618
saleshu@nVent.com

NEDERLAND

Tel. 0800 0224978
Fax 0800 0224993
salesnl@nVent.com

NORGE

Tel. +47 66 81 79 90
salesno@nVent.com

ÖSTERREICH

Tel. 0800 29 74 10
Fax 0800 29 74 09
salesat@nVent.com

POLSKA

Tel. +48 22 331 29 50
Fax +48 22 331 29 51
salespl@nVent.com

REPUBLIC OF KAZAKHSTAN

Tel. +7 7122 32 09 68
Fax +7 7122 32 55 54
saleskz@nVent.com

РОССИЯ

Тел. +7 495 926 18 85
Факс +97 495 926 18 86
salesru@nVent.com

SERBIA AND MONTENEGRO

Tel. +381 230 401 770
Fax +381 230 401 770
salesee@nVent.com

SCHWEIZ / SUISSE

Tel. +41 (41) 760 30 80
Fax +41 (41) 766 30 81
infoBaar@nVent.com

SUOMI

Puh. 0800 11 67 99
salesfi@nVent.com

SVERIGE

Tel. +46 31 335 58 00
salesse@nVent.com

TÜRKIYE

Tel. +90 560 977 6467
Fax +32 16 21 36 04
ntm-sales-tr@nVent.com

UNITED KINGDOM

Tel. 0800 969 013
Fax 0800 968 624
salesthermalUK@nVent.com



nVent.com/RAYCHEM

©2022 nVent. All nVent marks and logos are owned or licensed by nVent Services GmbH or its affiliates. All other trademarks are the property of their respective owners. nVent reserves the right to change specifications without notice.

RAYCHEM-IM-INST212-URDACCCE-ML-2202

PCN 6012-4001