

NVENT ERICO GROUNDING BUS BARS STANDARD CONFIGURATIONS IN STOCK

EGBA SERIES – 1/4" THICK



Busbars

- 1/4" thick copper
- ASTM B187-C11000
- Electro-tin plating available (add "T" to part number)

Brackets


- Type 304 stainless steel
- 1/8" thick

Insulators (Stand Off)


- Manufactured from a halogen-free, fiberglass-reinforced thermalset unsaturated polyester molded compound (BMC)
- Meet the requirements of UL® 94 V-0 for self-extinguishing materials
- Indoor rating: 600 volts

Fasteners


- 3/8" Type 304 stainless steel
- All bars shown include insulators, stainless steel brackets, stainless steel mounting bolts, and are UL Listed
- All illustrations show bars of 12" length. Bars of longer lengths will have additional holes according to the pattern shown
- Contact nVent ERICO for additional ground bar configurations

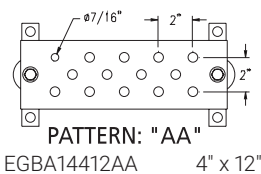


EGBA14412AA 4" x 12"

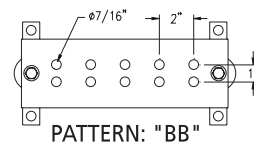


EGBA14212BB 2" x 12"
EGBA14412BB 4" x 12"

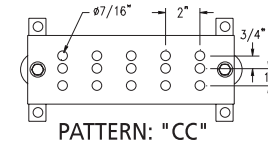


EGBA14412CC 4" x 12"
EGBA14418CC 4" x 18"
EGBA14420CC 4" x 20"
EGBA14424CC 4" x 24"

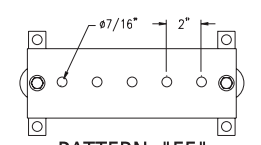


EGBA14212EE 2" x 12"

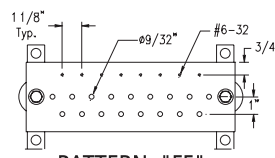


EGBA14410FF 4" x 10"

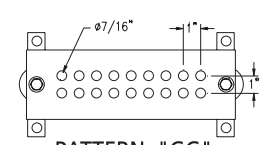


EGBA14212GG 2" x 12"
EGBA14412GG 4" x 12"
EGBA14424GG 4" x 24"

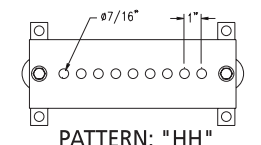


EGBA14212HH 2" x 12"

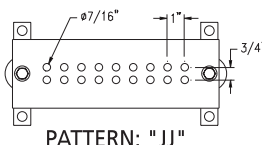

EGBA14215JJ 2" x 15"

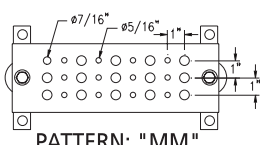

EGBA14424MM 4" x 24"

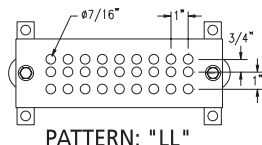

EGBA14412LL 4" x 12"
EGBA14424LL 4" x 24"

nVent ERICO Copper Bars

- 1/4" C11000 Copper Bars
- Non UL Listed, ideal for field fabrication

ECB14212	2" x 12"
ECB14224	2" x 24"
ECB14412	4" x 12"
ECB14424	4" x 24"
ECB142144	2" x 144"
ECB144144	4" x 144"

Custom lengths available upon request

TGB & TMGB SERIES – 1/4" THICK



Busbars

- 1/4" thick copper
- ASTM B187-C11000
- Electro-tin plating available (add "T" to part number)

Brackets

- Type 304 stainless steel
- 1/8" thick


Insulators (Stand Off)

- Manufactured from a halogen-free, fiberglass-reinforced thermalset unsaturated polyester molded compound (BMC)
- Meet the requirements of UL® 94 V-0 for self-extinguishing materials
- Indoor rating: 600 volts


Fasteners

- 3/8" Type 304 stainless steel
- All bars shown include insulators, stainless steel brackets, stainless steel mounting bolts and are UL Listed
- All TGB and TMGB bars meet ASTM B187-C11000 Standard for copper, and ANSI/TIA/EIA-J-STD-607


COPPER AND ELECTRO-TIN PLATED BARS (*"T" AT END OF PART NUMBER DESIGNATES ELECTRO-TIN PLATED)

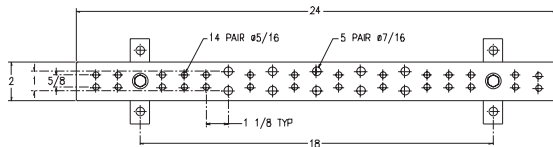


TGBA24L14P

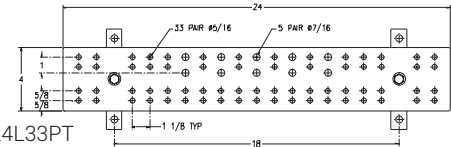


TMGBA24L33PT

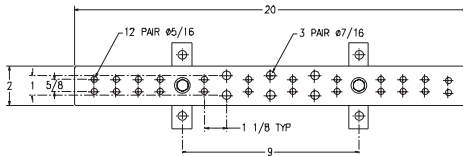


TGBA20L12PT

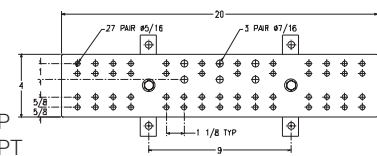


TMGBA20L27P
TMGBA20L27PT

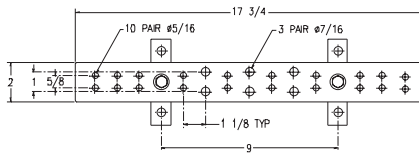


TGBA18L10PT

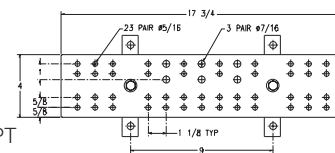


TMGBA18L23PT

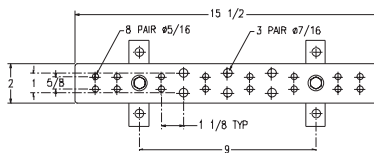


TGBA16L08P

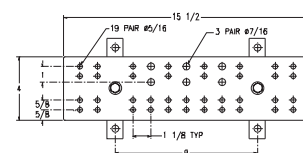

TMGBA16L19PT

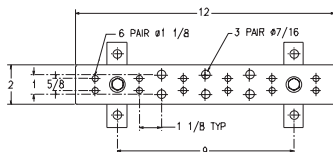

TGBA12L06P
TGBA12L06PT

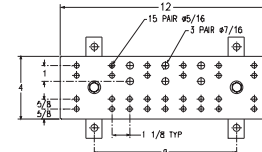


TMGBA12L15P
TMGBA12L15PT

TELECOM GROUNDING BUSBAR SPLICE KIT

Features

- Use splice kits to connect telecom ground bars when ground bar extensions are required
- Includes two tinned copper splice plates and 1/4" stainless steel fasteners

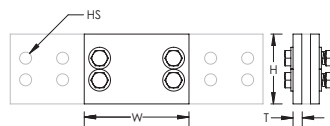

Material: Copper | Finish: Tinned



Part Number	For Use With	Height H	Width W	Thickness T	Hole Size HS
TGBSPICEKIT	TGB Series	2"	3"	1/4"	11/32"
TMGBSPICEKIT	TMGB Series	4"	3 1/2"	1/4"	11/32"



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN RAYCHEM SCHROFF TRACER