



**CONNECT AND PROTECT**

# PKM Metal Pressure Clip

 
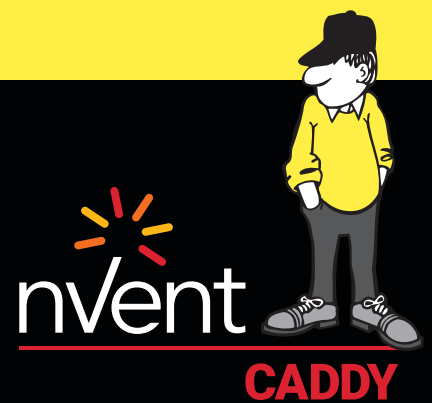


# Metal Pressure Clip – PKM10H3 & PKM10H6

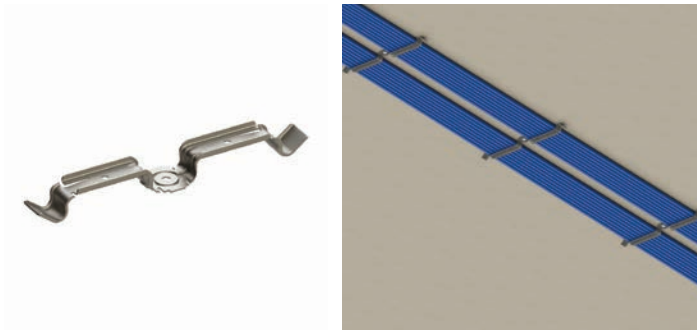

## FEATURES


- Ideal for smaller runs of cable
- Flexible clip retains shape and allows for cables to be inserted after installation
- Rounded edges help prevent cable damage
- Cables are neatly installed providing a consistent and professional appearance
- Low-profile allows for installations in tight spaces

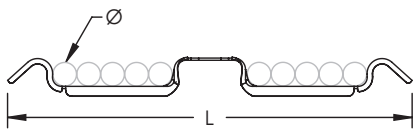

Part Number	PKM10H3	PKM10H6
Material	Spring Steel	Spring Steel
Finish	nVent CADDY Armour	nVent CADDY Armour
Cable Capacity	10	10
Diameter (Ø)	0.39" Max	0.39" Max
Hole Size (HS)	0.19"	0.28"
Length (L)	6 3/4"	6 3/4"
Standard Packaging Quantity	50 pc	50 pc
UPC	78285694743	78285694744
EAN-13	0782856947431	0782856947448



Supports cable diameters up to 1/2" (13 mm) when installed with a standard 1/4" (6 mm) washer.

# Metal Pressure Clip – PKM16H3 & PKM16H6

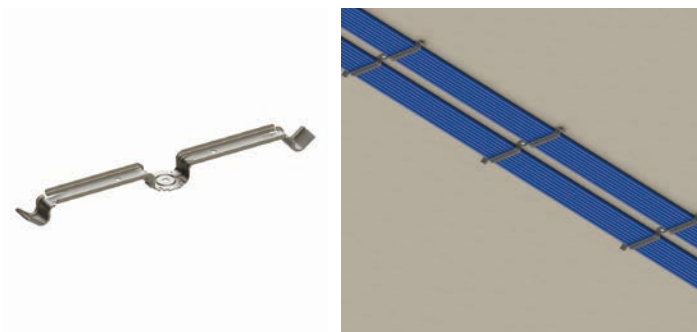

## FEATURES

 - Ideal for smaller runs of cable
- Flexible clip retains shape and allows for cables to be inserted after installation
- Rounded edges help prevent cable damage
- Cables are neatly installed providing a consistent and professional appearance
- Low-profile allows for installations in tight spaces

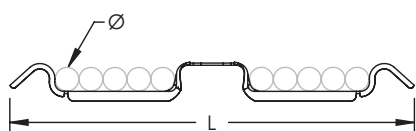

Part Number	PKM16H3	PKM16H6
Material	Spring Steel	Spring Steel
Finish	nVent CADDY Armour	nVent CADDY Armour
Cable Capacity	16	16
Diameter (Ø)	0.39" Max	0.39" Max
Hole Size (HS)	0.19"	0.28"
Length (L)	9 1/4"	9 1/4"
Standard Packaging Quantity	50 pc	50 pc
UPC	78285694745	78285694746
EAN-13	0782856947455	0782856947462

Supports cable diameters up to 1/2" (13 mm) when installed with a standard 1/4" (6 mm) washer.

Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN RAYCHEM SCHROFF TRACER**



[nVent.com/CADDY](https://www.nVent.com/CADDY)

WARNING: nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [nVent.com/CADDY](https://www.nVent.com/CADDY) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

©2018 nVent. All nVent marks and logos are owned or licensed by nVent Services GmbH or its affiliates. All other trademarks are the property of their respective owners. nVent reserves the right to change specifications without notice. CADDY-SB-H84219-PKMMetalPressureClip-USEN-1808