


MACROFIX Insulated Ventilation Duct Clamp

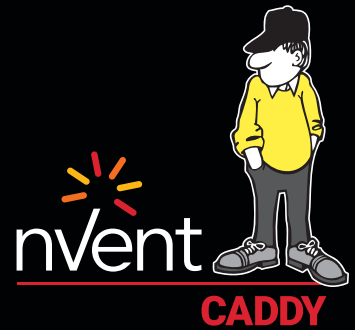

MFVI

DURABILITY FEATURES

Engineered embossed design including a central rib and return lips, gives the pipe clamp a superior load capacity on sizes 450mm and bigger

Does not open when sliding duct

Return-lip on the hanger prevents the rubber from detaching, eliminating rework during installation

Thread impression retains quick locking captive screw and prevents it from falling out during installation



The color of the line corresponds to the larger goal of each feature:

DURABILITY FEATURES
EASE OF USE FEATURES
VERSATILITY FEATURES

EASE OF USE FEATURES

Complete hanger assembly comes out of the box ready to install (sizes up to 600 mm)

Increased opening angle easily accommodates all standard-sized spiral ducts



Quick locking system prevents the hanger from accidentally opening when duct is moved or adjusted, and can be closed with one hand

VERSATILITY FEATURES

Combination nut can be attached to M8 or M10 threaded rod, simplifying material handling

Combo head bolt works with slotted, hex, or Phillips drivers

Longer ears position the screw farther from the hanger, improving tool clearance when the screw is tightened

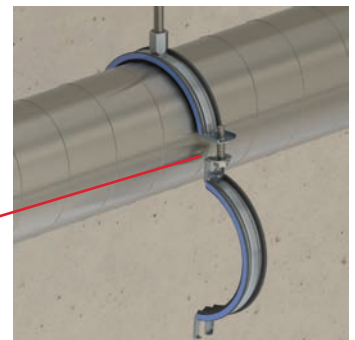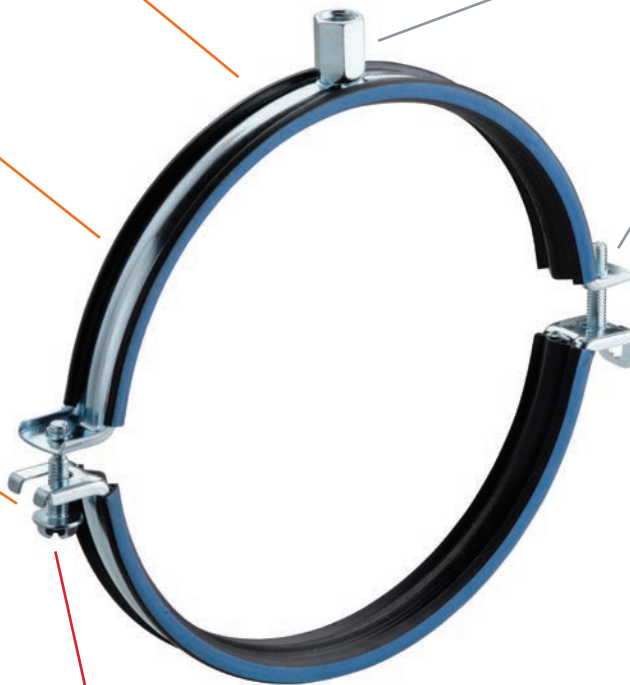

Our powerful portfolio of brands:

CADDY ERICO HOFFMAN RAYCHEM SCHROFF TRACER

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at nVent.com/CADDY and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and/or death, and void your warranty.

©2019 nVent. All nVent marks and logos are owned or licensed by nVent Services GmbH or its affiliates. All other trademarks are the property of their respective owners.

nVent reserves the right to change specifications without notice.

CADDY-FLY-H84777-MacroVFeatures-UKEN-1904