


DOSR DOUBLE OFFSET SURGE RESTRAINT FOR CPVC PIPE



- Provides quick and easy snap-in installation of pipe
- Built-in nail tab allows for fast, temporary mounting to any surface
- Rated for use with CPVC fire sprinkler pipe
- Positions pipe 1-1/2" (38 mm) out and up from the mounting surface eliminating the need for wooden spacer blocks
- Meets the UL® 203 stringent upward thrust requirement
- UL® Listed as both a hanger and restraint in the double offset orientation
- Complies with static load requirements of NFPA® 13
- Includes mounting screws
- Can be used with 3TW backing nut on composite wood joist installations

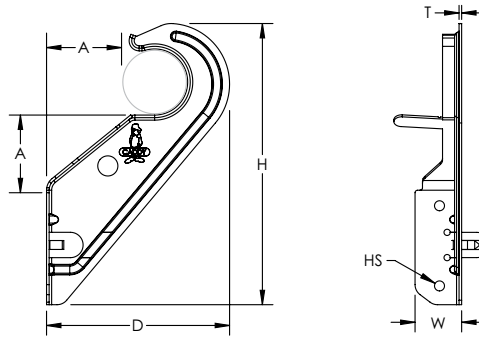

Material: Steel
Finish: Pregalvanized



Part Number	Pipe Size	Hole Size HS	Height H	Width W	Depth D	A	Thickness T	Hanger Spacing
DOSR075	3/4"	0.2"	5.2"	1"	3.5"	1 1/2"	18 GA	6' Max
DOSR100	1"	0.2"	5.8"	1"	3.4"	1 1/2"	18 GA	6' Max

NFPA is a registered trademark of National Fire Protection Association, Inc.
UL, UR, cUL, cUR, cULus and cURus are registered certification marks of UL LLC.