
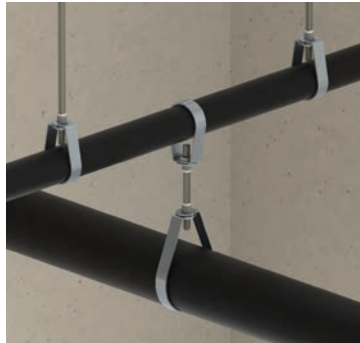


100T Heavy Duty Trapeze Loop Hanger

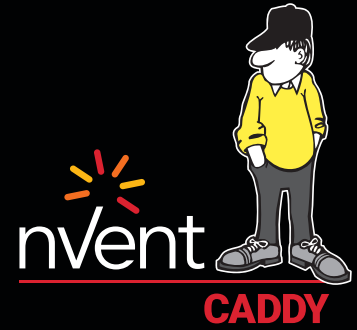

FEATURES

- Recommended for the suspension of stationary non-insulated pipe lines
- Designed for heavy duty trapeze installations where space is limited and attachment to structure is difficult
- UL® Listed to support trapeze assembly loads of 8" pipe size
- Conforms with Federal Specification WW-H-171 (Type 10), Manufacturers Standardization Society (MSS) SP-58 (Type 10)


SPECIFICATION

Material: Steel | Finish: Pregalvanized



Part Number	Pipe Size	Outer Diameter OD	Rod Size RS	A	B	C	Static Load F
100T0200EG	2"	2 1/2"	1/2"	5"	2 3/8"	1 7/16"	1,250 lb
100T0250EG	2 1/2"	3"	1/2"	5 5/8"	2 13/16"	1 5/8"	1,250 lb
100T0300EG	3"	3 5/8"	1/2"	6 9/16"	3 1/2"	1 7/8"	1,250 lb
100T0350EG	3 1/2"	4 1/8"	1/2"	7"	3 5/8"	1 7/8"	1,250 lb
100T0400EG	4"	4 5/8"	1/2"	7 3/4"	4"	2"	1,250 lb

Upper trapeze support and lower hanger must be able hold the maximum load intended for the trapeze assembly.

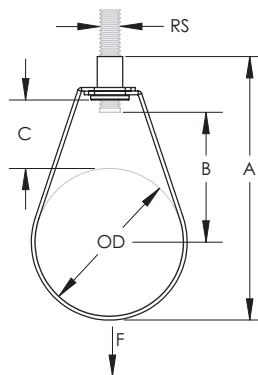

Our powerful portfolio of brands:

CADDY ERICO HOFFMAN RAYCHEM SCHROFF TRACER