


# nVent CADDY Heavy Duty Telescoping Bracket

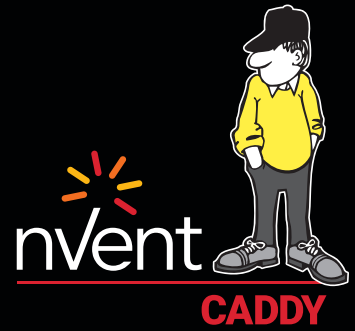


## CONNECT AND PROTECT

For ultimate stud-wall flexibility and snap-in time savings, choose the nVent CADDY Heavy Duty Telescoping Bracket and Box Mounting Plate. We created this product grouping after listening to the electrical contractor community, designing a solution that makes the job easier, repeatable and reliable. The result is a system based on a telescoping bracket that adapts to studs spaced 16" to 24", and a snap-in box mount with ultimate flexibility.

Made to work with data and electrical applications, choose the telescoping bracket and box mounting products for your next job; and provide your team the flexibility they need – with the confidence that it is installed right the first time.

### HEAVY DUTY TELESCOPING BRACKET

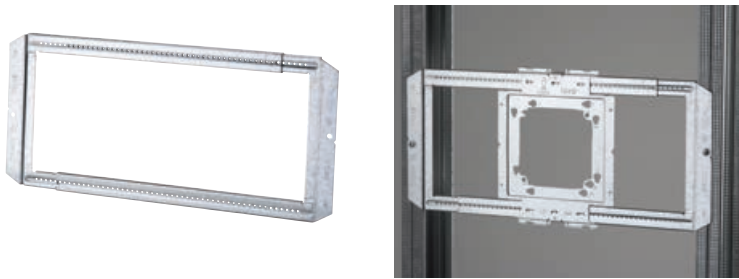

- Maximize speed and job efficiency with snap-on box mounting plates (sold separately)
- Install box mounting plates with a just a snap; securely at any position in the telescoping bracket
- Rigid design eliminates the need for far-side support
- Repeatable, time-saving design is ready to use right from the box
- Compatible with wood or metal studs, spaced from 16" to 24"

Part Number	Material	Finish	Stud Spacing Adjustability	Box Size	Standard Packaging Quantity
TB1624HD	Steel	Pregalvanized	14 1/2" – 25"	4" 4 11/16" 5"	25 pc




### BOX MOUNTING PLATE



- Works with our Heavy Duty Telescoping Bracket - just snap it in
- Flexible installation options also allow mounting direct to metal or wood studs
- Multiple key hole configurations for ease of installation and visual location confirmation
- Adapt with confidence to any situation; with low voltage extruded holes and the ability to remove and reinstall screws multiple times without compromise
- Works with vertically or horizontally-mounted single and double gang adjustable mud rings
- Ready for prefabrication and job-site adjustments with a specially-designed tab that holds strong without locking in place

Part Number	Material	Finish	Box Size	Standard Packaging Quantity
TB45P	Steel	Pregalvanized	4" 4 11/16" 5"	25 pc

## BOX MOUNTING PLATE WITH FAR SIDE SUPPORT

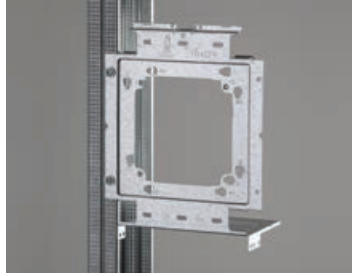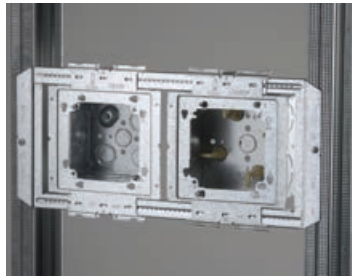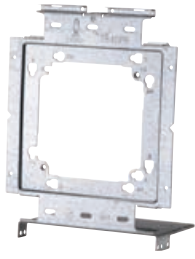


- Works with our Heavy Duty Telescoping Bracket - just snap it in
- Flexible installation options also allow mounting direct to metal or wood studs
- Far side support allows you to install on any stud depth and width
- Multiple key hole configurations for ease of installation and visual location confirmation
- Adapt with confidence to any situation; with low voltage extruded holes and the ability to remove and reinstall screws multiple times without compromise
- Works with vertically or horizontally-mounted single and double gang adjustable mud rings
- Ready for prefabrication and job-site adjustments with a specially-designed tab that holds strong without locking in place


Part Number	Material	Finish	Box Size	Standard Packaging Quantity
TB45PK	Steel	Pregalvanized	4" 4 11/16" 5"	25 pc

### Box Mounting Plate – Detailed View


Prefabrication Tab  
in Bent Position

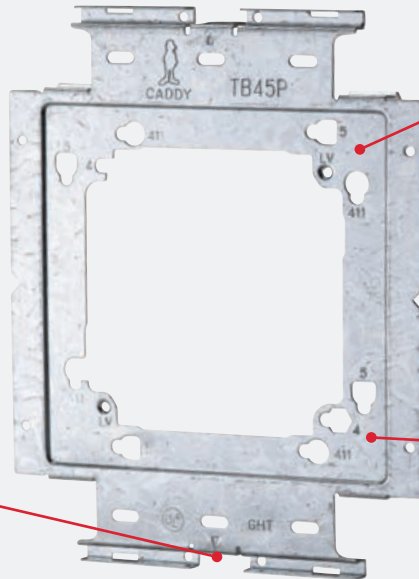

Low Voltage Extruded Hole

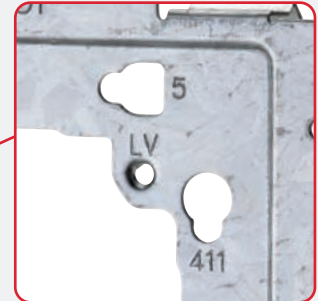

Keyholes

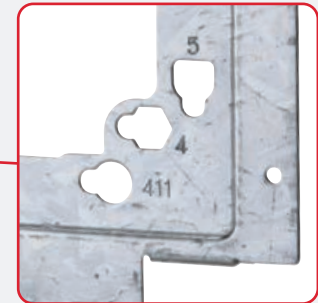

Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN RAYCHEM SCHROFF TRACER**