

Complete your grounding system with nVent ERICO



CONNECT AND PROTECT

Versatile connection and clamping options to fit every installation requirement


nVent ERICO is your trusted source for grounding and bonding systems. Our clamps, connectors and innovative grounding solutions help ensure your project will stay on time and on budget.

HAMMERLOCK GROUND CLAMP – INSTALL WITH JUST A HAMMER

Features


- Irreversible connection with excellent mechanical strength
- Low resistance connection
- Provides a visual indication of completed connection
- Allows for “T” or pass-through connections

3/0,4/0

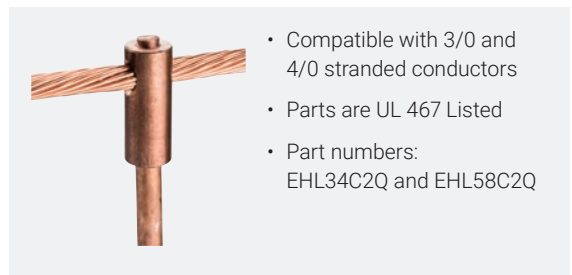

- Compatible with 3/0 and 4/0 stranded conductors
- Parts are UL 467 Listed
- Part numbers: EHL34C2Q and EHL58C2Q

2 HOLE

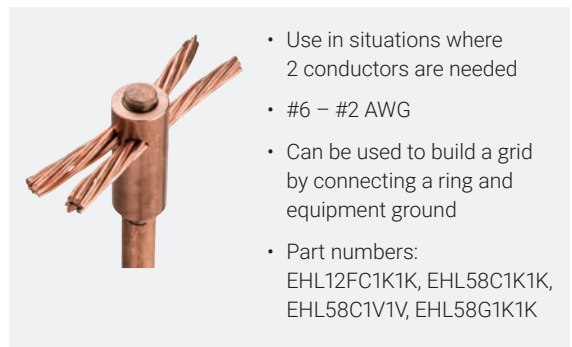


- Use in situations where 2 conductors are needed
- #6 – #2 AWG
- Can be used to build a grid by connecting a ring and equipment ground
- Part numbers: EHL12FC1K1K, EHL58C1K1K, EHL58C1V1V, EHL58G1K1K

UNIVERSAL GROUND ROD CLAMP – MAKE CONNECTIONS QUICKER AND EASIER

Features


- Cost-effective and reliable way to connect ground rods to conductors
- Used for above ground and below grade installation
- Universal size means you carry less with you and get more done
- UL 467 – suitable for direct burial in earth or concrete

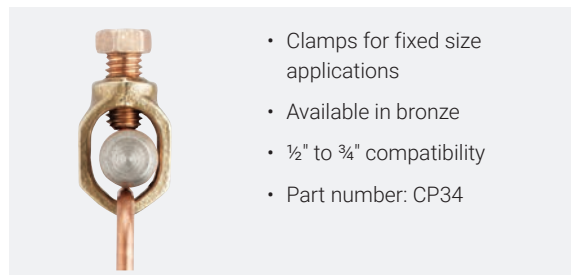

- Clamps for fixed size applications
- Available in bronze
- ½" to ¾" compatibility
- Part number: CP34

CONNECTORS

Water Pipe Clamps

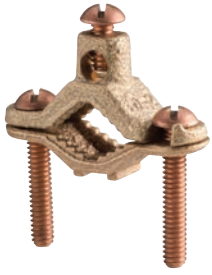

- High-strength silicone bronze
- Connect copper conductors to metallic water pipe or ground rods

Fence Post Clamps



- Use your fence or gate as an ideal grounding mounting point
- Theft-detrant appearance

Rebar Connectors



- Lay-in feature cuts installation time
- Approved for direct burial in earth and concrete

Couplers



- Join ground rod to ground rod
- Bronze, galvanized, or stainless
- Low-resistance connection

U-Bolt



- Connect conductors in parallel and perpendicular orientations
- Theft-detrant appearance

Acorn Clamp



- Bronze or stainless
- Simple installation
- Inexpensive

COMPLETE YOUR GROUNDING SYSTEM WITH NVENT ERICO

Copper-Bonded Ground Rods



- Available in 3/8" to 1" diameter
- 99.9% pure electrolytic copper coating – 10 mils minimum
- High carbon steel core and tip
- 80,000 psi minimum tensile strength
- IEEE® Std 80 rated for high-fault current capacity

nVent ERICO Cadweld



- Battery-powered control units, graphite molds and exothermic welding material
- Trusted in more than 100 million connections worldwide
- No corrosion or loosening over time

Learn more about our full range of products and solutions on our [Grounding and Bonding Hub](#). 



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN RAYCHEM SCHROFF TRACER