



# Cable Management on Concrete Structures

## Non-Continuous

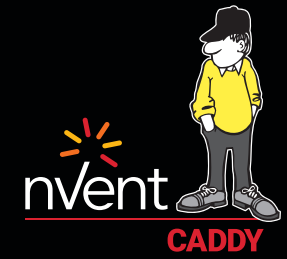

CONNECT AND PROTECT

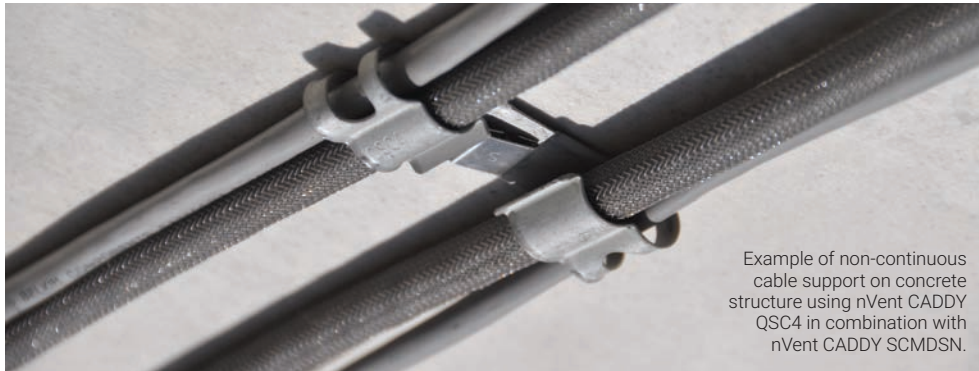

Example of non-continuous cable support on concrete structure using nVent CADDY QSC4 in combination with nVent CADDY SCMDSN.

			MLT2HS6 (188100)	CT (170450) & MLT2HS6 (188100)	CTS1 (171600) & MLT2HS6 (188100)	QSC (182058)	QSC4 (182059)	PKM10H3 (182044)	PKM10H3GBSF (182053)	PKM10H6 (182045)	PKM10H6IN (182048)	PKM16H3 (182046)	PKM16H3GBSF (182054)	PKM16H6 (182047)	PKM16H6IN (182049)	nVent CADDY Cat HP J-Hook System	
Installation Methods	Direct Fastening																
	Anchoring Solutions	SCMDSN (800070)															
		SCMND (800071)															
		BSZSU06040ZL (402605)															
Application	Ceiling Installation (Horizontal)		✓	✓	✓	✓	✓	✓	✓	✓	✓	✓	✓	✓	✓	✓	✓
	Wall Installation (Vertical)			✓	✓												✓
	Full Stainless Steel Solution for Superior Corrosion Protection/Outdoor		✓		✓												
	Maximum Cable Capacity		1 >1	1 >1	1 >1	4	4	10	10	10	10	16	16	16	16	16	330
	Fire-Rating per DIN 4102-12			✓	✓							✓				✓	✓
	Suitable for Supporting Wiring Systems According to BS7671-1:2018 When Installed in Combination with Other Steel Components		✓	✓	✓	✓	✓	✓	✓	✓	✓	✓	✓	✓	✓	✓	✓

**Legend:** Best/recommended installation method **X** Works but not the best/recommended installation method Suitable/applicable