


# nVent CADDY Rod Lock Spring Steel Strut Nut

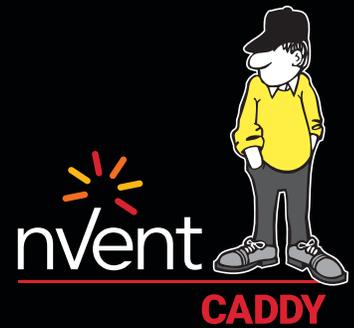

## CONNECT AND PROTECT

The QCN combines the unique properties of Spring Steel and CADDY "push-to-install" technology to create a snap in place strut nut with shockingly quick install of threaded rod or bolts. Use with a hex nut on threaded rod for fast install of prefabricated trapeze systems or with a truss head bolt for unbelievably fast wall mounting of electrical boxes and other services.




### FEATURES

- Easy "push-to-install" design allows installers to simply push the threaded rod through the mounting hole, instantly holding it in position
- Works with slightly damaged threads and minor burrs on the threaded rod
- Perfect for quickly installing branch runs either at the load with standard strut or at the structure in combination with embedded strut
- Integrated design eliminates the need for finicky spring nuts and loose hardware, simplifying install
- Quickly wall mount enclosures using common threaded bolts
- Designed for use with standard strut widths (1 5/8" or 41 mm) both shallow and deep profiles

Material: Spring Steel  
Finish: nVent CADDY Armour

Part Number	Rod Size RS	Height H	A	B	Static Load 1 F1	Static Load 2 F2	Static Load 3 F3	Torque TQ
4QCN	1/4"	0.72"	1 1/2"	1 1/2"	75 lb	20 lb	30 lb	10 ft lb
5QCN	5/16"	0.72"	1 1/2"	1 1/2"	100 lb	25 lb	50 lb	10 ft lb
6QCN	3/8"	0.72"	1 1/2"	1 1/2"	110 lb	30 lb	50 lb	20 ft lb
8QCN	1/2"	0.67"	1 1/2"	1 1/2"	125 lb	30 lb	50 lb	25 ft lb

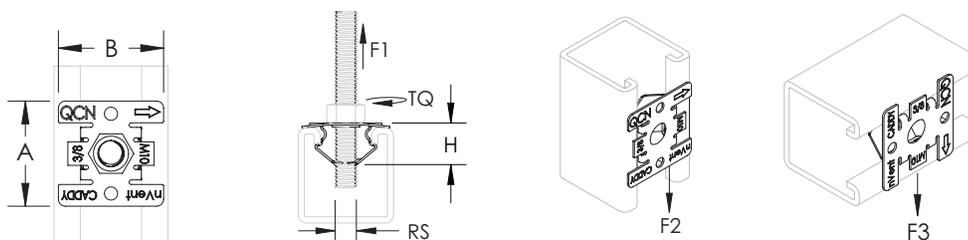

Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN RAYCHEM SCHROFF TRACER**