


nVent CADDY Macrofix Plus – Insulated

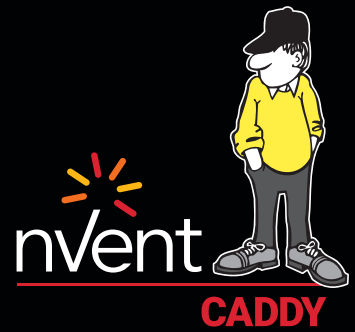

CONNECT AND PROTECT

Features Guide

DURABILITY FEATURES

Engineered embossed design including a central rib and return lips, give the pipe clamp a superior load capacity

Return-lip on the hanger prevents the rubber from detaching, eliminating rework during installation

Thread impression retains quick locking captive screw and prevents it from falling out during installation



The color of the line corresponds to the larger goal of each feature:

DURABILITY FEATURES
EASE OF INSTALL FEATURES
VERSATILITY FEATURES

EASE OF INSTALL FEATURES

Longer ears position the screw farther from the hanger, improving tool clearance when the screw is driven down

Quick locking system prevents the hanger from accidentally opening when pipe is moved or adjusted, and can be closed with one hand

Increased opening angle easily accommodates all standard-sized pipe up to 215 mm diameter

VERSATILITY FEATURES

Combination nut can be attached to M8 or M10 threaded rod, simplifying material handling

Screw length has been optimized to accommodate an increased pipe range, reducing inventory

Combo head bolt works with slotted, hex, or Phillips drivers



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN RAYCHEM SCHROFF TRACER