
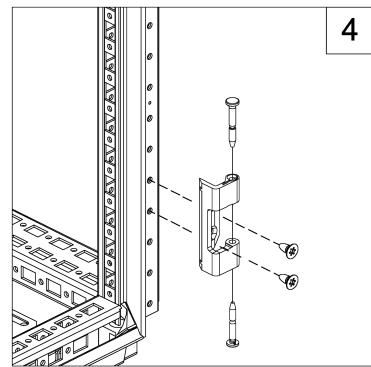
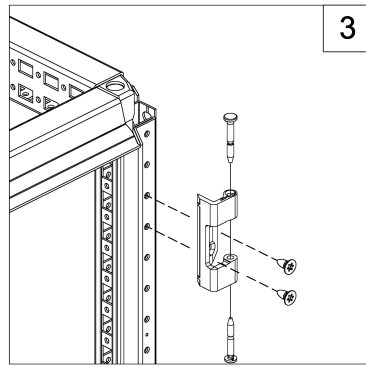
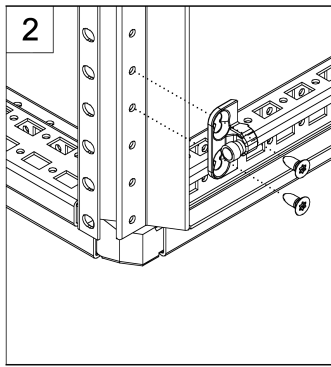
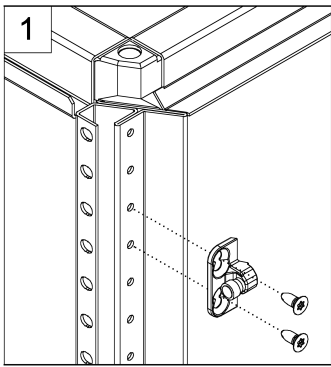




DNMK01

Ref.	Pic.	Qty.
A		4
B		4
C		8
D	M6x12	16

H	A	B
1100	275	425
1400	325	525
1600	425	525
1800	525	525
2000	625	525
2200	625	725






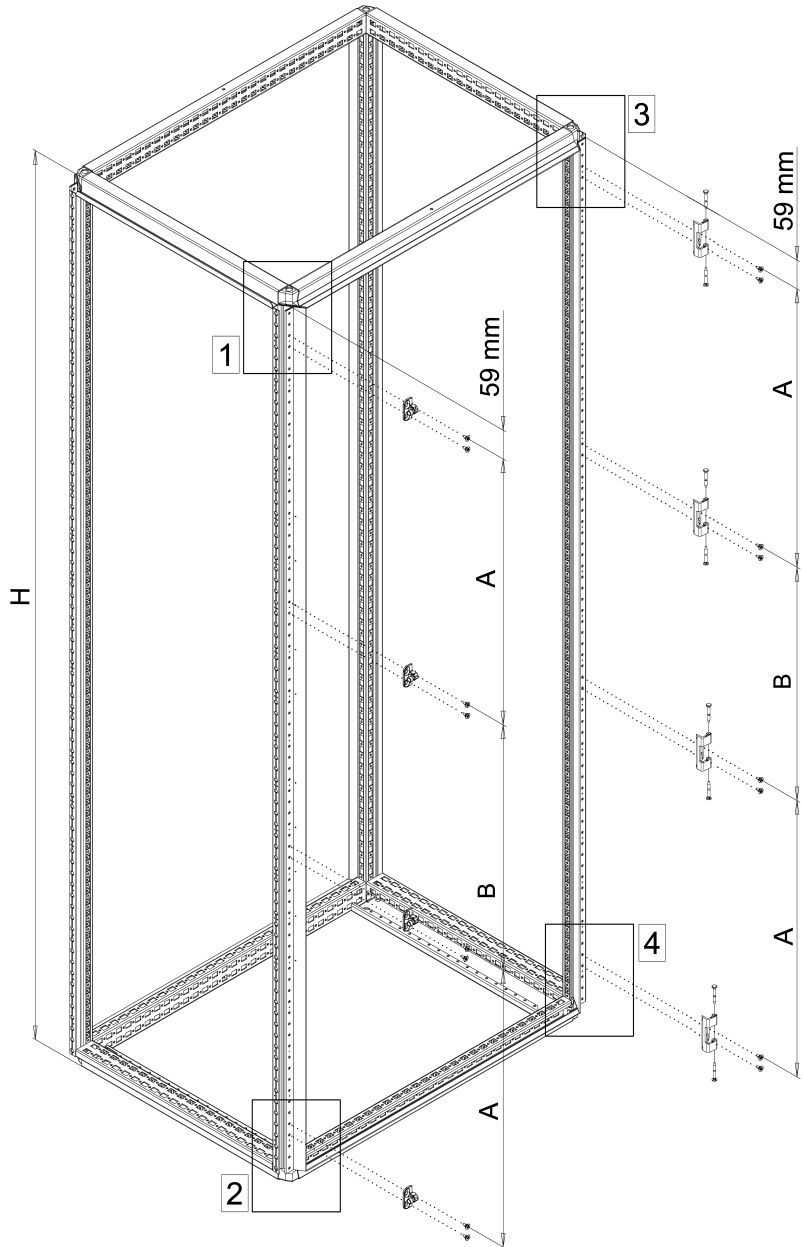


 DNMK02

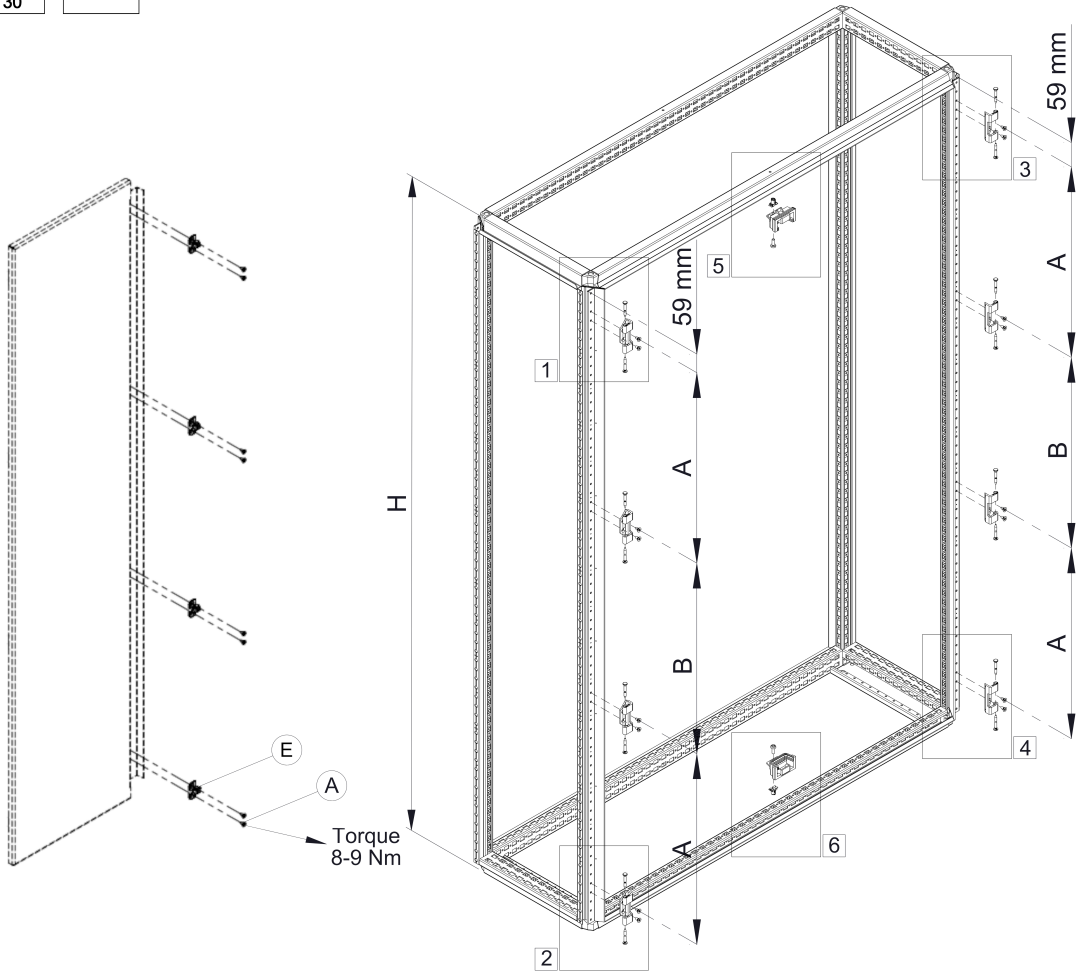

Ref.	Pic.	Qty.
A		24
B		2
C		2
D		2
E		4
F		8
G		16

H	A	B
1100	275	425
1400	325	525
1600	425	525
1800	525	525
2000	625	525
2200	625	725

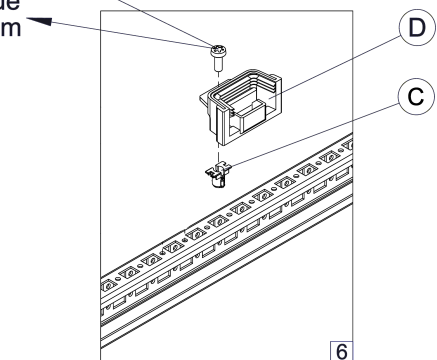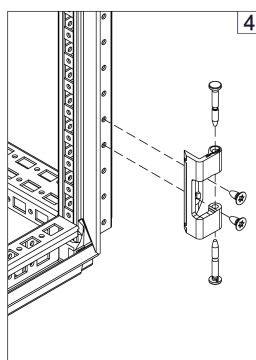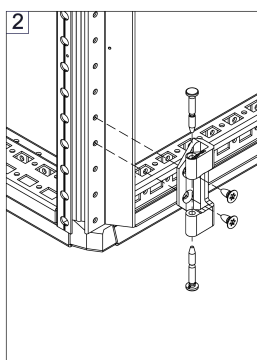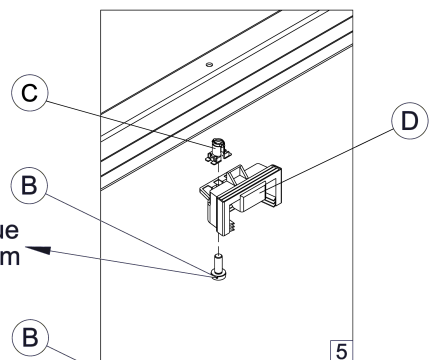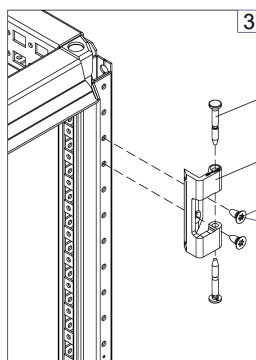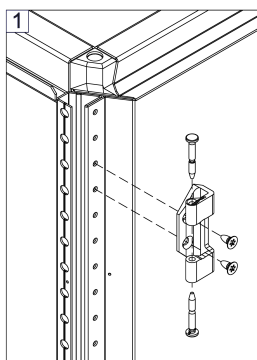

Torque 8-9 Nm

Torque 8-9 Nm

Torque 8-9 Nm