


nVent CADDY SuperKlip

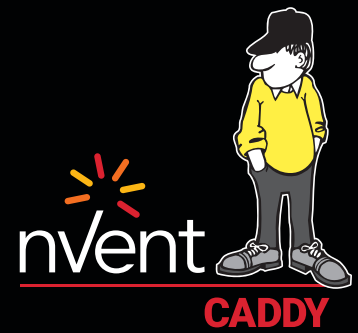

CONNECT AND PROTECT




Material: Xenoy®
Finish: -13 to 194°F

FEATURES

- Closes and locks automatically when the pipe, tube or cable is inserted
- One-piece clamp for fast and convenient installation
- Fasten with either wood screw, dual threaded screw with or without collar, nail with collar, threaded rod, mounting plate or shot-fire bracket

Part Number	Outer Diameter OD	Rigid Conduit Size	Pipe Size	Copper Tube Size	B	C	Static Load F
389017	0.31" – 0.37"	–	–	1/4"	1 1/16"	1 1/16"	30 lb
389018	0.37" – 0.46"	–	–	1/4"	1 1/16"	1 1/16"	33 lb
389001	0.46" – 0.56"	–	–	3/8"	9/16"	1 3/16"	35 lb
389002	0.56" – 0.66"	–	–	1/2"	9/16"	1 3/16"	40 lb
389003	0.66" – 0.77"	3/8"	3/8"	5/8"	5/8"	1 13/32"	43 lb
389004	0.77" – 0.86"	1/2"	1/2"	–	5/8"	1 9/16"	50 lb
389005	0.86" – 0.98"	–	–	3/4"	2 1/32"	1 5/8"	48 lb
389006	0.98" – 1.09"	3/4"	3/4"	–	1 1/16"	1 3/4"	54 lb
389007	1.09" – 1.23"	–	–	1"	1 1/16"	1 15/16"	58 lb
389008	1.23" – 1.40"	1"	1"	1 1/4"	1 1/16"	2 1/8"	67 lb
389009	1.40" – 1.56"	–	–	1 1/4"	1 1/16"	2 5/16"	72 lb
389011	1.56" – 1.71"	1 1/4"	1 1/4"	1 1/2"	3/4"	2 1/2"	80 lb
389012	1.83" – 2.00"	1 1/2"	1 1/2"	–	3/4"	2 7/8"	84 lb
389013	2.00" – 2.19"	–	–	2"	2 5/32"	3 3/32"	90 lb
389014	2.30" – 2.52"	2"	2"	–	1 3/16"	3 15/32"	92 lb

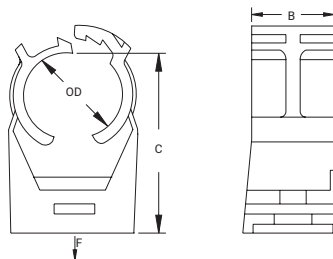

Our powerful portfolio of brands:

CADDY ERICO HOFFMAN RAYCHEM SCHROFF TRACER